


Front Panel, Unshielded, 3 U, 8 HP, 2.5 mm, Al, Anodized, Untreated Edges

CATALOG NUMBER

30818-277

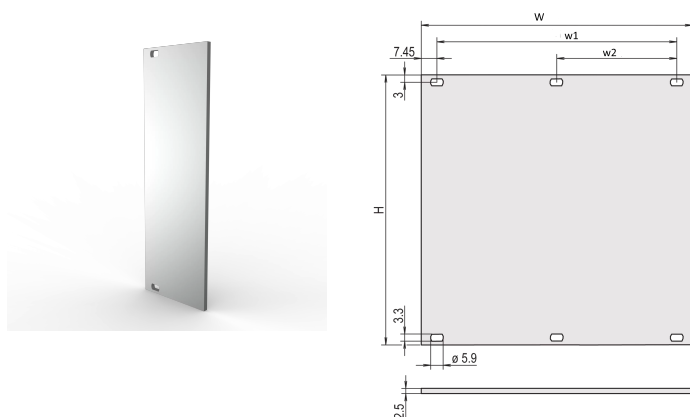

Front Panel, anodized with untreated edges, unshielded. The panels enable mounting on horizontal rails.

CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm

Al, clear anodized, untreated edges

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 8HP

Accessory Type: Front panel

Package Quantity: 1

Handle Type: None

Mounting: Screw-on Front

Front Finish: Anodized

Rear Finish: Anodized

Treated Edges: No

Complies With: IEC 60297-3-101; IEEE 1101.1/10

EMC Shielding: No

Finish: Anodized

Material: Aluminum


Product Type: Front Panel

Type: Front Panel without Handle

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

DIAGRAMS

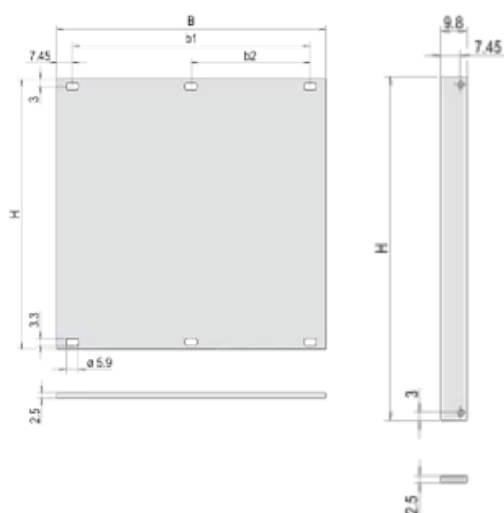

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE