

## Honeywell Sensing and Control

Search



4TL11-1  
( Home : Products : Switches » MICRO SWITCH™ Toggle Switches » TL )

contacts

### narrow your search

#### Products

- Controls Monitoring and Lighting (286)
- Machine Safety (1727)
- Sensors (6158)
- Switches (9781)
- Wireless (45)

#### Technology

- Control and Instrumentation (890)
- Electromechanical (9303)
- Magnetic (538)
- Platinum thin film (56)
- Thick Film (1372)
- More...

### new products

#### New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site  
WGLA and WPMM  
XYR6000™

 
find out more

### white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

### Need help?

Click here to contact us



TL Series Toggle Switch, 4 pole, 3 position, Screw terminal, Standard Lever

Actual product  
appearance may  
vary.

Sales &amp; Service

Distributor Inventory

Customer Service  
Technical Support  
Global Sales & Service  
View Site Demo  
Site Comments?

### meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.



Meet Dr. Larry

### my links

Login to iCOM  
Login to Rep/AD Portal  
Login to Digital University


### News Center

HONEYWELL INTRODUCES TRUSTABILITY® NSC SERIES, UNCOMPENSATED / UNAMPLIFIED BOARD MOUNT PRESSURE SENSORS

HONEYWELL EXPANDS ITS LIMITLESS™ PLATFORM WITH THE LAUNCH OF ITS GLOBALLY AVAILABLE INDUSTRIAL WIRELESS RECEIVER

HONEYWELL EXTENDS ITS TRUSTABILITY® PRESSURE SENSOR PRODUCT LINE WITH A SINGLE SIDE LIQUID MEDIA OPTION

### MICRO SWITCH Anniversary site

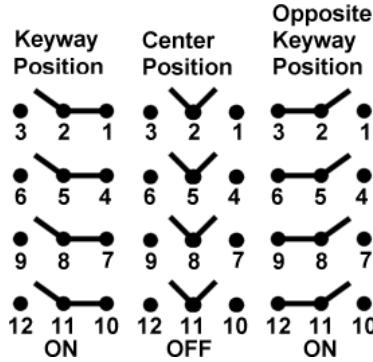

Overview Specs Documentation Application Notes

#### Product Specifications

Circuitry/Operating action

Product Type	MICRO SWITCH™ Toggle Switch
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc, 0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac, 0.5 A at 250 Vdc
Circuitry	4PDT
Action	3 position
Mounting	Bushing 15/32 in
Termination	Screw
Lever Type	Standard
Comment	Silver cadmium oxide contacts
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	TL