


PropacPRO, Case, Unshielded, Desktop

SCHROFF



Other Views

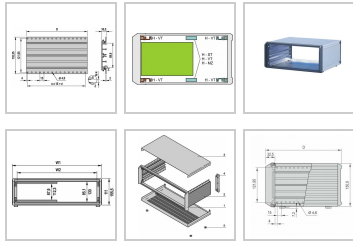

Catalog Number: 14576-145

Back To Product

- Unshielded
- Prepared for GND/earthing
- Desk-top case with pre-configured components, in accordance with IEC 60297-3-101; prepared for 19" components such as plug-in units and euroboards
- Ventilation slots in base plate

Family:

PropacPRO

EMC Shielding:

- Retrofitable
- Unshielded

Options:

Front Trim

Disposition:

Case only

Type:

Case Kit

Note:

Case, 2 U with side panel for tip-up carrying handle on request



Select product specifications before modifying or adding to project list or requesting a quote.

Height-U-defining

3

Depth-mm-defining

386

Width-HP-defining

63

Clear Selection

Quantity

1

Add Item to Project List +

Documents

- Main Catalog - PropacPRO
- User manual
- Earthing instructions
- EMC test report with perforated rear panel
- EMC testreport (Rear panel without perforation)

Links

- Native CAD files

Technical Data

Qty	1 piece	Maximum mounting depth	D - 45 (open space: front panel - rear panel)
Depth D mm	386.0		
For case height [U]	3		
Height U	3		
Width HP	63		

EXPLORE

- About Us
- Services & Capabilities
- News & Events
- Newsletter Subscriptions
- Strategic Partnerships
- Investor Relations

CONTACT

- Customer Service
- Find a Sales Office or Distributor
- Global Locations
- Product Compliance & Certifications
- Partner Login

DOWNLOAD

- Download Center
- Reference Projects
- Videos
- Product Configurators
- Warranties and Terms of Sale & Procurement

Connect With Us

