

# HC-D 7-SML-57/M1PG11/PA - Housing



1772298

<https://www.phoenixcontact.com/us/products/1772298>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON D7 box mounting base, with single locking latch, height 25.5 mm, with 1 x Pg11 screw connection, with open bottom, zinc

## Commercial data

Item number	1772298
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF55
Product key	AF7AAE
Catalog page	Page 413 (C-4-2013)
GTIN	4017918036966
Weight per piece (including packing)	29.66 g
Weight per piece (excluding packing)	29.66 g
Customs tariff number	85389099
Country of origin	DE

# HC-D 7-SML-57/M1PG11/PA - Housing



1772298

<https://www.phoenixcontact.com/us/products/1772298>

## Technical data

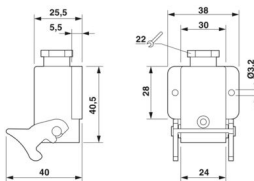
### Notes

General	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
---------	---

### Product properties

Product type	Housing with locking latch
Housing type	Surface mounting housing
Application	Standard
Type	D7
No. of cable outlets	1
Type of the screw connection	1x Pg11
Shielded	no
Cable outlet	lateral
Pg screw connection	with

### Dimensions

Dimensional drawing	
Width	40.5 mm
Height	25.5 mm
Length	24 mm
Wrench size, union nut	18 mm

### Material specifications

Seal material Cable seal	NBR
Housing material	PA
Housing surface material	PA, light gray
Locking latch material	PA

### Mechanical properties

#### Mechanical data

Type of the screw connection	1x Pg11
Locking type	Latch

### Cable/line

External cable diameter Cable 1	7.5 mm ... 12.5 mm
---------------------------------	--------------------

### Connection data

# HC-D 7-SML-57/M1PG11/PA - Housing



1772298

<https://www.phoenixcontact.com/us/products/1772298>

External cable diameter	7.5 mm ... 12.5 mm
-------------------------	--------------------

## Environmental and real-life conditions

### Ambient conditions

Degree of protection	IP54
	IP65 (with sealing screw)
Ambient temperature (operation)	-40 °C ... 125 °C

## Drawings

### Dimensional drawing



# HC-D 7-SML-57/M1PG11/PA - Housing



1772298

<https://www.phoenixcontact.com/us/products/1772298>

## Classifications

### ECLASS

ECLASS-13.0	27440202
-------------	----------

# HC-D 7-SML-57/M1PG11/PA - Housing



1772298

<https://www.phoenixcontact.com/us/products/1772298>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)