




Part Number : [150110640](#)

Product Description : 0.35mm Pitch Premo-Flex SlimStack FFC/FPC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 40 Circuits

Series Number : 15011

Status : Active

Product Category : Flat-Flexible Cable (FFC)

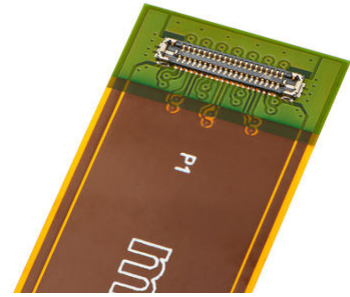

Documents and Resources

Drawings


[150110640 sd.pdf](#)

Specifications

[150110001-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15011
Description	0.35mm Pitch Premo-Flex SlimStack FFC/FPC Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 40 Circuits
Product Name	Premo-Flex SlimStack FFC/FPC Jumper
UPC	198282795391

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	60V AC/DC

Physical

Cable Length	152.00mm
Circuits (Loaded)	40
Contact Layout Type	A (same side)
Design Feature	Flexible Printed Circuit
Material - Plating Mating	Gold
Packaging Type	Bag
Pitch - Mating Interface	0.35mm
Temperature Range - Operating	-40° to +85°C
Termination Style	Soldered SlimStack Connector
Wire/Cable Type	Flexible Printed Circuit (FPC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
SlimStack Board-to-Board Plug, 0.35mm Pitch, ACB6+ Series, 0.60mm Mated Height, 1.90mm Mated Width, 40 Circuits, 8 Reels/ Carton	<u>2167010409</u>

This document was generated on Apr 28, 2026