



# Locking Forks - Non-Insulated Butted Seam 22-18 AWG

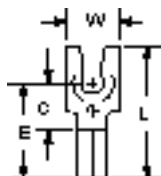


Product Number†	UPC (054007-)	Wire Range (AWG)	Stud Size	Max. Lock Width	W	C	L	E	Thickness	Barrel Length	Barrel I.D.	Terminals per Case
MU18-4FLK	01347	22-18	4	0.27	0.25	0.25	0.68	0.50	0.030	0.25	0.070	1000
MU18-6FLK	01348	22-18	6	0.27	0.25	0.25	0.68	0.50	0.030	0.25	0.070	1000
MU18-8FLK	01349	22-18	8	0.34	0.30	0.25	0.68	0.50	0.030	0.25	0.070	1000
MU18-10FLK	01350	22-18	10	0.35	0.32	0.25	0.68	0.50	0.030	0.25	0.070	1000




**MU18-4FL**  
4  
22-18

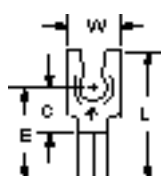

**MU18-6FL**  
6  
22-18

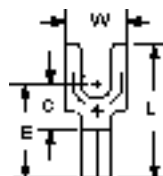

**MU18-8FL**  
8  
22-18

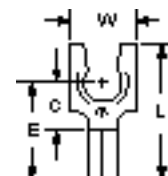

**MU18-10FL**  
10  
22-18

**Stud Size**  
**Wire Range**