



YMQ-110-01-L-5

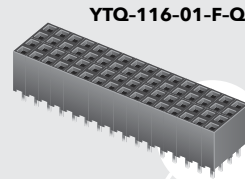

YMQ-116-01-F-Q

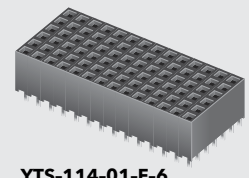

YTS-114-01-F-6

(2.00 mm) .0787"

YTS, YMQ SERIES

# HIGH-DENSITY SOCKET STRIP

## SPECIFICATIONS

For complete specifications see [www.samtec.com?YTS](http://www.samtec.com?YTS) or [www.samtec.com?YMQ](http://www.samtec.com?YMQ)

### Insulator Material:

Black Liquid Crystal Polymer

### Contact Material:

Phosphor Bronze

### Operating Temp Range:

-55 °C to +125 °C

### Plating:

Sn or Au over 50 μ" (1.27 μm) Ni

### Insertion Depth:

(2.62 mm) .103" to (5.03 mm) .198"

### Max Cycles:

100 with 10 μ" (0.25 μm) Au

### RoHS Compliant:

Yes

### Mates with:

YTT, YTW, YTE, TMMS



Choice of four, five or six row

(2.00 mm) .0787" pitch

(6.35 mm) .250"

(2.00 mm) .0787" TYP

## PROCESSING

### YTS Lead-Free Solderable:

Wave Only

### YMQ Lead-Free Solderable:


Wave or reflow with Matte Sn plating

## RECOGNITIONS

For complete scope of recognitions see [www.samtec.com/quality](http://www.samtec.com/quality)



FILE NO. E111594

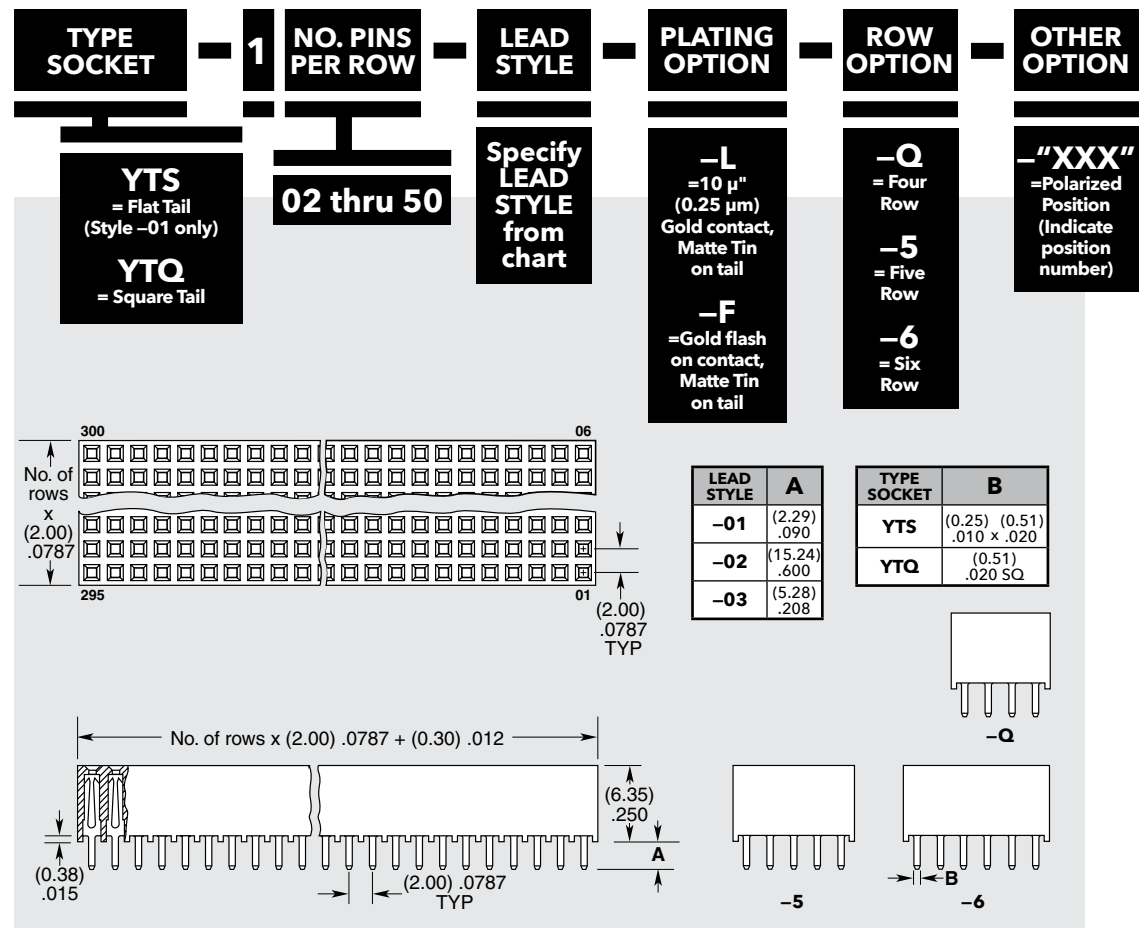

**Note:**  
Some lengths, styles and options are non-standard, non-returnable.

[WWW.SAMTEC.COM](http://WWW.SAMTEC.COM)

Unless otherwise approved in writing by Samtec, all parts and components are designed and built according to Samtec's specifications which are subject to change without notice.