



TOP VIEW

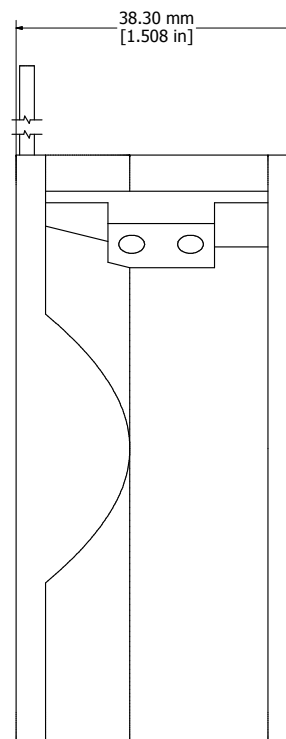

SIDE VIEW

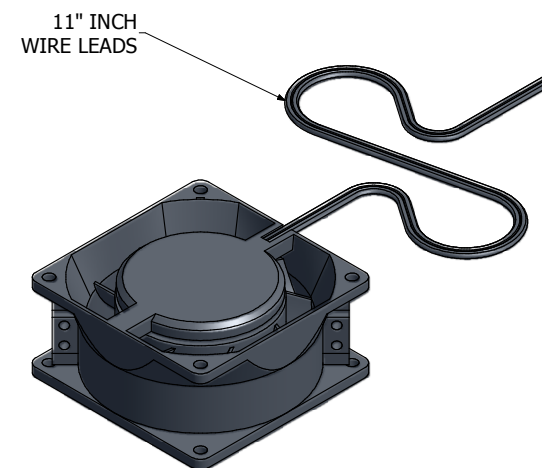

ISOMETRIC VIEW

FAN80AC230
Finish - Housing - Black Painted Aluminum
- Fan - Black Painted Steel
Rated - 230 VAC, 50/60 Hz, 0.05 Amps
Free Flow Air Delivery - 32 CFM
Hardware
4 Screws - Panhead Self-tapping 10-32 x 1/2"



HAMMOND
MANUFACTURING™

FAN80AC230

www.hammondmfg.com