


STRAIGHT JACK RECEPTACLE FOR PCB SOLDER LEGS

R141.426.000

SERIES BNC

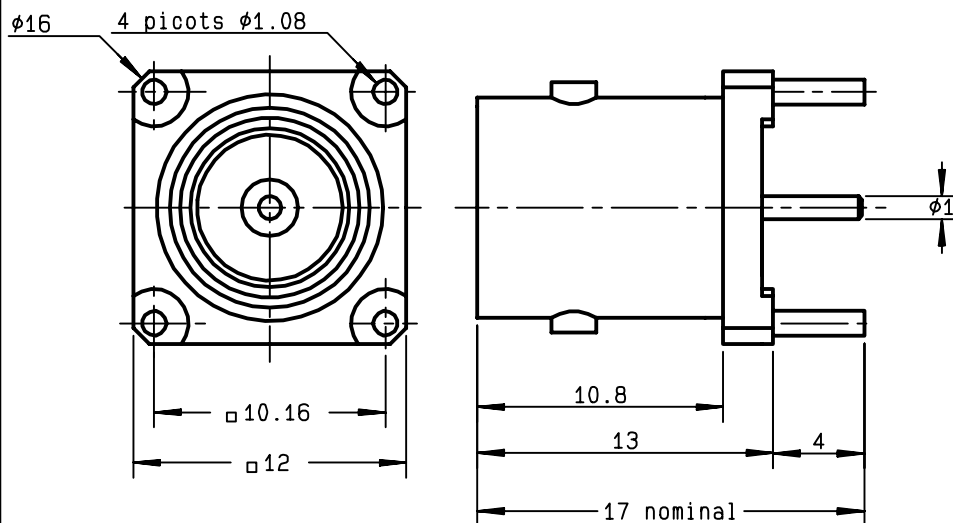

PERCAGE PANNEAU
MOUNTING HOLE

B DIA
5 holes

	MM		INCH	
	maxi	mini	maxi	mini
A	5.13	5.03	0.202	0.198
B	1.4	1.2	0.055	0.047
C	10.21	10.11	0.402	0.398

NOMINAL IMPEDANCE	50	Ω
FREQUENCY RANGE	0-4	GHz
TEMPERATURE RATING	-65/+165	°C
V.S.W.R	1.06* + .006 x F(GHz)Maxi	
RF INSERTION LOSS	.025* √F(GHz)	dB Maxi
VOLTAGE RATING	500	Veff Maxi
DIELECTRIC WITHSTANDING VOLTAGE	1500	Veff Mini
INSULATION RESISTANCE	5000	MΩMini
HERMETIC SEAL	NA	Atm.cm ³ /s
LEAKAGE (pressurized only)	NA	
MECHANICAL DURABILITY	500	Cycles
WEIGHT	9	gr
SPECIFICATION		

CABLES :

OTHERS CHARACTERISTICS

* Coaxial Transmission Line Only

CABLE RETENTION	NA	N Mini
CENTER CONTACT RETENTION		
Axial force - mating end	18	N Mini
Axial force - opposite end	18	N Mini
Torque	NA	cm.N Mini
RECOMMENDED TORQUES		
Mating	NA	cm.N
Panel nut	NA	cm.N
Clamp nut	NA	cm.N

CONNECTOR PARTS	MATERIALS	FINISH	(all values are given in micrometers)
BODY	BRASS	NICKEL 2	
OUTER CONTACT			
CENTER CONTACT	BERYLLIUM COPPER	GOLD 0.5 OVER NICKEL 2	
INSULATOR	PTFE	-	
GASKET		-	
OTHERS PIECES			

SOULARD

ISSUE
9913F00

CREATION DATE
07/11/1984

FILE PART-NUMBER



RADIALL®

The information given here is subject to change without notice.
Design changes may be in order to improve the product.

Connect to the future