

COMBINATION KNOBS

Versatile Collet Knob System

Suitable for a huge number of applications, our COMBINATION KNOBS feature a reliable collet fixing system, and can be configured as round knobs, wing knobs and spindle-shaped knobs in combination with a large selection of accessories.

- standard round, wing and spindle type design with matt surfaces
- secure operation by tried and tested collet fixing system
- convenient assembly of knobs from the front; brass collet fixing system for tight fitting to the control spindle
- clip-on covers in different colors, with or without indicator line
- also suitable for fitting accessory arrow disks, disks, dials, stator and nut covers
- torsion protection for 'D' profiled axes 6/4.6 mm as accessory (suitable for round and wing knobs sizes $\varnothing$ 20 to 50 mm with 6 mm borehole)

Round Knobs

sizes $\varnothing$ 9, 10, 13.5, 16, 20, 23, 31, 40, 50 mm

with boreholes 3, 4, 6, 8 mm, 1/8", 1/4" (depend from the size)

Wing Knobs

sizes $\varnothing$ 13.5, 16 mm with borehole 6 mm

Spindle-shaped Knobs



sizes $\varnothing$ 16, 23, 31, 40 mm with boreholes 3, 4, 6 mm (depend from the size)

Collet Type

sizes 10 and 13: blind holes with screw fixing

sizes 16 and 20: brass collet with stepped counterbored hole, except for axes 4 mm

from size 23 up: brass collet with through holes

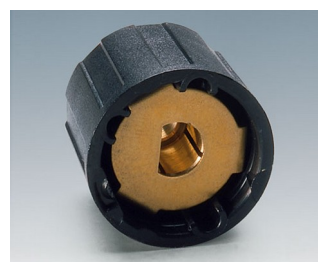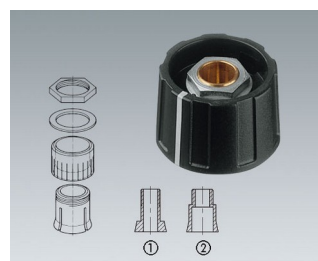

COMBINATION KNOBS

View Customizing Options

What do you still need for your own very personal product? We can supply enclosures and tuning knobs with all necessary modifications for fitting your electronic components.
Customizing options for Combination Knobs



Machining



Printing



Installation / Assembly
of accessories

Select Versions



A2316040
SPINDLE-SHAPED KNOB 16,
without line
ABS (UL 94 HB)
black RAL 9005
16x16mm 4mm



A2416030
SPINDLE-SHAPED KNOB 16,
with line
ABS (UL 94 HB)
black RAL 9005
16x16mm 3mm



A2416040
SPINDLE-SHAPED KNOB 16,
with line
ABS (UL 94 HB)
black RAL 9005
16x16mm 4mm



A2416048
SPINDLE-SHAPED KNOB 16,
with line
ABS (UL 94 HB)
dusty gray RAL 7037
16x16mm 4mm



A2423040
SPINDLE-SHAPED KNOB 23,
with line
ABS (UL 94 HB)
black RAL 9005
23x16mm 4mm



A2423060
SPINDLE-SHAPED KNOB 23,
with line
ABS (UL 94 HB)
black RAL 9005
23x16mm 6mm



A2423068
SPINDLE-SHAPED KNOB 23,
with line
ABS (UL 94 HB)
dusty gray RAL 7037
23x16mm 6mm



A2431060
SPINDLE-SHAPED KNOB 31,
with line
ABS (UL 94 HB)
black RAL 9005
31x16mm 6mm

COMBINATION KNOBS



A2431068
SPINDLE-SHAPED KNOB 31,
with line
ABS (UL 94 HB)
dusty gray RAL 7037
31x16mm 6mm



A2440060
SPINDLE-SHAPED KNOB 40,
with line
ABS (UL 94 HB)
black RAL 9005
40x16mm 6mm



A2440068
SPINDLE-SHAPED KNOB 40,
with line
ABS (UL 94 HB)
dusty gray RAL 7037
40x16mm 6mm



A2510030
ROUND KNOB 10, without line
ABS (UL 94 HB)
black RAL 9005
10x14mm 3mm



A2510038
ROUND KNOB 10, without line
ABS (UL 94 HB)
dusty gray RAL 7037
10x14mm 3mm



A2510040
ROUND KNOB 10, without line
ABS (UL 94 HB)
black RAL 9005
10x14mm 4mm



A2510048
ROUND KNOB 10, without line
ABS (UL 94 HB)
dusty gray RAL 7037
10x14mm 4mm



A2510320
ROUND KNOB 10, without line
ABS (UL 94 HB)
black RAL 9005
10x14mm 1/8"



A2513040
ROUND KNOB 13.5, without line
ABS (UL 94 HB)
black RAL 9005
13x15mm 4mm



A2513048
ROUND KNOB 13.5, without line
ABS (UL 94 HB)
dusty gray RAL 7037
13x15mm 4mm



A2513060
ROUND KNOB 13.5, without line
ABS (UL 94 HB)
black RAL 9005
13x15mm 6mm



A2513068
ROUND KNOB 13.5, without line
ABS (UL 94 HB)
dusty gray RAL 7037
13x15mm 6mm



A2516040
ROUND KNOB 16, without line
ABS (UL 94 HB)
black RAL 9005
16x15mm 4mm



A2516060
ROUND KNOB 16, without line
ABS (UL 94 HB)
black RAL 9005
16x15mm 6mm



A2516068
ROUND KNOB 16, without line
ABS (UL 94 HB)
dusty gray RAL 7037
16x15mm 6mm



A2516630
ROUND KNOB 16, without line
ABS (UL 94 HB)
black RAL 9005
16x15mm 1/4"

COMBINATION KNOBS



A2516638
ROUND KNOB 16, without line
ABS (UL 94 HB)
dusty gray RAL 7037
16x15mm 1/4"



A2520040
ROUND KNOB 20, without line
ABS (UL 94 HB)
black RAL 9005
20x15mm 4mm



A2520060
ROUND KNOB 20, without line
ABS (UL 94 HB)
black RAL 9005
20x15mm 6mm



A2520068
ROUND KNOB 20, without line
ABS (UL 94 HB)
dusty gray RAL 7037
20x15mm 6mm



A2520630
ROUND KNOB 20, without line
ABS (UL 94 HB)
black RAL 9005
20x15mm 1/4"



A2523040
ROUND KNOB 23, without line
ABS (UL 94 HB)
black RAL 9005
23x15mm 4mm



A2523060
ROUND KNOB 23, without line
ABS (UL 94 HB)
black RAL 9005
23x15mm 6mm




A2523068
ROUND KNOB 23, without line
ABS (UL 94 HB)
dusty gray RAL 7037
23x15mm 6mm



A2523630
ROUND KNOB 23, without line
ABS (UL 94 HB)
black RAL 9005
23x15mm 1/4"



A2523638
ROUND KNOB 23, without line
ABS (UL 94 HB)
dusty gray RAL 7037
23x15mm 1/4"

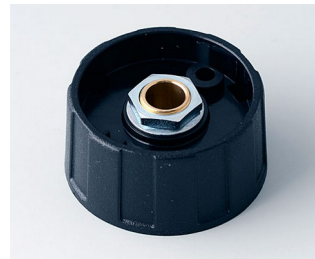

A2531060
ROUND KNOB 31, without line
ABS (UL 94 HB)
black RAL 9005
31x15mm 6mm



A2531068
ROUND KNOB 31, without line
ABS (UL 94 HB)
dusty gray RAL 7037
31x15mm 6mm



A2531630
ROUND KNOB 31, without line
ABS (UL 94 HB)
black RAL 9005
31x15mm 1/4"



A2540060
ROUND KNOB 40, without line
ABS (UL 94 HB)
black RAL 9005
40x15mm 6mm



A2540068
ROUND KNOB 40, without line
ABS (UL 94 HB)
dusty gray RAL 7037
40x15mm 6mm



A2540080
ROUND KNOB 40, without line
ABS (UL 94 HB)
black RAL 9005
40x15mm 8mm

COMBINATION KNOBS



A2550060
ROUND KNOB 50, without line
ABS (UL 94 HB)
black RAL 9005
50x15mm 6mm



A2550068
ROUND KNOB 50, without line
ABS (UL 94 HB)
dusty gray RAL 7037
50x15mm 6mm



A2609040
ROUND KNOB 9, with line
ABS (UL 94 HB)
black RAL 9005
9x14mm 4mm



A2610030
ROUND KNOB 10, with line
ABS (UL 94 HB)
black RAL 9005
10x14mm 3mm



A2610038
ROUND KNOB 10, with line
ABS (UL 94 HB)
dusty gray RAL 7037
10x14mm 3mm



A2610040
ROUND KNOB 10, with line
ABS (UL 94 HB)
black RAL 9005
10x14mm 4mm



A2610048
ROUND KNOB 10, with line
ABS (UL 94 HB)
dusty gray RAL 7037
10x14mm 4mm



A2610320
ROUND KNOB 10, with line
ABS (UL 94 HB)
black RAL 9005
10x14mm 1/8"



A2613040
ROUND KNOB 13.5, with line
ABS (UL 94 HB)
black RAL 9005
13x15mm 4mm



A2613048
ROUND KNOB 13.5, with line
ABS (UL 94 HB)
dusty gray RAL 7037
13x15mm 4mm



A2613060
ROUND KNOB 13.5, with line
ABS (UL 94 HB)
black RAL 9005
13x15mm 6mm



A2613068
ROUND KNOB 13.5, with line
ABS (UL 94 HB)
dusty gray RAL 7037
13x15mm 6mm



A2616040
ROUND KNOB 16, with line
ABS (UL 94 HB)
black RAL 9005
16x15mm 4mm



A2616060
ROUND KNOB 16, with line
ABS (UL 94 HB)
black RAL 9005
16x15mm 6mm



A2616068
ROUND KNOB 16, with line
ABS (UL 94 HB)
dusty gray RAL 7037
16x15mm 6mm



A2616630
ROUND KNOB 16, with line
ABS (UL 94 HB)
black RAL 9005
16x15mm 1/4"

COMBINATION KNOBS



A2620040
ROUND KNOB 20, with line
ABS (UL 94 HB)
black RAL 9005
20x15mm 4mm



A2620060
ROUND KNOB 20, with line
ABS (UL 94 HB)
black RAL 9005
20x15mm 6mm



A2620068
ROUND KNOB 20, with line
ABS (UL 94 HB)
dusty gray RAL 7037
20x15mm 6mm



A2623040
ROUND KNOB 23, with line
ABS (UL 94 HB)
black RAL 9005
23x15mm 4mm



A2623060
ROUND KNOB 23, with line
ABS (UL 94 HB)
black RAL 9005
23x15mm 6mm



A2623068
ROUND KNOB 23, with line
ABS (UL 94 HB)
dusty gray RAL 7037
23x15mm 6mm



A2631060
ROUND KNOB 31, with line
ABS (UL 94 HB)
black RAL 9005
31x15mm 6mm




A2631068
ROUND KNOB 31, with line
ABS (UL 94 HB)
dusty gray RAL 7037
31x15mm 6mm



A2640060
ROUND KNOB 40, with line
ABS (UL 94 HB)
black RAL 9005
40x15mm 6mm



A2640068
ROUND KNOB 40, with line
ABS (UL 94 HB)
dusty gray RAL 7037
40x15mm 6mm

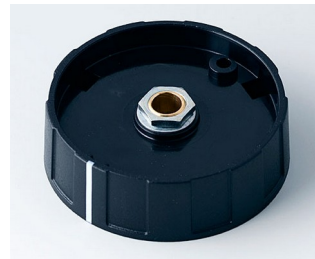

A2650060
ROUND KNOB 50, with line
ABS (UL 94 HB)
black RAL 9005
50x15mm 6mm



A2813060
WING KNOB 13.5, with line
ABS (UL 94 HB)
black RAL 9005
13x15mm 6mm



A2816060
WING KNOB 16, with line
ABS (UL 94 HB)
black RAL 9005
16x15mm 6mm

COMBINATION KNOBS

System components to complete



A4110000
Cover 10, without line
ABS (UL 94 HB)
black RAL 9005



A4110002
Cover 10, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4110004
Cover 10, without line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4110005
Cover 10, without line
ABS (UL 94 HB)
green RAL F12/0-43



A4110006
Cover 10, without line
ABS (UL 94 HB)
light blue RAL 5012



A4110007
Cover 10, without line
ABS (UL 94 HB)
pebble gray RAL 7032




A4110008
Cover 10, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4110100
Cover 10, with line
ABS (UL 94 HB)
black RAL 9005



A4110102
Cover 10, with line
ABS (UL 94 HB)
red RAL F12/0-10

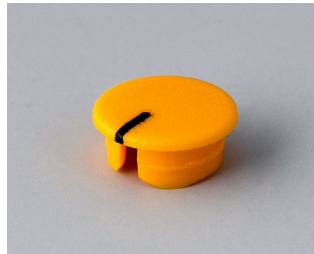

A4110104
Cover 10, with line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4110106
Cover 10, with line
ABS (UL 94 HB)
light blue RAL 5012



A4110108
Cover 10, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4113000
Cover 13.5, without line
ABS (UL 94 HB)
black RAL 9005



A4113002
Cover 13.5, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4113004
Cover 13.5, without line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4113005
Cover 13.5, without line
ABS (UL 94 HB)
green RAL F12/0-43

COMBINATION KNOBS



A4113006
Cover 13.5, without line
ABS (UL 94 HB)
light blue RAL 5012



A4113007
Cover 13.5, without line
ABS (UL 94 HB)
pebble gray RAL 7032



A4113008
Cover 13.5, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4113100
Cover 13.5, with line
ABS (UL 94 HB)
black RAL 9005



A4113102
Cover 13.5, with line
ABS (UL 94 HB)
red RAL F12/0-10



A4113104
Cover 13.5, with line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4113105
Cover 13.5, with line
ABS (UL 94 HB)
green RAL F12/0-43



A4113106
Cover 13.5, with line
ABS (UL 94 HB)
light blue RAL 5012



A4113107
Cover 13.5, with line
ABS (UL 94 HB)
pebble gray RAL 7032



A4113108
Cover 13.5, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4116000
Cover 16, without line
ABS (UL 94 HB)
black RAL 9005



A4116002
Cover 16, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4116004
Cover 16, without line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4116005
Cover 16, without line
ABS (UL 94 HB)
green RAL F12/0-43



A4116006
Cover 16, without line
ABS (UL 94 HB)
light blue RAL 5012



A4116007
Cover 16, without line
ABS (UL 94 HB)
pebble gray RAL 7032

COMBINATION KNOBS



A4116008
Cover 16, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4116100
Cover 16, with line
ABS (UL 94 HB)
black RAL 9005



A4116102
Cover 16, with line
ABS (UL 94 HB)
red RAL F12/0-10



A4116106
Cover 16, with line
ABS (UL 94 HB)
light blue RAL 5012



A4116107
Cover 16, with line
ABS (UL 94 HB)
pebble gray RAL 7032



A4116108
Cover 16, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4120000
Cover 20, without line
ABS (UL 94 HB)
black RAL 9005



A4120002
Cover 20, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4120005
Cover 20, without line
ABS (UL 94 HB)
green RAL F12/0-43



A4120006
Cover 20, without line
ABS (UL 94 HB)
light blue RAL 5012



A4120007
Cover 20, without line
ABS (UL 94 HB)
pebble gray RAL 7032



A4120008
Cover 20, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4120100
Cover 20, with line
ABS (UL 94 HB)
black RAL 9005



A4120102
Cover 20, with line
ABS (UL 94 HB)
red RAL F12/0-10



A4120104
Cover 20, with line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4120106
Cover 20, with line
ABS (UL 94 HB)
light blue RAL 5012

COMBINATION KNOBS



A4120107
Cover 20, with line
ABS (UL 94 HB)
pebble gray RAL 7032



A4120108
Cover 20, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4123000
Cover 23, without line
ABS (UL 94 HB)
black RAL 9005



A4123002
Cover 23, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4123004
Cover 23, without line
ABS (UL 94 HB)
yellow RAL F12/0-1



A4123006
Cover 23, without line
ABS (UL 94 HB)
light blue RAL 5012



A4123007
Cover 23, without line
ABS (UL 94 HB)
pebble gray RAL 7032



A4123008
Cover 23, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4123100
Cover 23, with line
ABS (UL 94 HB)
black RAL 9005



A4123102
Cover 23, with line
ABS (UL 94 HB)
red RAL F12/0-10



A4123105
Cover 23, with line
ABS (UL 94 HB)
green RAL F12/0-43



A4123106
Cover 23, with line
ABS (UL 94 HB)
light blue RAL 5012



A4123107
Cover 23, with line
ABS (UL 94 HB)
pebble gray RAL 7032



A4123108
Cover 23, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4131000
Cover 31, without line
ABS (UL 94 HB)
black RAL 9005



A4131002
Cover 31, without line
ABS (UL 94 HB)
red RAL F12/0-10

COMBINATION KNOBS



A4131005
Cover 31, without line
ABS (UL 94 HB)
green RAL F12/0-43



A4131006
Cover 31, without line
ABS (UL 94 HB)
light blue RAL 5012



A4131007
Cover 31, without line
ABS (UL 94 HB)
pebble gray RAL 7032



A4131008
Cover 31, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4131100
Cover 31, with line
ABS (UL 94 HB)
black RAL 9005



A4131102
Cover 31, with line
ABS (UL 94 HB)
red RAL F12/0-10



A4131108
Cover 31, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A4140000
Cover 40, without line
ABS (UL 94 HB)
black RAL 9005



A4140002
Cover 40, without line
ABS (UL 94 HB)
red RAL F12/0-10



A4140007
Cover 40, without line
ABS (UL 94 HB)
pebble gray RAL 7032



A4140008
Cover 40, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4140100
Cover 40, with line
ABS (UL 94 HB)
black RAL 9005



A4150000
Cover 50, without line
ABS (UL 94 HB)
black RAL 9005



A4150008
Cover 50, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A4150100
Cover 50, with line
ABS (UL 94 HB)
black RAL 9005



A4150107
Cover 50, with line
ABS (UL 94 HB)
pebble gray RAL 7032

COMBINATION KNOBS



A5016000
Cover 16, without line
ABS (UL 94 HB)
black RAL 9005



A5016100
Cover 16, with line
ABS (UL 94 HB)
black RAL 9005



A5016108
Cover 16, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A5023000
Cover 23, without line
ABS (UL 94 HB)
black RAL 9005



A5023008
Cover 23, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A5023100
Cover 23, with line
ABS (UL 94 HB)
black RAL 9005



A5023108
Cover 23, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A5031000
Cover 31, without line
ABS (UL 94 HB)
black RAL 9005



A5031008
Cover 31, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A5031100
Cover 31, with line
ABS (UL 94 HB)
black RAL 9005



A5031107
Cover 31, with line
ABS (UL 94 HB)
pebble gray RAL 7032



A5031108
Cover 31, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A5040000
Cover 40, without line
ABS (UL 94 HB)
black RAL 9005



A5040008
Cover 40, without line
ABS (UL 94 HB)
dusty gray RAL 7037




A5040100
Cover 40, with line
ABS (UL 94 HB)
black RAL 9005



A5040108
Cover 40, with line
ABS (UL 94 HB)
dusty gray RAL 7037

COMBINATION KNOBS


Accessory "screws"

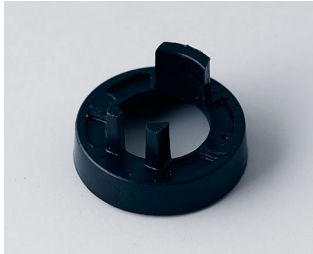

A5116000
Nut cover 16, without line
ABS (UL 94 HB)
black RAL 9005




A5123000
Nut cover 23, without line
ABS (UL 94 HB)
black RAL 9005

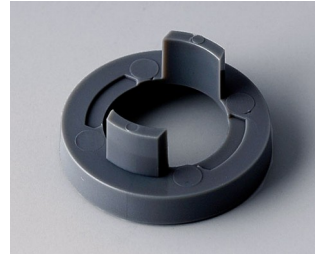


A5123008
Nut cover 23, without line
ABS (UL 94 HB)
dusty gray RAL 7037



A5131000
Nut cover 31, without line
ABS (UL 94 HB)
black RAL 9005

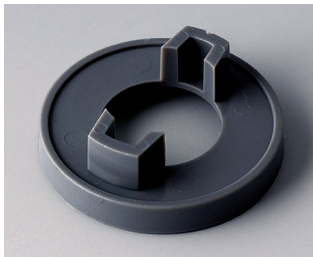

A5131008
Nut cover 31, without line
ABS (UL 94 HB)
dusty gray RAL 7037

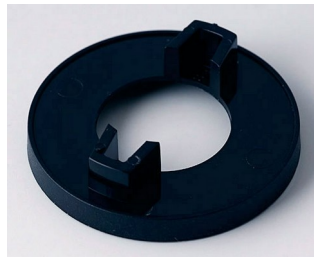

A5140000
Nut cover 40, without line
ABS (UL 94 HB)
black RAL 9005



A6207009
Round nut M7 x 0.75



A6210009
Round nut M10 x 0.75



A6295009
Round nut 3/8"-32G



A6300000
Spanner



A7510000
Nut cover 10, without line
ABS (UL 94 HB)
black RAL 9005



A7510010
Nut cover 10, with line
ABS (UL 94 HB)
black RAL 9005



A7510018
Nut cover 10, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A7513000
Nut cover 13.5, without line
ABS (UL 94 HB)
black RAL 9005



A7513010
Nut cover 13.5, with line
ABS (UL 94 HB)
black RAL 9005



A7513018
Nut cover 13.5, with line
ABS (UL 94 HB)
dusty gray RAL 7037

COMBINATION KNOBS



A7516000
Nut cover 16, without line
ABS (UL 94 HB)
black RAL 9005



A7516010
Nut cover 16, with line
ABS (UL 94 HB)
black RAL 9005



A7516018
Nut cover 16, with line
ABS (UL 94 HB)
dusty gray RAL 7037



A7616000
Nut cover 16, without line
ABS (UL 94 HB)
black RAL 9005



A7616008
Nut cover 16, without line
ABS (UL 94 HB)
dusty gray RAL 7037

Accessory



A4210000
Arrow disk 10
ABS (UL 94 HB)
black RAL 9005



A4210002
Arrow disk 10
ABS (UL 94 HB)
red RAL F12/0-10



A4210008
Arrow disk 10
ABS (UL 94 HB)
dusty gray RAL 7037



A4213000
Arrow disk 13.5
ABS (UL 94 HB)
black RAL 9005



A4213002
Arrow disk 13.5
ABS (UL 94 HB)
red RAL F12/0-10



A4213008
Arrow disk 13.5
ABS (UL 94 HB)
dusty gray RAL 7037



A4216000
Arrow disk 16
ABS (UL 94 HB)
black RAL 9005



A4216002
Arrow disk 16
ABS (UL 94 HB)
red RAL F12/0-10


COMBINATION KNOBS




A4216008
Arrow disk 16
ABS (UL 94 HB)
dusty gray RAL 7037



A4220000
Arrow disk 20
ABS (UL 94 HB)
black RAL 9005

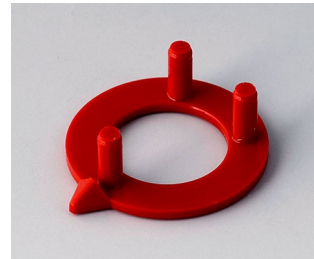

A4220002
Arrow disk 20
ABS (UL 94 HB)
red RAL F12/0-10

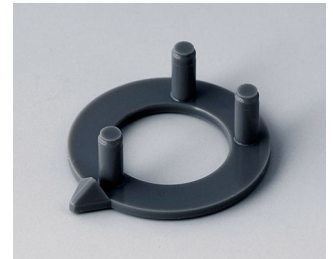

A4220008
Arrow disk 20
ABS (UL 94 HB)
dusty gray RAL 7037



A4223000
Arrow disk 23
ABS (UL 94 HB)
black RAL 9005



A4223002
Arrow disk 23
ABS (UL 94 HB)
red RAL F12/0-10



A4223008
Arrow disk 23
ABS (UL 94 HB)
dusty gray RAL 7037



A4231000
Arrow disk 31
ABS (UL 94 HB)
black RAL 9005




A4231002
Arrow disk 31
ABS (UL 94 HB)
red RAL F12/0-10



A4231008
Arrow disk 31
ABS (UL 94 HB)
dusty gray RAL 7037



A4240000
Arrow disk 40
ABS (UL 94 HB)
black RAL 9005

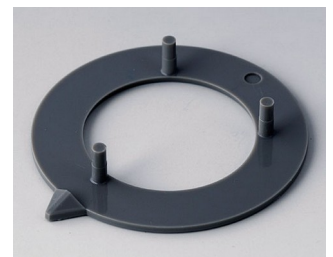

A4240008
Arrow disk 40
ABS (UL 94 HB)
dusty gray RAL 7037



A4410060
Dial 10
PC (UL 94 HB)
transparent



A4413010
Dial 13.5
PC (UL 94 HB)
transparent




A4413020
Dial 13.5
PC (UL 94 HB)
transparent



A4413049
Dial 13.5
PC (UL 94 HB)
transparent


COMBINATION KNOBS

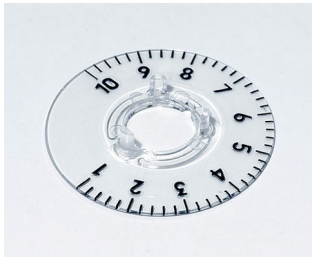

A4413060
Dial 13.5
PC (UL 94 HB)
transparent



A4416001
Dial 16
PC (UL 94 HB)
transparent

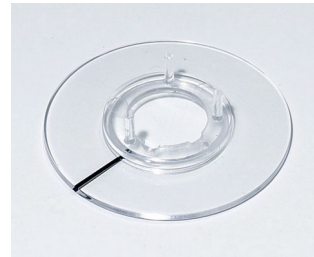

A4416010
Dial 16
PC (UL 94 HB)
transparent




A4416020
Dial 16
PC (UL 94 HB)
transparent




A4416060
Dial 16
PC (UL 94 HB)
transparent




A4420001
Dial 20
PC (UL 94 HB)
transparent

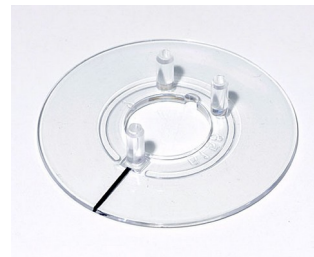

A4420010
Dial 20
PC (UL 94 HB)
transparent

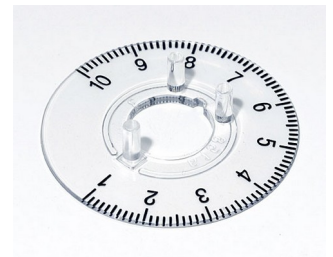

A4420060
Dial 20
PC (UL 94 HB)
transparent

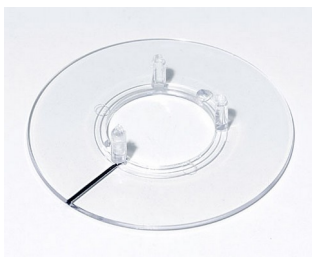


A4423010
Dial 23
PC (UL 94 HB)
transparent




A4423020
Dial 23
PC (UL 94 HB)
transparent




A4423039
Dial 23
PC (UL 94 HB)
transparent

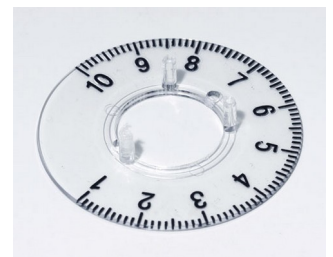


A4423060
Dial 23
PC (UL 94 HB)
transparent

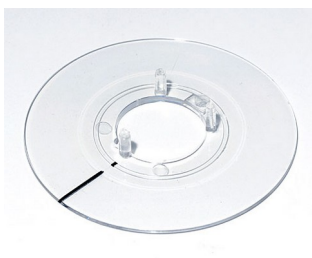


A4431010
Dial 31
PC (UL 94 HB)
transparent

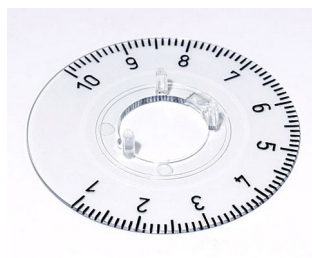

A4431060
Dial 31
PC (UL 94 HB)
transparent

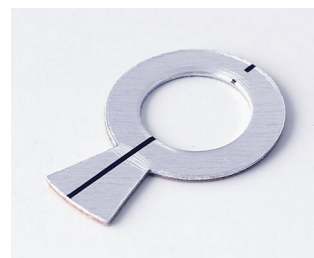

A6016019
Stator 16
Aluminum

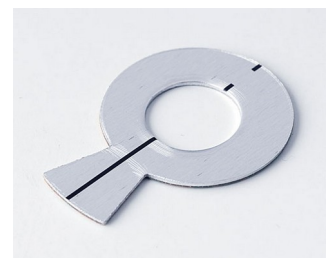

A6020019
Stator 20
Aluminum

COMBINATION KNOBS




A6023019
Stator 23
Aluminum



A6402005
Adjusting key 10/13/16
ABS (UL 94 HB)
green



A6403005
Adjusting key 20/23/31
ABS (UL 94 HB)
green

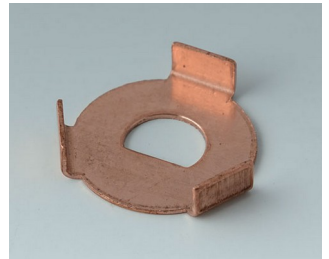

A6600064
Torsion protection 6/4.6



A7316000
Disk 16, without line
ABS (UL 94 HB)
black RAL 9005



A7316010
Disk 16, with line
ABS (UL 94 HB)
black RAL 9005



A7323010
Disk 23, with line
ABS (UL 94 HB)
black RAL 9005



A7331000
Disk 31, without line
ABS (UL 94 HB)
black RAL 9005



A7331010
Disk 31, with line
ABS (UL 94 HB)
black RAL 9005



A7340010
Disk 40, with line
ABS (UL 94 HB)
black RAL 9005

Subject to technical modification without notice. © by OKW Gehäusesysteme, Buchen/Germany.