


Part Number : 191150015

Product Description : Avikrimp Snap Spade Terminal for 22-18 AWG Wire, Tape and Reel, Stud Size 10 (M5)

Series Number : 19115

Status : Active

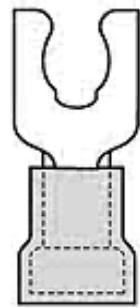

Product Category : Ring and Spade Terminals

Engineering Number : AA-8715-10T

Documents & Resources

Drawings

191150015_sd.pdf

3D Models and Design Files

STEP AP242

SOLIDWORKS

Creo

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	ⓘ per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19115
Description	Avikrimp Snap Spade Terminal for 22-18 AWG Wire, Tape and Reel, Stud Size 10 (M5)
Keyword	Spade Terminal, Spade Terminals
Product Name	Avikrimp
Style	Spade Snap
Type	Spade Connector
UPC	800753091979

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.853/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm

Stud Size	10 (M5)
Wire Size (AWG)	18, 20, 22

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880023</u>
Mini-Mac Pneumatic Applicator for Ring and Spade Terminals, 22-18 AWG	<u>638851300</u>

This document was generated on Sep 16, 2025