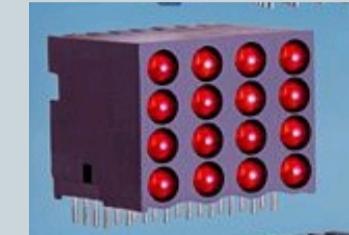


Part Number: **56822323234F****General Description**

Series	568
Configuration	3 mm Lens
Description	3 mm 4X4 Backlighting G - Y-G-Y
Package Options	Bulk Packaging
Sizes	3mm
Lamp Type	Quad Level Housing
Viewing	Right Angle
Polarity	Cathode Right
Lens Style	Tinted, Non -Diffused
Viewing Angle	45
LED Centerline	2.54mm

**56822323234F****check stock** 

This is a
RoHS Compliant Product
[To learn more click here](#)

Absolute Maximum Ratings (Ta = 25°)

Solder Temperature	260 for 5 secs
Operating Temperature	-55 to +100
Storage Temperature	-55 to +100

Operating Characteristics

	LED Position: 1,3	LED Position: 2,4
Color	Green	Yellow
LED Type	High Efficiency	High Efficiency
Peak Wave Length	565	585
Luminous Intensity Min	32	10
Luminous Intensity Typical	50	
Forward Voltage Typical	2.1	2.1
Forward Voltage Max	2.8	2.8
Power Dissipation Max	100mW	60mW