


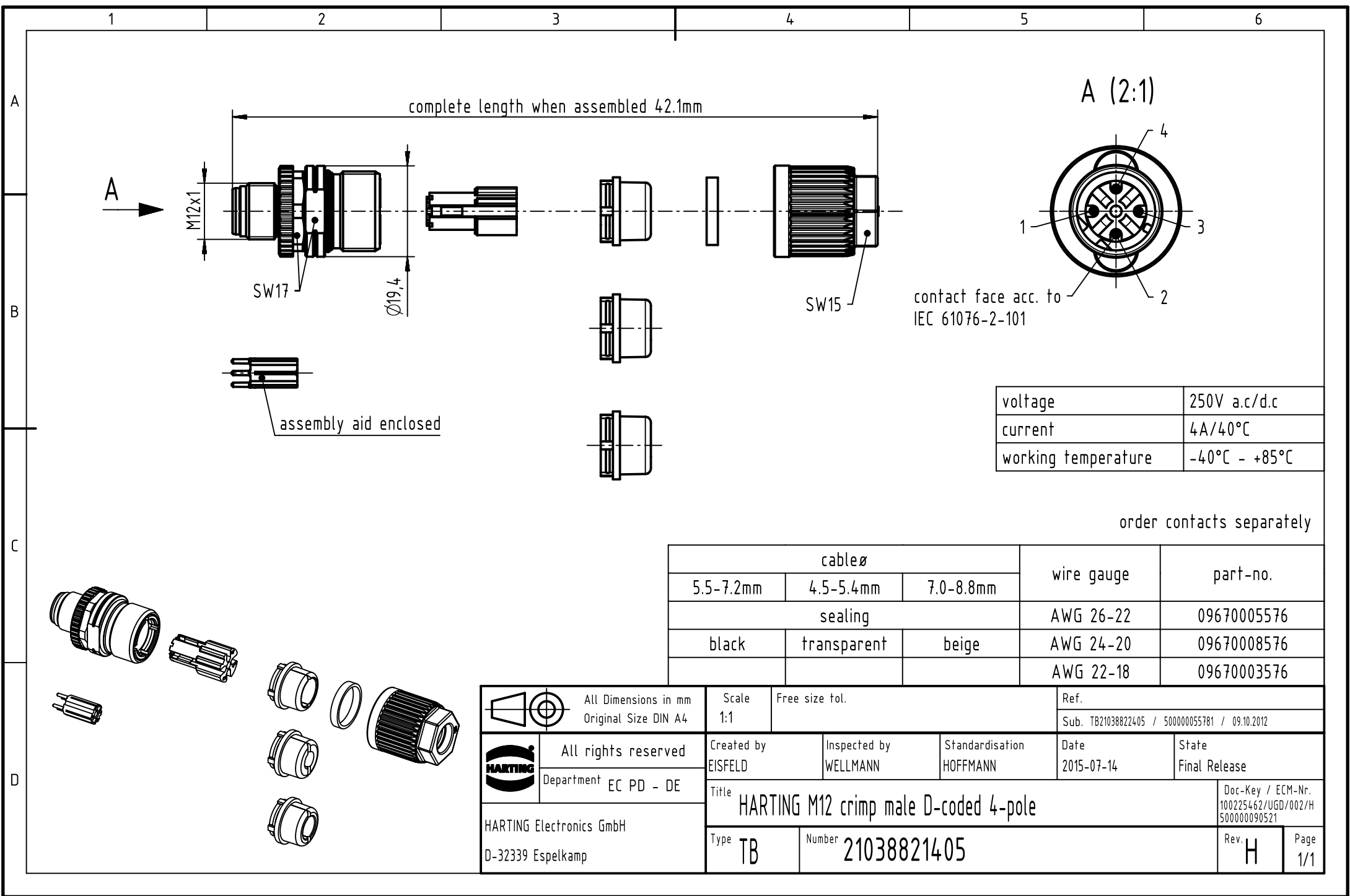

voltage	250V a.c/d.c
current	4A/40°C
working temperature	-40°C - +85°C

order contacts separately

cableø			wire gauge	part-no.
5.5-7.2mm	4.5-5.4mm	7.0-8.8mm		
sealing			AWG 26-22	09670005576
black	transparent	beige	AWG 24-20	09670008576
			AWG 22-18	09670003576

		All Dimensions in mm Original Size DIN A4		Scale 1:1		Free size tol.		Ref.					
								Sub. TB21038822405 / 500000055781 / 09.10.2012					
		All rights reserved		Created by EISFELD		Inspected by WELLMANN		Standardisation HOFFMANN		Date 2015-07-14		State Final Release	
		Department EC PD - DE											
HARTING Electronics GmbH D-32339 Espelkamp				Title HARTING M12 crimp male D-coded 4-pole								Doc-Key / ECM-Nr. 100225462/UGD/002/H 500000090521	
				Type TB		Number 21038821405						Rev. H	