



World Wide [Change](#)


[Home](#) [Products](#) [Support](#) [Service](#) [Selectors](#) [How to Buy](#)

Symmetra PX

Symmetra PX 80kW Static Switch Module, 400V

SYSW80KH

[Add Options](#)

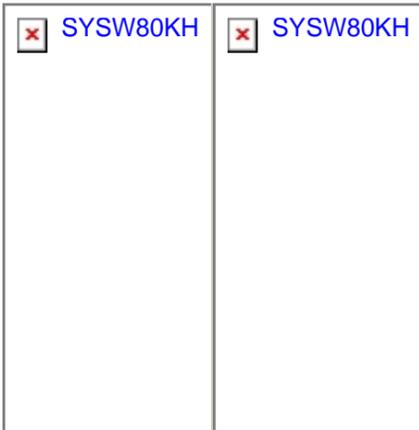

APC Symmetra PX, 80 kW / 80 kVA, Input 400V 3PH / Output 230V, 400V 3PH

[Runtime Chart](#)

[Email Technical Specification](#)

[Printer Friendly](#)

[More Images](#)

[Technical Specifications](#) [Product Overview](#) [Compare Models](#)

Output

Output Power Capacity
80 kW / 80 kVA
Max Configurable Power
80 kW / 80 kVA
Nominal Output Voltage
230V, 400V 3PH

Input

Nominal Input Voltage
400V 3PH
Input Frequency
50/60 Hz

Physical

Maximum Height
413.00 mm
Maximum Width
483.00 mm
Maximum depth
394.00 mm
Net Weight
35.00 KG
Shipping Weight
38.50 KG
Shipping Height
536.00 mm
Shipping Width
551.00 mm
Shipping Depth
616.00 mm
Color
Black

Environmental

Operating Environment
0 - 40 °C
Operating Relative Humidity
0 - 95%
Operating Elevation
0-3000 meters
Storage Temperature
-25 - 65 °C
Storage Relative Humidity
0 - 95%
Storage Elevation
0-15000 meters
Audible noise at 1 meter from surface of unit
0.00 dBA
Protection Class
IP 20