


Amphenol® RF

PRODUCTS

AMPHENOL RF PART NUMBER

082-811

N-Type Straight Solder Jack, Solder Cup, Hermetic Seal, Bulkhead, 50 Ohm

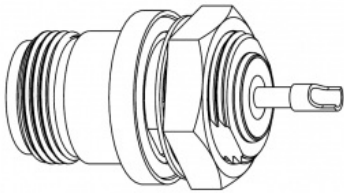

FIND STOCK & BUY NOW

ADD TO COMPARE

ADD TO PART LIST

PRODUCT OVERVIEW

RF Connector, N-Type Straight Solder Jack, Solder Cup, Hermetic Seal, Bulkhead, 50 Ohm

Product Type	Connectors
Product Series	N-Type
Status	Active

DOWNLOADS

 [082-811 Customer Drawing](#) (Size: 105.3 KB)

PRODUCT SPECIFICATIONS

Brand	Amphenol RF
Gender	Jack
Orientation	Straight
Termination Style	Solder Cup
Impedance (Ohms)	50
Body Finish	Nickel
Body Material	Brass
Contact Finish	Silver
Contact Material	Beryllium Copper
Contact Termination Style	Solder
Insulator Material	Glass
Coupling Mechanism	Threaded
Mounting Feature	Bulkhead - Front Mount
IP Rating	Hermetic
Max Frequency (GHz)	11
Polarity	Standard
Thread Direction	Standard
Min. Temp. (Celsius)	-65

Max. Temp. (Celsius)	200
Mating Cycles	500

PRODUCT COMPLIANCE

Product compliance documentation, if available is listed below:

RoHS 2 (EU)	Compliant with Exemption 6C - View Certificate
-------------	--

Additional compliance information is available in our [Product Compliance Center](#).

FOLLOW US

NEWSLETTER

AMPHENOL RF

QUICK LINKS

CONTACT US

Copyright © 2014 Amphenol RF. All Rights Reserved.
[Copyright](#) | [Terms & Conditions](#) | [Privacy Policy](#) | [Logos](#) | [Amphenol.com](#)