

CV61 Configurations



All CV61 standard configurations are available with the following components:

- Intel® Atom D425 1.8 GHz
- Up to 3GB RAM
- 40GB solid-state disk
- 802.11 a/b/g/n radio, CCX v4
- Bluetooth 2.0 + EDR Class 1.5 (30m range)
- Microsoft Windows XP Pro or Windows 7 Pro
- Optional Intermec Client Pack software
 - Intermec Terminal Emulator (ITE)
 - Intermec Browser
- Standard or heated display for freezer environments



The first *voice-enabled* rugged vehicle mount computer running Microsoft Windows XP or 7 and VoiceCatalyst!

- Voice-enabled workflows are proven to improve safety and productivity
- Forklift operators can simply talk, listen and act—keeping focused on the task at hand
- Vocollect Voice can be integrated across your entire enterprise, including all forklift applications



CV61 Models

Windows XP

Windows 7

CV61 with Standard Display
(1GB RAM)
(2GB RAM)
(3GB RAM)

CV61A11XPAN80000 (1GB RAM)
CV61A12XPAN80000 (2GB RAM)
CV61A13XPAN80000 (3GB RAM)

CV61A127MAN80000 (2GB RAM)
CV61A137MAN80000 (3GB RAM)

CV61 with Heated Display
(1GB RAM)
(2GB RAM)
(3GB RAM)

CV61A21XPAN80000 (1GB RAM)
CV61A22XPAN80000 (2GB RAM)
CV61A23XPAN80000 (3GB RAM)

CV61A227MAN80000 (2GB RAM)
CV61A237MAN80000 (3GB RAM)

Intermec Medallion Service

MEDV1-GLD-3	Gold plan, 3 years, with 2-day on-site standard
MEDV1-SLV-3-C	Silver plan, 3 years, with 2-day return to depot
MEDV1-BRZ-3-C	Bronze plan, 3 years, with 5-day return to depot

Intermec Client Pack Software Maintenance



454-023-001	License, Intermec Client Pack
ICP-SFT1	One-year maintenance subscription for Intermec Client Pack
ICP-SFT3	Three-year maintenance subscription for Intermec Client Pack

CV61 Forklift Install with Tethered Scanner


Option 1 – Direct to Battery
9-60V DC + SR61T



	Part Number	Description
OR	1 CV61A11XPAN80000	CV61 with Standard Touchscreen, 1GB RAM, Windows XP, Multilingual (Worldwide)
	CV61A127MAN80000	CV61 with Standard Touchscreen, 2GB RAM, Windows 7, Multilingual (Worldwide)
	2 203-956-001	Vehicle Mounting Kit with Extra-Duty Stubby RAM Mount (Includes CV61 Backplate, 5" Arm, 2x 3.375" Balls)
	3 203-950-001	Direct Wiring Kit (For Use with 6-60V DC Trucks to CV61 DC/DC Input--NOT For Use with Heated Touchscreen Models)
	4 SR61TXR-SER001	SR61TXR (EX25) Serial Scanner Kit (includes Scanner & 236-184-001 RS232 Serial Cable, Power from Host)
	5a 203-876-002	SR61 Wall Mount or Vehicle Mount Holder
OR	5b 825-181-001	SR61 Dangle Suspension
	6 G9A-KB001-02	Keyboard Mounting Kit for CV61 (Tray Mount Attaches Directly to CV61; Full Swivel; Compatible with All Rugged Keyboards)
	7 340-053-003	Rugged 101-Key Windows Keyboard (PS/2, Windows Layout)

CV61 Forklift Install with Tethered Scanner

Option 2 – DC/DC converter
Varying DC + SR61T

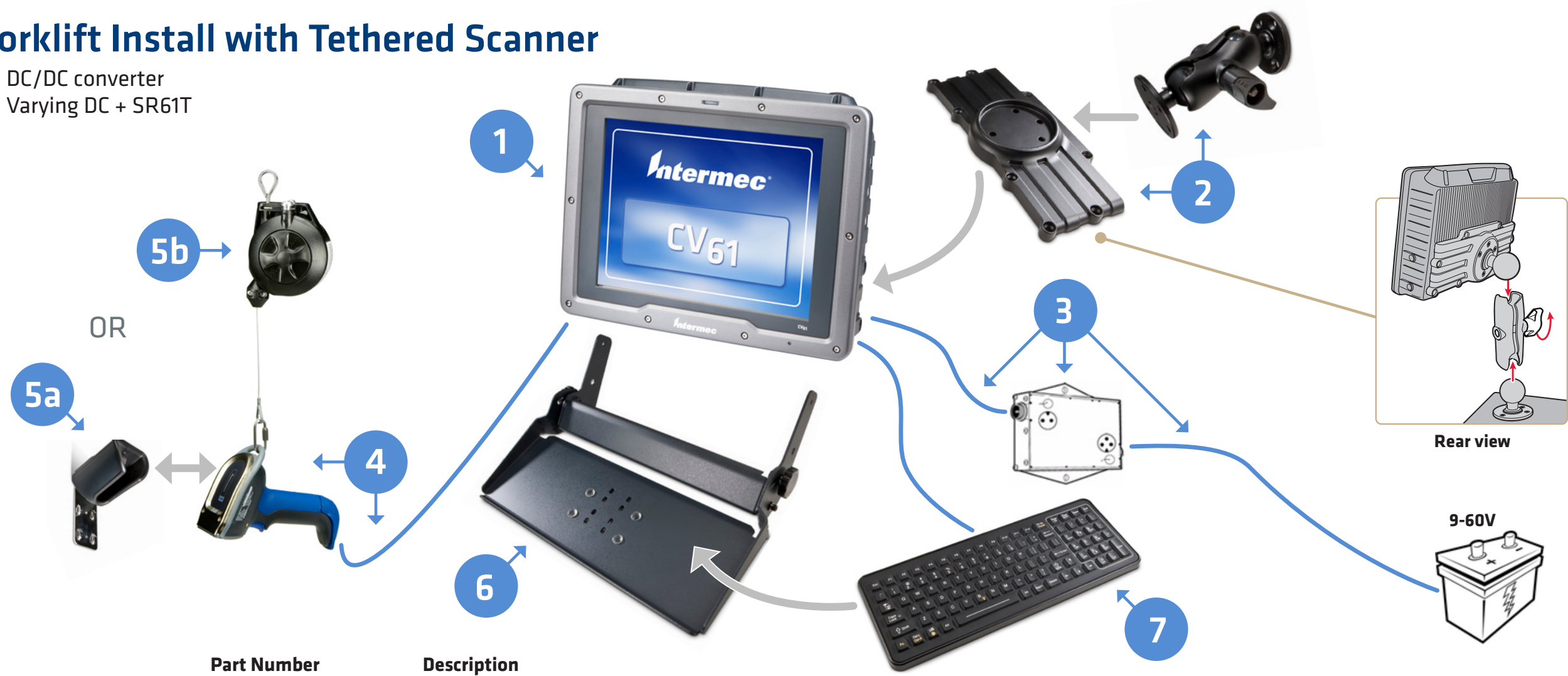

	Part Number	Description
OR	1 CV61A11XPAN80000	CV61 with Standard Touchscreen, 1GB RAM, Windows XP, Multilingual (Worldwide)
	CV61A127MAN80000	CV61 with Standard Touchscreen, 2GB RAM, Windows 7, Multilingual (Worldwide)
	2 203-956-001	Vehicle Mounting Kit with Extra-Duty Stubby RAM Mount (Includes CV61 Backplate, 5" Arm, 2x 3.375" Balls)
	3 203-779-001	DC/DC Converter Kit, 6-60V DC (Requires VE027-8024-C0; Converts CV60 5-Pin Power Output Cables to CV61 6-Pin Input)
OR	203-780-001	DC/DC Converter Kit, 15-96V DC (Requires VE027-8024-C0; Converts CV60 5-Pin Power Output Cables to CV61 6-Pin Input)
AND	VE027-8024-C0	Cable, 5-Pin Male to 6-Pin Female
	4 SR61TXR-SER001	SR61TXR (EX25) Serial Scanner Kit (includes Scanner & 236-184-001 RS232 Serial Cable, Power from Host)
	5a 203-876-002	SR61 Wall Mount or Vehicle Mount Holder
OR	5b 825-181-001	SR61 Dangle Suspension
	6 G9A-KB001-02	Keyboard Mounting Kit for CV61 (Tray Mount Attaches Directly to CV61; Full Swivel; Compatible with All Rugged Keyboards)
	7 340-053-003	Rugged 101-Key Windows Keyboard (PS/2, Windows Layout)

CV61 Forklift Install with Tethered Scanner

Option 3 – Cold Temperature (-30°C)
Varying DC + SR61T



	Part Number	Description
OR	1 CV61A21XPAN80000	CV61 with Heated Touchscreen, 1GB RAM, Windows XP, Multilingual (Worldwide)
	CV61A227MAN80000	CV61 with Heated Touchscreen, 2GB RAM, Windows 7, Multilingual (Worldwide)
2	203-956-001	Vehicle Mounting Kit with Extra-Duty Stubby RAM Mount (Includes CV61 Backplate, 5" Arm, 2x 3.375" Balls)
OR	3 203-779-001	DC/DC Converter Kit, 6-60V DC (Requires VE027-8024-C0; Converts CV60 5-Pin Power Output Cables to CV61 6-Pin Input)
	203-780-001	DC/DC Converter Kit, 15-96V DC (Requires VE027-8024-C0; Converts CV60 5-Pin Power Output Cables to CV61 6-Pin Input)
AND	VE027-8024-C0	Cable, 5-Pin Male to 6-Pin Female
4	SR61TXR-SER001	SR61TXR (EX25) Serial Scanner Kit (includes Scanner & 236-184-001 RS232 Serial Cable, Power from Host)
5	520-3648-N3	Thermotrax Scanner Heater for 155X
6	G9A-KB001-02	Keyboard Mounting Kit for CV61 (Tray Mount Attaches Directly to CV61; Full Swivel; Compatible with All Rugged Keyboards)
7	340-054-102	Extreme Temperature Rugged Keyboard (DB15/USB, Windows Layout)

CV61 Desktop Install


Standard AC Power Connection



	Part Number	Description
OR	1 CV61A11XPAN80000	CV61 with Standard Touchscreen, 1GB RAM, Windows XP, Multilingual (Worldwide)
	CV61A127MAN80000	CV61 with Standard Touchscreen, 2GB RAM, Windows 7, Multilingual (Worldwide)
	2 203-954-001	Desktop Mounting Kit (Includes CV61 Backplate, 2x 2.25" Balls, 5" Arm, Weighted Metal Table Stand)
	3 203-955-001	AC Wall Charger, US and International
	4 AC Cord	See Page 7 for Country Specific AC Cord
Optional	5 SG20THP-USB501	SG20 (EA30) USB Scanner Kit (Includes Scanner, USB Cable and Adjustable Stand)
Optional	6 VE011-2017	Breakout Cable, Dual-USB (Breakout Y-Cable Adapter to Dual-USB Type A Host Connectors; REQUIRED for CV61 USB Connections)

CV61 I/O Connectors

Available Connections on the CV61

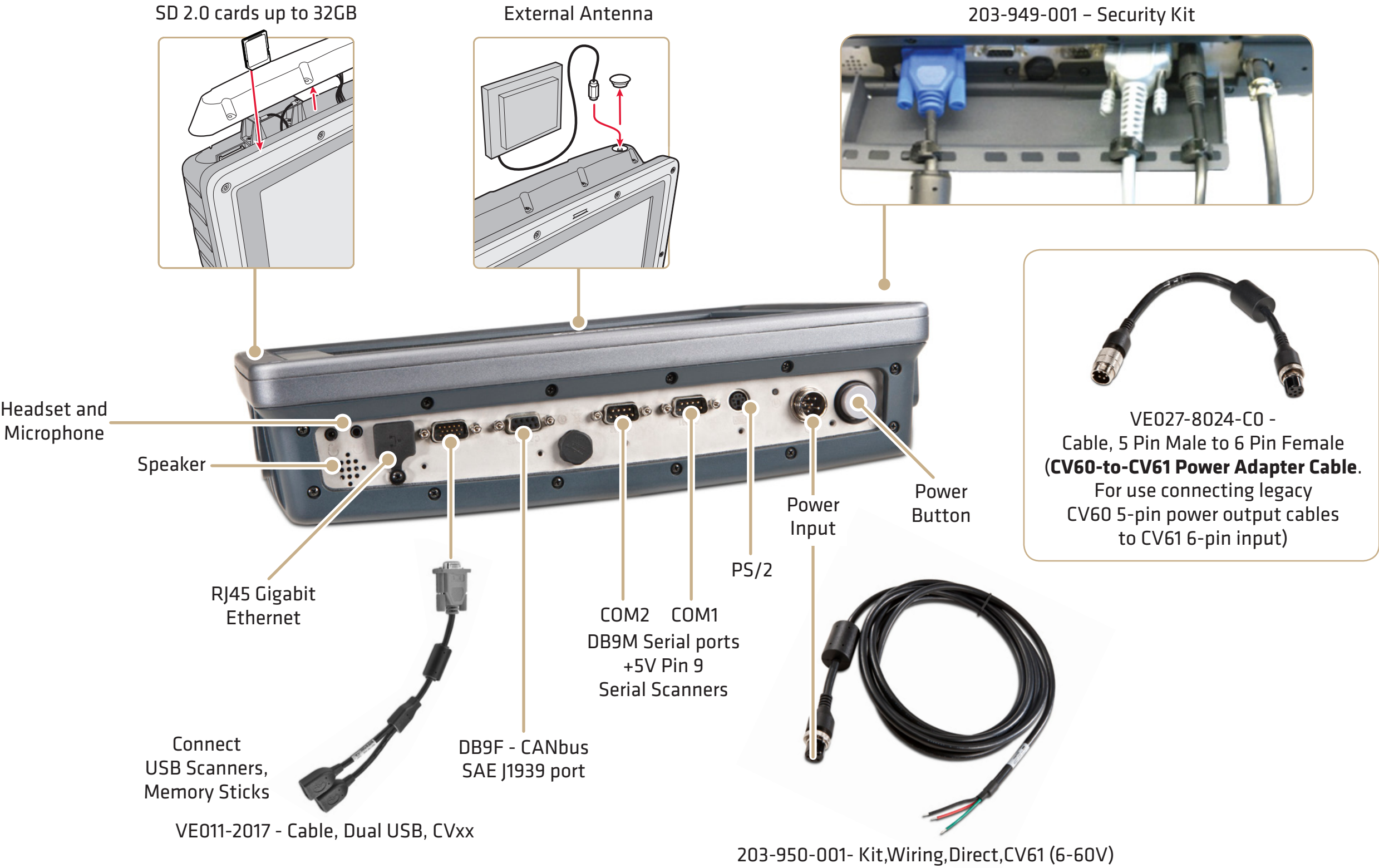

Miscellaneous

Other Accessories

Part Number	Description
805-662-001	External antenna, 802.11 a/b/g dual band (2.4 and 5.0 GHz), sealed with remote mount. Compatible with 802.11 infrastructure. RoHS compliant.
	
805-552-002	Omnidirectional antenna, single band (2.4 GHz), with remote mount. Supports 802.11 b/g/n only (does not support 5.0 GHz 802.11a). Features 3dB gain and wider coverage cone.
	
203-958-001	Memory upgrade kit, adds 1GB additional RAM to CV61 base unit for a total of 2GB RAM. User installable 1GB DDR2 SODIMM module.
	
203-958-002	Memory upgrade kit, adds 2GB additional RAM to CV61 base unit for a total of 3GB RAM. User installable 2GB DDR2 SODIMM module.
	

AC Cords



Part Number	Description
1-974030-025	AC Power Cord, Australia (RoHS)
71918	AC Power Cord, China (RoHS)
321-501-002	AC Power Cord, Denmark (RoHS)
1-974027-025	AC Power Cord, Europe (RoHS)
321-502-002	AC Power Cord, India & South Africa (RoHS)
321-471-002	AC Power Cord, Italy (RoHS)
321-500-002	AC Power Cord, Japan (RoHS)
1-974029-020	AC Power Cord, UK (RoHS)
1-974028-025	AC Power Cord, US (RoHS)