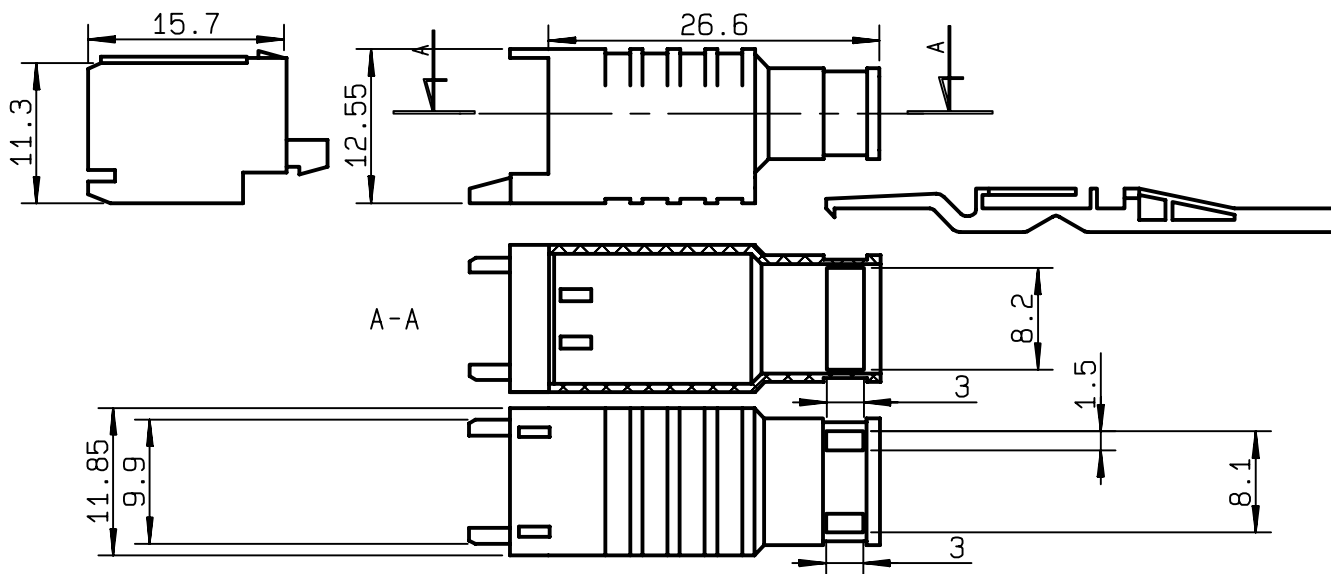


**CABLE ASSEMBLY KIT= COVER + LATCH
+ HOUSING PACK. 100**
R280.420.058
SERIES ACC-COAX


NOMINAL IMPEDANCE	NA	Ω
FREQUENCY RANGE	NA	GHz
TEMPERATURE RATING	-25/+125	$^{\circ}\text{C}$
V.S.W.R	NA +	x F(GHz)Maxi
RF INSERTION LOSS	NA	$\sqrt{F}(\text{GHz})$ dB Maxi
VOLTAGE RATING	NA	Veff Maxi
DIELECTRIC WITHSTANDING VOLTAGE	NA	Veff Mini
INSULATION RESISTANCE	NA	M Ω Mini
HERMETIC SEAL	NA	Atm.cm ³ /s
LEAKAGE (pressurized only)	NA	
MECHANICAL DURABILITY		Cycles
WEIGHT	3.2	gr
SPECIFICATION		

CABLES :

OTHERS CHARACTERISTICS

CABLE RETENTION	NA	N Mini
CENTER CONTACT RETENTION		
Axial force - mating end	NA	N Mini
Axial force - opposite end	NA	N Mini
Torque	NA	cm.N Mini
RECOMMENDED TORQUES		
Mating	NA	cm.N
Panel nut	NA	cm.N
Clamp nut	NA	cm.N

CONNECTOR PARTS	MATERIALS	FINISH	(all values are given) in micrometers
BODY			
OUTER CONTACT			
CENTER CONTACT			
INSULATOR	LIQUID CRISTAL POLYMER	-	
GASKET		-	
OTHERS PIECES	POLYAMID 6/6 (NYLON)		

BAFFERT

 ISSUE
 0234B00

 CREATION DATE
 04/05/1998

 FILE PART-NUMBER
 EPC 95-08

RADIALL®

 The information given here is subject to change without notice.
 Design changes may be in order to improve the product .

Connect to the future