


FLEXIMARK® Organized shrink tube

FLEXIMARK® Organized Shrink Tube are pre-cutted shrink tubes for wire and cable marking. Also available as diesel-resistant and halogen-free version.

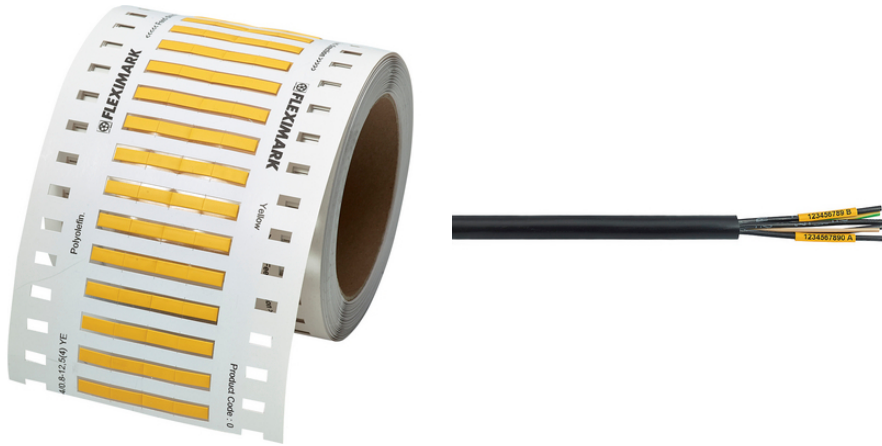

Mechanical and plant engineering



Rail



Wind Energy



Halogen-free



Assembly time



Space requirement

Benefits

Reduced working time
Already cut to the exact length

Application range

Covers a wide range of cable diameters, even applicable for single core marking

Norm references / Approvals

Not halogen-free version: UL 224 certified

Note

Easy to print via FLEXIMARK® software Flexisoft and FLEXIMARK® thermal transfer printer SQUIX, EOS5 or EOS2
Recommended ribbon: FTI-X 60-300 BK (article no. 83260206)

Included

Delivered as a roll of labels

Last Update (17.11.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03.16

FLEXIMARK® Organized shrink tube

Technical Data

Classification ETIM 5:	ETIM 5.0 Class-ID: EC001288 ETIM 5.0 Class-Description: Labelling material
Classification ETIM 6:	ETIM 6.0 Class-ID: EC001288 ETIM 6.0 Class-Description: Labelling material
On request:	Also available as diesel-resistant version (with SNCF-NF F00-608 approval)
Colour delivered:	Standard colour: Yellow Also available in white
Material:	Polyolefin Shrink ratio: Halogen-free version: 2:1 Not halogen-free version: 3:1
Temperature range:	Halogen-free version: -55 °C to +105 °C Not halogen-free Version: -55 °C to +135 °C Shrinking temperature: +90 °C

Note

Photographs and graphics are not to scale and do not represent detailed images of the respective products.
Prices are net prices without VAT and surcharges. Sale to business customers only.
FLEXIMARK® products are sold in packaging units. As example if you like to order 640 labels of LCK 32 you just need to order 1 PU instead of 640 single labels.

FLEXIMARK® Organized shrink tube

Article number	Article designation	Colour	Shrinkage range (mm)	Length (mm)	Markers / PU	PU
Halogen-free						
83260225	FLEXIMARK® O.shr 2.4/1.2-12.5 YE	yellow	1.2 - 2.4	12.5	4000	1
83260228	FLEXIMARK® O.shr 2.4/1.2-16.6 YE	yellow	1.2 - 2.4	16.6	3000	1
83260100	FLEXIMARK® O.shr 2.4/1.2-25 YE	yellow	1.2 - 2.4	25.0	2000	1
83260090	FLEXIMARK® O.shr 2.4/1.2-38 YE	yellow	1.2 - 2.4	38.0	1000	1
83260080	FLEXIMARK® O.shr 2.4/1.2-50 YE	yellow	1.2 - 2.4	50.0	1000	1
83260226	FLEXIMARK® O.shr 3.2/1.6-12.5 YE	yellow	1.6 - 3.2	12.5	4000	1
83260229	FLEXIMARK® O.shr 3.2/1.6-16.6 YE	yellow	1.6 - 3.2	16.6	3000	1
83260101	FLEXIMARK® O.shr 3.2/1.6-25 YE	yellow	1.6 - 3.2	25.0	2000	1
83260091	FLEXIMARK® O.shr 3.2/1.6-38 YE	yellow	1.6 - 3.2	38.0	1000	1
83260081	FLEXIMARK® O.shr 3.2/1.6-50 YE	yellow	1.6 - 3.2	50.0	1000	1
83260227	FLEXIMARK® O.shr 4.8/2.4-12.5 YE	yellow	2.4 - 4.8	12.5	4000	1
83260230	FLEXIMARK® O.shr 4.8/2.4-16.6 YE	yellow	2.4 - 4.8	16.6	3000	1
83260102	FLEXIMARK® O.shr 4.8/2.4-25 YE	yellow	2.4 - 4.8	25.0	2000	1
83260092	FLEXIMARK® O.shr 4.8/2.4-38 YE	yellow	2.4 - 4.8	38.0	1000	1
83260082	FLEXIMARK® O.shr 4.8/2.4-50 YE	yellow	2.4 - 4.8	50.0	1000	1
83260103	FLEXIMARK® O.shr 6.4/3.2-25 YE	yellow	3.2 - 6.4	25.0	2000	1
83260093	FLEXIMARK® O.shr 6.4/3.2-38 YE	yellow	3.2 - 6.4	38.0	1000	1
83260083	FLEXIMARK® O.shr 6.4/3.2-50 YE	yellow	3.2 - 6.4	50.0	1000	1
83260104	FLEXIMARK® O.shr 9.5/4.8-25 YE	yellow	4.8 - 9.5	25.0	1000	1
83260094	FLEXIMARK® O.shr 9.5/4.8-38 YE	yellow	4.8 - 9.5	38.0	500	1

Last Update (17.11.2022)
 ©2022 Lapp Group - Technical changes reserved
 Product Management www.lappkabel.de
 You can find the current technical data in the corresponding data sheet.
 PN 0456 / 02_03.16

FLEXIMARK® Organized shrink tube

Article number	Article designation	Colour	Shrinkage range (mm)	Length (mm)	Markers / PU	PU
83260084	FLEXIMARK® O.shr 9.5/4.8-50 YE	yellow	4.8 - 9.5	50.0	500	1
83260105	FLEXIMARK® O.shr 12.7/6.4-25 YE	yellow	6.4 - 12.7	25.0	1000	1
83260095	FLEXIMARK® O.shr 12.7/6.4-38 YE	yellow	6.4 - 12.7	38.0	500	1
83260085	FLEXIMARK® O.shr 12.7/6.4-50 YE	yellow	6.4 - 12.7	50.0	500	1
83260106	FLEXIMARK® O.shr 19.1/9.5-25 YE	yellow	9.5 - 19.1	25.0	1000	1
83260096	FLEXIMARK® O.shr 19.1/9.5-38 YE	yellow	9.5 - 19.1	38.0	500	1
83260086	FLEXIMARK® O.shr 19.1/9.5-50 YE	yellow	9.5 - 19.1	50.0	500	1
83260107	FLEXIMARK® O.shr 25.4/12.7-25 YE	yellow	12.7 - 25.4	25.0	600	1
83260097	FLEXIMARK® O.shr 25.4/12.7-38 YE	yellow	12.7 - 25.4	38.0	300	1
83260087	FLEXIMARK® O.shr 25.4/12.7-50 YE	yellow	12.7 - 25.4	50.0	300	1
83260098	FLEXIMARK® O.shr 38.1/19.1-38 YE	yellow	19.1 - 38.1	38.0	100	1
83260088	FLEXIMARK® O.shr 38.1/19.1-50 YE	yellow	19.1 - 38.1	50.0	100	1
83260099	FLEXIMARK® O.shr 50.8/25.4-38 YE	yellow	25.4 - 50.8	38.0	100	1
83260089	FLEXIMARK® O.shr 50.8/25.4-50 YE	yellow	25.4 - 50.8	50.0	100	1
Not halogen-free						
83260044	FLEXIMARK® Org.shr. 2.4/0.8-25(2) YE	yellow	0.8 - 2.4	25.0	2000	1
83260035	FLEXIMARK® Org.shr. 2.4/0.8-38(1) YE	yellow	0.8 - 2.4	38.0	1000	1
83260026	FLEXIMARK® Org.shr. 2.4/0.8-50(1) YE	yellow	0.8 - 2.4	50.0	1000	1
83260045	FLEXIMARK® Org.shr. 3.2/1.0-25(2) YE	yellow	1.0 - 3.2	25.0	2000	1
83260036	FLEXIMARK® Org.shr. 3.2/1.0-38(1) YE	yellow	1.0 - 3.2	38.0	1000	1
83260027	FLEXIMARK® Org.shr. 3.2/1.0-50(1) YE	yellow	1.0 - 3.2	50.0	1000	1

Last Update (17.11.2022)

©2022 Lapp Group - Technical changes reserved

Product Management www.lappkabel.de

You can find the current technical data in the corresponding data sheet.

PN 0456 / 02_03_16

FLEXIMARK® Organized shrink tube

Article number	Article designation	Colour	Shrinkage range (mm)	Length (mm)	Markers / PU	PU
83260046	FLEXIMARK® Org.shr. 4.8/1.6-25(2) YE	yellow	1.6 - 4.8	25.0	2000	1
83260037	FLEXIMARK® Org.shr. 4.8/1.6-38(1) YE	yellow	1.6 - 4.8	38.0	1000	1
83260028	FLEXIMARK® Org.shr. 4.8/1.6-50(1) YE	yellow	1.6 - 4.8	50.0	1000	1
83260047	FLEXIMARK® Org.shr. 6.4/2.0-25(2) YE	yellow	2.0 - 6.4	25.0	2000	1
83260038	FLEXIMARK® Org.shr. 6.4/2.0-38(1) YE	yellow	2.0 - 6.4	38.0	1000	1
83260029	FLEXIMARK® Org.shr. 6.4/2.0-50(1) YE	yellow	2.0 - 6.4	50.0	1000	1
83260048	FLEXIMARK® Org.shr. 9.5/3.0-25(2) YE	yellow	3.0 - 9.5	25.0	1000	1
83260039	FLEXIMARK® Org.shr. 9.5/3.0-38(1) YE	yellow	3.0 - 9.5	38.0	500	1
83260030	FLEXIMARK® Org.shr. 9.5/3.0-50(1) YE	yellow	3.0 - 9.5	50.0	500	1
83260049	FLEXIMARK® Org.shr. 12.7/4.0-25(2) YE	yellow	4.0 - 12.7	25.0	1000	1
83260040	FLEXIMARK® Org.shr.12.7/4.0-38(1)YE	yellow	4.0 - 12.7	38.0	500	1
83260031	FLEXIMARK® Org.shr.12.7/4.0-50(1)YE	yellow	4.0 - 12.7	50.0	500	1
83260041	FLEXIMARK® Org.shr. 19.0/6.0-38(1)YE	yellow	6.0 - 19.0	38.0	500	1
83260032	FLEXIMARK® Org.shr.19.0/6.0-50(1)YE	yellow	6.0 - 19.0	50.0	500	1
83260051	FLEXIMARK® Org.shr. 5.4/8.0-25(2)YE	yellow	8.0 - 25.4	25.0	600	1
83260042	FLEXIMARK® Org.shr.25.4/8.0-38(1)YE	yellow	8.0 - 25.4	38.0	300	1
83260033	FLEXIMARK® Org.shr. 25.4/8.0-50(1)YE	yellow	8.0 - 25.4	50.0	300	1
83260043	FLEXIMARK® Org.shr. 38.1/12.7-38(1)YE	yellow	12.7 - 38.1	38.0	100	1
83260034	FLEXIMARK® Org.shr. 38.1/12.7-75(1)YE	yellow	12.7 - 38.1	75.0	100	1
83260050	FLEXIMARK® Org. shr.19.0/6.0-25(2)YE	yellow	6.0 - 19.0	25.0	1000	1