

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1554211004](#)
Status: **Active**
Overview: [Flamar Standard Cables for Industrial Automation](#)
Description: Flamar PROFIBUS* DP Network Cable, WSOR Jacket, Braided Shielding Overall, 2 Circuits, 0.34mm² / 22 AWG, 8.20mm (.323") Diameter, 200.0m (656.17') Length, Violet

Documents:

[Product Specification 1554211004-P1E \(PDF\)](#) [Product Literature \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	155421
Crimp Quality Equipment	Yes
Geographic Area	Global
Overview	Flamar Standard Cables for Industrial Automation
Product Literature Order No	987651-3992
Product Name	Flamar
Protocol	PROFIBUS*
UPC	889056464123

Physical

Bending Radius - Minimum	> 15xOD
Cable Length	200.0m
Circuits (Loaded)	2
Color - Cable Jacket	Violet
Insulation	Foam PE
Material - Outer Jacket	WSOR
Net Weight	0.010/g
Outer Jacket Diameter	8.20mm
Packaging Type	Reel
Temperature Range - Operating	-10°C to +60°C
Wire Size AWG	22
Wire Size mm²	0.34
Wire/Cable Type	UL AWM 21215 / CSA

Electrical

Current - Maximum per Contact	Contact Molex
Voltage - Maximum	600V


Material Info

Engineering Number	1X200M
--------------------	--------

Reference - Drawing Numbers

Product Specification	1554211004-P1E
-----------------------	----------------

*PROFIBUS is a trademark of PROFIBUS International.

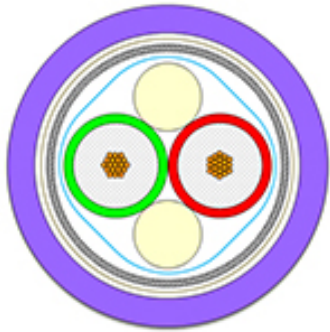

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[155421](#) Series

Use With

Micro-Change® (M12) [130047](#) , [120100](#) , [130034](#) , [120071](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION