

Product Search

Product Catalog

Products

Lamps & LED-Lamps

Neon lamps

Wired Terminal

Markets

Automotive

Aviation

Gaming

Illumination

Transport

Custom Projects


POS-CCE - Romania Sibiu



Product details

Article: 08000118



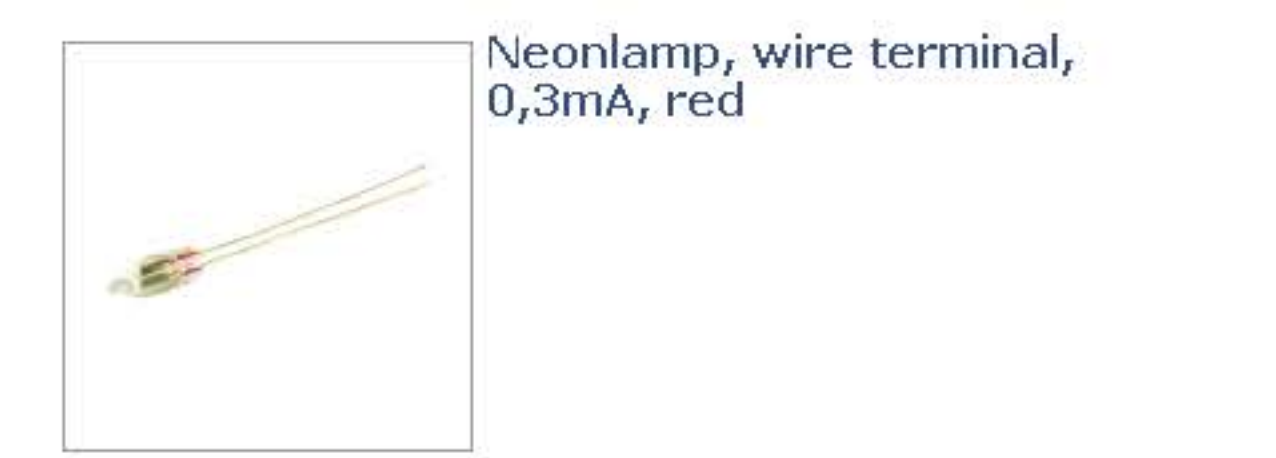

Neonlamp, wire terminal,
0,3mA, red

Description

Designation: Neonlamp, wire terminal, 0,3mA, red

Optical features

Colour: red

Electrical features

Current: 0,3 mA

Max. Striking Voltage AC: 65 V

Max. Striking Voltage DC: 90 V

Series resitors at 230V: 220 kohm (W)

Series resitors at 110V: 150 kohm (W)

Mechanical features

Socket: wire terminal

Diameter: 4 mm

Gallery



Click on a small picture to select it. Click the large image to view full size.

**Kingbright**

LEDs & LED-Displays
Distributed by CML
[Click here for information](#)

Stock inquiry

Latest News

2014-08-28

New CML catalogue:
"CML LED lamps for
signalisation and LED
panel mount
indicators"
>> [More details](#)

2014-07-07

Optimized BA15d LED
lamp for use in light
towers
>> [More details](#)

2013-11-10

StockCheck function
added to the website
>> [More details](#)