




### 31NT391-3-C08

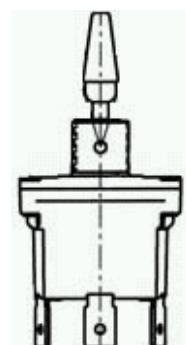

NT Series Toggle Switch, 1 pole, 2 position, Quick Connect terminal, Tab Lever

*Actual product appearance may vary.*

#### Features

Completely sealed switching chamber  
NEMA 3, 3R, 4, and 13  
UL recognized, File E12252, Vol. 1, Section 44  
CSA certified, File LR4442  
CE approved

#### Potential Applications

Aerial lifts, scissor lifts, truck mounted tele-handlers, and cranes  
Construction equipment  
Agriculture equipment  
Material-handling equipment  
Factory-floor control units  
Machine tool equipment manufacturers

#### Description

MICRO SWITCH™ NT Series toggle switches meet the need for a rugged, cost effective toggle switch. Quality construction features include a seal between the toggle lever and bushing, and between the cover and case. These switches can be used where panels are subject to splashes, hosedowns, or outdoor environments. The "Easy-Start" threaded bushing enables quick alignment of mounting nut to decrease the chance of cross threading. The panel stand-off with O-ring feature available on some listings, eliminates the need for behind-the-panel hardware, provides uniform panel height, and provides a panel to cover seal.

#### Supporting Documentation

[Accessory: Seals](#)

[Accessory: Nuts](#)

[Engineering Drawing](#)

Product Specifications		
Circuitry/Operating action	<b>Keyway Position</b>	<b>Opposite Keyway Position</b>
Product Type	MICRO SWITCH™ Toggle Switch	
Ampere/Voltage Range (Resistive Load)	0.5 A to 20 A at 0.5 Vdc to 28 Vdc, 0.5 A at 250 Vdc, 0.75 A at 115 Vdc, 0.5 A to 15 A at 0.5 Vac to 277 Vac	
Circuitry	SPDT	
Action	2 position	
Mounting	Bushing 15/32 in	
Termination	Quick Connect	
Lever Type	Tab	
UL/CSA Rating Code	L191: 15 A - 125, 250, 277 Vac; 1/2 Hp - 125 Vac; 1 Hp - 250, 277 Vac; 5 A - 120 Vac "L"	
Comment	Yellow	
Availability	Global	
UNSPSC Code	30211908	
UNSPSC Commodity	30211908 Toggle switches	
Series Name	NT	

#### My Links

[Login to iCOM](#)  
[Login as Rep/AD](#)  
[Login as Guest](#)  
[Login to Digital University](#)

#### Keyword Search

Search for product and support information.

All Sensing and Control

#### Product Search

Part number search:

Use (\*) to expand search

#### Specification Search

#### Order Product and Get Support

- U.S. Authorized Distributors
- Global Sales & Service
- N. American Sales Reps
- Distributor Inventory
- Technical Assistance
- White Papers
- Literature Request
- Test and Measurement Catalog
- RoHS Product List
- Customer Feedback