


Wire to Board Connectors
2.5mm Metric Interconnect System

Receptacle Assemblies
for wire insulation
displacement Crimp

Material and Finish :
Housing——94V-0 rated,
66Nylon, natural, black or
blue
Contact——Pre-tin Phosphor
bronze

Wire Size : AWG#28-22
(0.09-0.3mm²)
Insulation Dia. : 1.0-1.5mm

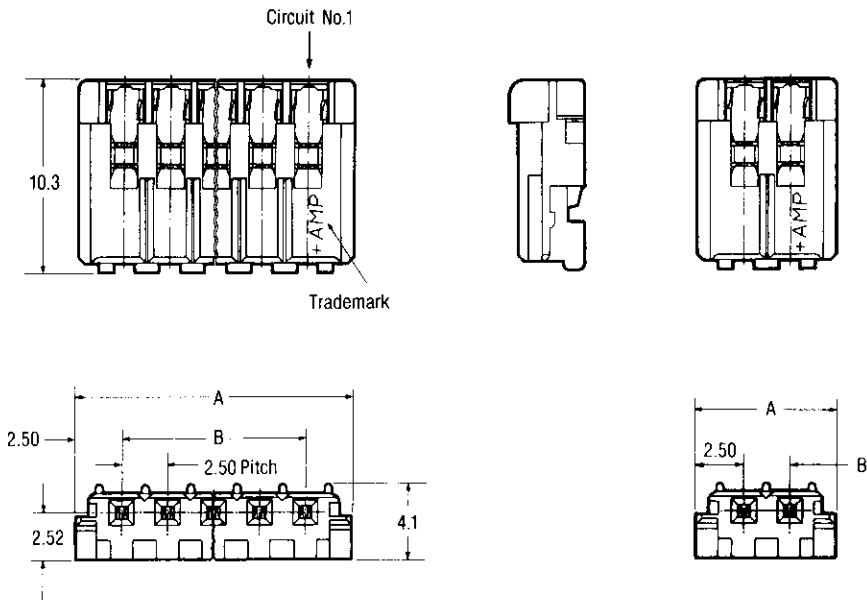

No. of Pos.	Dimensions		Part No. of Receptacle Assembly		
	A	B	Natural (#26, #28)	Black (#24)	Blue (#22)
2	7.5	2.5	2-177534-2	177534-2	179872-2
3	10.0	5.0	2-177534-3	177534-3	179872-3
4	12.5	7.5	2-177534-4	177534-4	179872-4
5	15.0	10.0	2-177534-5	177534-5	179872-5
6	17.5	12.5	2-177534-6	177534-6	179872-6
7	20.0	15.0	2-177534-7	177534-7	179872-7
8	22.5	17.5	2-177534-8	177534-8	179872-8
9	25.0	20.0	2-177534-9	177534-9	179872-9
10	27.5	22.5	3-177534-0	1-177534-0	1-179872-0
11	30.0	25.0	3-177534-1	1-177534-1	1-179872-1
12	32.5	27.5	3-177534-2	1-177534-2	1-179872-2
13	35.0	30.0	3-177534-3	1-177534-3	1-179872-3