


## Extruded Aluminum Enclosures *1455 Series*

Anodize Finish, Sliding Belly Plates, Plastic or Metal End Plates

### NEW SIZES

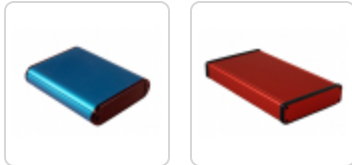

### Key Features:

- Designed to house PC boards or for equipment interfacing.
- PC boards mount horizontally by sliding into internal slots extruded into the enclosure body.
- Rugged body constructed from extruded aluminum with a minimum thickness of 0.06" (1.5 mm).
- Many sizes include a removable sliding plate.

### Includes:

- Versions with metal end plates include two flat aluminum end panels, color matched to housing, and two open plastic bezels, black.
- Versions with plastic end plates include two closed end panels, black.
- Extruded aluminum body, with or without sliding plate (see tables below).
- Four adhesive rubber feet. Order **1421T2CL** (pack of 24) for replacements.
- #6 x 3/8" thread rolling, steel end panel screws with a #4 flat head phillips drive. Clear anodized versions include natural screws, and black, red, and blue anodized versions include black screws.
- For black replacement screws (quantity 100) order part number **1455MS100BK**.
- For natural replacement screws for clear anodized enclosures (quantity 100) order part number **1455MS100**.
- NOTE: Recommended screw torque is 5 lbf-in.

### Photo Features:

Black Anodized Enclosure



Red Anodized Enclosure



Blue Anodized Enclosure



Many models feature a slide-



Accessory panels and



All models are sold as a complete enclosure and

out plate. All models include rubber feet.

bezels allow for mixing and matching of colors.

feature card slots for easy installation and assembly of PC boards.

## Accessories:

### Plastic Bezels and End Caps

Extra plastic bezels and end caps are sold in packs of (2) and (10) and are available in black, red, yellow, transparent red, and transparent blue. Refer to the accessory table below to select the part number you need.



### Aluminum End Panels

Extra end panels are sold in 10-packs and are available in clear, black, red, or blue anodized finishes. Refer to the accessory table below to select the part number you need.



### Flanged End Panel Kit

Flanged end panel kits are sold as a pair (2 panels total) and include black pan head assembly screws. Refer to the accessory table below to select the part number you need.



## Enclosures With Sliding Plate

| Enclosures w/<br>Aluminum End Panels | Enclosures w/<br>Plastic End Panels | Anodize Color | Length (mm) | Width (mm) | Depth (mm) |
|--------------------------------------|-------------------------------------|---------------|-------------|------------|------------|
| 1455J801                             | 1455J802                            | Clear         | 80.00       | 78.00      | 27.00      |
| 1455J801BK                           | 1455J802BK                          | Black         | 80.00       | 78.00      | 27.00      |
| 1455J801BU                           |                                     | Blue          | 80.00       | 78.00      | 27.00      |
| 1455J801RD                           |                                     | Red           | 80.00       | 78.00      | 27.00      |
| 1455K801                             | 1455K802                            | Clear         | 80.00       | 78.00      | 43.00      |
| 1455K801BK                           | 1455K802BK                          | Black         | 80.00       | 78.00      | 43.00      |
| 1455K801BU                           |                                     | Blue          | 80.00       | 78.00      | 43.00      |
| 1455K801RD                           |                                     | Red           | 80.00       | 78.00      | 43.00      |
| 1455L801                             | 1455L802                            | Clear         | 80.00       | 103.00     | 30.50      |

| Enclosures w/<br>Aluminum End Panels | Enclosures w/<br>Plastic End Panels | Anodize Color | Length (mm) | Width (mm) | Depth (mm) |
|--------------------------------------|-------------------------------------|---------------|-------------|------------|------------|
| 1455L801BK                           | 1455L802BK                          | Black         | 80.00       | 103.00     | 30.50      |
| 1455L801BU                           |                                     | Blue          | 80.00       | 103.00     | 30.50      |
| 1455L801RD                           |                                     | Red           | 80.00       | 103.00     | 30.50      |
| 1455J1201                            | 1455J1202                           | Clear         | 120.00      | 78.00      | 27.00      |
| 1455J1201BK                          | 1455J1202BK                         | Black         | 120.00      | 78.00      | 27.00      |
| 1455J1201BU                          |                                     | Blue          | 120.00      | 78.00      | 27.00      |
| 1455J1201RD                          |                                     | Red           | 120.00      | 78.00      | 27.00      |
| 1455K1201                            | 1455K1202                           | Clear         | 120.00      | 78.00      | 43.00      |
| 1455K1201BK                          | 1455K1202BK                         | Black         | 120.00      | 78.00      | 43.00      |
| 1455K1201BU                          |                                     | Blue          | 120.00      | 78.00      | 43.00      |
| 1455K1201RD                          |                                     | Red           | 120.00      | 78.00      | 43.00      |
| 1455L1201                            | 1455L1202                           | Clear         | 120.00      | 103.00     | 30.50      |
| 1455L1201BK                          | 1455L1202BK                         | Black         | 120.00      | 103.00     | 30.50      |
| 1455L1201BU                          |                                     | Blue          | 120.00      | 103.00     | 30.50      |
| 1455L1201RD                          |                                     | Red           | 120.00      | 103.00     | 30.50      |
| 1455N1201                            | 1455N1202                           | Clear         | 120.00      | 103.00     | 53.00      |
| 1455N1201BK                          | 1455N1202BK                         | Black         | 120.00      | 103.00     | 53.00      |
| 1455N1201BU                          |                                     | Blue          | 120.00      | 103.00     | 53.00      |
| 1455N1201RD                          |                                     | Red           | 120.00      | 103.00     | 53.00      |
| 1455T1201                            | 1455T1202                           | Clear         | 120.00      | 165.00     | 51.50      |
| 1455T1201BK                          | 1455T1202BK                         | Black         | 120.00      | 165.00     | 51.50      |
| 1455J1601                            | 1455J1602                           | Clear         | 160.00      | 78.00      | 27.00      |
| 1455J1601BK                          | 1455J1602BK                         | Black         | 160.00      | 78.00      | 27.00      |
| 1455J1601BU                          |                                     | Blue          | 160.00      | 78.00      | 27.00      |
| 1455J1601RD                          |                                     | Red           | 160.00      | 78.00      | 27.00      |
| 1455K1601                            | 1455K1602                           | Clear         | 160.00      | 78.00      | 43.00      |
| 1455K1601BK                          | 1455K1602BK                         | Black         | 160.00      | 78.00      | 43.00      |
| 1455K1601BU                          |                                     | Blue          | 160.00      | 78.00      | 43.00      |
| 1455K1601RD                          |                                     | Red           | 160.00      | 78.00      | 43.00      |
| 1455L1601                            | 1455L1602                           | Clear         | 160.00      | 103.00     | 30.50      |
| 1455L1601BK                          | 1455L1602BK                         | Black         | 160.00      | 103.00     | 30.50      |
| 1455L1601BU                          |                                     | Blue          | 160.00      | 103.00     | 30.50      |
| 1455L1601RD                          |                                     | Red           | 160.00      | 103.00     | 30.50      |
| 1455N1601                            | 1455N1602                           | Clear         | 160.00      | 103.00     | 53.00      |
| 1455N1601BK                          | 1455N1602BK                         | Black         | 160.00      | 103.00     | 53.00      |
| 1455N1601BU                          |                                     | Blue          | 160.00      | 103.00     | 53.00      |
| 1455N1601RD                          |                                     | Red           | 160.00      | 103.00     | 53.00      |
| 1455P1601                            | 1455P1602                           | Clear         | 160.00      | 125.00     | 30.50      |
| 1455P1601BK                          | 1455P1602BK                         | Black         | 160.00      | 125.00     | 30.50      |
| 1455P1601BU                          |                                     | Blue          | 160.00      | 125.00     | 30.50      |
| 1455P1601RD                          |                                     | Red           | 160.00      | 125.00     | 30.50      |
| 1455Q1601                            | 1455Q1602                           | Clear         | 160.00      | 125.00     | 51.50      |
| 1455Q1601BK                          | 1455Q1602BK                         | Black         | 160.00      | 125.00     | 51.50      |
| 1455Q1601BU                          |                                     | Blue          | 160.00      | 125.00     | 51.50      |
| 1455Q1601RD                          |                                     | Red           | 160.00      | 125.00     | 51.50      |
| 1455R1601                            | 1455R1602                           | Clear         | 160.00      | 165.00     | 30.50      |
| 1455R1601BK                          | 1455R1602BK                         | Black         | 160.00      | 165.00     | 30.50      |
| 1455R1601BU                          |                                     | Blue          | 160.00      | 165.00     | 30.50      |
| 1455R1601RD                          |                                     | Red           | 160.00      | 165.00     | 30.50      |
| 1455T1601                            | 1455T1602                           | Clear         | 160.00      | 165.00     | 51.50      |
| 1455T1601BK                          | 1455T1602BK                         | Black         | 160.00      | 165.00     | 51.50      |
| 1455T1601BU                          |                                     | Blue          | 160.00      | 165.00     | 51.50      |
| 1455T1601RD                          |                                     | Red           | 160.00      | 165.00     | 51.50      |

| Enclosures w/<br>Aluminum End Panels | Enclosures w/<br>Plastic End Panels | Anodize Color | Length (mm) | Width (mm) | Depth (mm) |
|--------------------------------------|-------------------------------------|---------------|-------------|------------|------------|
| 1455U1601                            | 1455U1602                           | Clear         | 160.00      | 191.00     | 66.00      |
| 1455U1601BK                          | 1455U1602BK                         | Black         | 160.00      | 191.00     | 66.00      |
| 1455L2201                            | 1455L2202                           | Clear         | 220.00      | 103.00     | 30.50      |
| 1455L2201BK                          | 1455L2202BK                         | Black         | 220.00      | 103.00     | 30.50      |
| 1455L2201BU                          |                                     | Blue          | 220.00      | 103.00     | 30.50      |
| 1455L2201RD                          |                                     | Red           | 220.00      | 103.00     | 30.50      |
| 1455N2201                            | 1455N2202                           | Clear         | 220.00      | 103.00     | 53.00      |
| 1455N2201BK                          | 1455N2202BK                         | Black         | 220.00      | 103.00     | 53.00      |
| 1455N2201BU                          |                                     | Blue          | 220.00      | 103.00     | 53.00      |
| 1455N2201RD                          |                                     | Red           | 220.00      | 103.00     | 53.00      |
| 1455P2201                            | 1455P2202                           | Clear         | 220.00      | 125.00     | 30.50      |
| 1455P2201BK                          | 1455P2202BK                         | Black         | 220.00      | 125.00     | 30.50      |
| 1455P2201BU                          |                                     | Blue          | 220.00      | 125.00     | 30.50      |
| 1455P2201RD                          |                                     | Red           | 220.00      | 125.00     | 30.50      |
| 1455Q2201                            | 1455Q2202                           | Clear         | 220.00      | 125.00     | 51.50      |
| 1455Q2201BK                          | 1455Q2202BK                         | Black         | 220.00      | 125.00     | 51.50      |
| 1455Q2201BU                          |                                     | Blue          | 220.00      | 125.00     | 51.50      |
| 1455Q2201RD                          |                                     | Red           | 220.00      | 125.00     | 51.50      |
| 1455R2201                            | 1455R2202                           | Clear         | 220.00      | 165.00     | 30.50      |
| 1455R2201BK                          | 1455R2202BK                         | Black         | 220.00      | 165.00     | 30.50      |
| 1455R2201BU                          |                                     | Blue          | 220.00      | 165.00     | 30.50      |
| 1455R2201RD                          |                                     | Red           | 220.00      | 165.00     | 30.50      |
| 1455T2201                            | 1455T2202                           | Clear         | 220.00      | 165.00     | 51.50      |
| 1455T2201BK                          | 1455T2202BK                         | Black         | 220.00      | 165.00     | 51.50      |
| 1455T2201BU                          |                                     | Blue          | 220.00      | 165.00     | 51.50      |
| 1455T2201RD                          |                                     | Red           | 220.00      | 165.00     | 51.50      |
| 1455U2201                            | 1455U2202                           | Clear         | 220.00      | 191.00     | 66.00      |
| 1455U2201BK                          | 1455U2202BK                         | Black         | 220.00      | 191.00     | 66.00      |
| 1455U2801                            | 1455U2802                           | Clear         | 280.00      | 191.00     | 66.00      |
| 1455U2801BK                          | 1455U2802BK                         | Black         | 280.00      | 191.00     | 66.00      |

## Enclosures Without Sliding Plate

| Enclosures w/<br>Aluminum End Panels | Enclosures w/<br>Plastic End Panels | Anodize Color | Length (mm) | Width (mm) | Depth (mm) |
|--------------------------------------|-------------------------------------|---------------|-------------|------------|------------|
| 1455D601                             | 1455D602                            | Clear         | 60.00       | 45.00      | 23.00      |
| 1455D601BK                           | 1455D602BK                          | Black         | 60.00       | 45.00      | 23.00      |
| 1455D601BU                           |                                     | Blue          | 60.00       | 45.00      | 23.00      |
| 1455D601RD                           |                                     | Red           | 60.00       | 45.00      | 23.00      |
| 1455D801                             | 1455D802                            | Clear         | 80.00       | 45.00      | 23.00      |
| 1455D801BK                           | 1455D802BK                          | Black         | 80.00       | 45.00      | 23.00      |
| 1455D801BU                           |                                     | Blue          | 80.00       | 45.00      | 23.00      |
| 1455D801RD                           |                                     | Red           | 80.00       | 45.00      | 23.00      |
|                                      | 1455A802                            | Clear         | 80.00       | 70.00      | 12.00      |
|                                      | 1455A802BK                          | Black         | 80.00       | 70.00      | 12.00      |
|                                      | 1455A802BU                          | Blue          | 80.00       | 70.00      | 12.00      |
|                                      | 1455A802RD                          | Red           | 80.00       | 70.00      | 12.00      |
|                                      | 1455B802                            | Clear         | 80.00       | 71.70      | 19.00      |
|                                      | 1455B802BK                          | Black         | 80.00       | 71.70      | 19.00      |
|                                      | 1455B802BU                          | Blue          | 80.00       | 71.70      | 19.00      |
|                                      | 1455B802RD                          | Red           | 80.00       | 71.70      | 19.00      |
| 1455C801                             | 1455C802                            | Clear         | 80.00       | 54.00      | 23.00      |
| 1455C801BK                           | 1455C802BK                          | Black         | 80.00       | 54.00      | 23.00      |
| 1455C801BU                           | 1455C802BU                          | Blue          | 80.00       | 54.00      | 23.00      |

| Enclosures w/<br>Aluminum End Panels | Enclosures w/<br>Plastic End Panels | Anodize Color | Length (mm) | Width (mm) | Depth (mm) |
|--------------------------------------|-------------------------------------|---------------|-------------|------------|------------|
| 1455C801RD                           | 1455C802RD                          | Red           | 80.00       | 54.00      | 23.00      |
| 1455CS801                            | 1455CS802                           | Clear         | 80.00       | 54.00      | 54.00      |
| 1455CS801BK                          | 1455CS802BK                         | Black         | 80.00       | 54.00      | 54.00      |
|                                      | 1455A1002                           | Clear         | 100.00      | 70.00      | 12.00      |
|                                      | 1455A1002BK                         | Black         | 100.00      | 70.00      | 12.00      |
|                                      | 1455A1002BU                         | Blue          | 100.00      | 70.00      | 12.00      |
|                                      | 1455A1002RD                         | Red           | 100.00      | 70.00      | 12.00      |
|                                      | 1455B1002                           | Clear         | 100.00      | 71.70      | 19.00      |
|                                      | 1455B1002BK                         | Black         | 100.00      | 71.70      | 19.00      |
|                                      | 1455B1002BU                         | Blue          | 100.00      | 71.70      | 19.00      |
|                                      | 1455B1002RD                         | Red           | 100.00      | 71.70      | 19.00      |
|                                      | 1455A1202                           | Clear         | 120.00      | 70.00      | 12.00      |
|                                      | 1455A1202BK                         | Black         | 120.00      | 70.00      | 12.00      |
|                                      | 1455A1202BU                         | Blue          | 120.00      | 70.00      | 12.00      |
|                                      | 1455A1202RD                         | Red           | 120.00      | 70.00      | 12.00      |
|                                      | 1455B1202                           | Clear         | 120.00      | 71.70      | 19.00      |
|                                      | 1455B1202BK                         | Black         | 120.00      | 71.70      | 19.00      |
|                                      | 1455B1202BU                         | Blue          | 120.00      | 71.70      | 19.00      |
|                                      | 1455B1202RD                         | Red           | 120.00      | 71.70      | 19.00      |
| 1455C1201                            | 1455C1202                           | Clear         | 120.00      | 54.00      | 23.00      |
| 1455C1201BK                          | 1455C1202BK                         | Black         | 120.00      | 54.00      | 23.00      |
| 1455C1201BU                          |                                     | Blue          | 120.00      | 54.00      | 23.00      |
| 1455C1201RD                          |                                     | Red           | 120.00      | 54.00      | 23.00      |
| 1455CS1201                           | 1455CS1202                          | Clear         | 120.00      | 54.00      | 54.00      |
| 1455CS1201BK                         | 1455CS1202BK                        | Black         | 120.00      | 54.00      | 54.00      |
| 1455NS1201                           | 1455NS1202                          | Clear         | 120.00      | 104.50     | 104.50     |
| 1455NS1201BK                         | 1455NS1202BK                        | Black         | 120.00      | 104.50     | 104.50     |
| 1455NS1601                           | 1455NS1602                          | Clear         | 160.00      | 104.50     | 104.50     |
| 1455NS1601BK                         | 1455NS1602BK                        | Black         | 160.00      | 104.50     | 104.50     |
| 1455NS2201                           | 1455NS2202                          | Clear         | 220.00      | 104.50     | 104.50     |
| 1455NS2201BK                         | 1455NS2202BK                        | Black         | 220.00      | 104.50     | 104.50     |

## Closed Bezels (Plastic End Caps)

| Part No.<br>Starting<br>With: | Black      |               | Yellow   |             | Red        |                | Translucent Red |                | Translucent Blue |                |
|-------------------------------|------------|---------------|----------|-------------|------------|----------------|-----------------|----------------|------------------|----------------|
|                               | 2-pack     | 10-pack       | 2-pack   | 10-pack     | 2-pack     | 10-pack        | 2-pack          | 10-pack        | 2-pack           | 10-pack        |
| 1455A                         | 1455APLBK  | 1455APLBK-10  |          |             |            |                |                 |                |                  |                |
| 1455B                         | 1455BPLBK  | 1455BPLBK-10  |          |             |            |                |                 |                |                  |                |
| 1455C                         | 1455CPLBK  | 1455CPLBK-10  | 1455CPLY | 1455CPLY-10 | 1455CPLRE  | 1455CPLRE D    | 1455CPLTR       | 1455CPLTR D-10 | 1455CPLTB        | 1455CPLTB U-10 |
| 1455CS                        | 1455CSPLBK | 1455CSPLBK-10 |          |             |            |                |                 |                |                  |                |
| 1455D                         | 1455DPLBK  | 1455DPLBK-10  |          |             |            |                |                 |                | 1455DPLTB        | 1455DPLTB U-10 |
| 1455J                         | 1455JPLBK  | 1455JPLBK-10  | 1455JPLY | 1455JPLY-10 | 1455JPLRED | 1455JPLRED -10 | 1455JPLTRD      | 1455JPLTRD -10 | 1455JPLTB        | 1455JPLTB U-10 |
| 1455K                         | 1455KPLBK  | 1455KPLBK-10  | 1455KPLY | 1455KPLY-10 | 1455KPLRE  | 1455KPLRE D    | 1455KPLTR       | 1455KPLTR D-10 | 1455KPLTB        | 1455KPLTB U-10 |
| 1455L                         | 1455LPLBK  | 1455LPLBK-10  | 1455LPLY | 1455LPLY-10 | 1455LPLRE  | 1455LPLRE D    | 1455LPLTRD      | 1455LPLTRD -10 | 1455LPLTB        | 1455LPLTB U-10 |
| 1455N                         | 1455NPLBK  | 1455NPLBK-10  | 1455NPLY | 1455NPLY-10 | 1455NPLRE  | 1455NPLRE D    | 1455NPLTR       | 1455NPLTR D-10 | 1455NPLTB        | 1455NPLTB U-10 |

| Part No.       | Black          |                   | Yellow   |                 | Red            |                   | Translucent Red |                   | Translucent Blue |                   |
|----------------|----------------|-------------------|----------|-----------------|----------------|-------------------|-----------------|-------------------|------------------|-------------------|
| Starting With: | 2-pack         | 10-pack           | 2-pack   | 10-pack         | 2-pack         | 10-pack           | 2-pack          | 10-pack           | 2-pack           | 10-pack           |
| 1455NS         | 1455NSPLB<br>K | 1455NSPLB<br>K-10 |          |                 |                |                   |                 |                   |                  |                   |
| 1455P          | 1455PPLBK      | 1455PPLBK-<br>10  | 1455PPLY | 1455PPLY-10     | 1455PPLRE<br>D | 1455PPLRE<br>D-10 | 1455PPLTRD      | 1455PPLTRD<br>-10 | 1455PPLTBU       | 1455PPLTB<br>U-10 |
| 1455Q          | 1455QPLBK      | 1455QPLBK-<br>10  | 1455QPLY | 1455QPLY-<br>10 | 1455QPLRE<br>D | 1455QPLRE<br>D-10 | 1455QPLTR<br>D  | 1455QPLTR<br>D-10 | 1455QPLTB<br>U   | 1455QPLTB<br>U-10 |
| 1455R          | 1455RPLBK      | 1455RPLBK-<br>10  | 1455RPLY | 1455RPLY-<br>10 | 1455RPLRE<br>D | 1455RPLRE<br>D-10 | 1455RPLTR<br>D  | 1455RPLTR<br>D-10 | 1455RPLTB<br>U   | 1455RPLTB<br>U-10 |
| 1455T          | 1455TPLBK      | 1455TPLBK-<br>10  | 1455TPLY | 1455TPLY-10     | 1455TPLRE<br>D | 1455TPLRE<br>D-10 | 1455TPLTRD      | 1455TPLTRD<br>-10 | 1455TPLTBU       | 1455TPLTB<br>U-10 |
| 1455U          | 1455UPLBK      | 1455UPLBK-<br>10  | 1455UPLY | 1455UPLY-<br>10 | 1455UPLRE<br>D | 1455UPLRE<br>D-10 | 1455UPLTR<br>D  | 1455UPLTR<br>D-10 | 1455UPLTB<br>U   | 1455UPLTB<br>U-10 |

### Open Bezels (For Use w/ Metal End Plate Enclosures)

| Part No.       | Black     |                  | Yellow  |            | Red       |                  | Translucent Red |                  | Translucent Blue |                   |
|----------------|-----------|------------------|---------|------------|-----------|------------------|-----------------|------------------|------------------|-------------------|
| Starting With: | 2-pack    | 10-pack          | 2-pack  | 10-pack    | 2-pack    | 10-pack          | 2-pack          | 10-pack          | 2-pack           | 10-pack           |
| 1455C          | 1455CBBK  | 1455CBBK-<br>10  | 1455CBY | 1455CBY-10 | 1455CBRED | 1455CBRED-<br>10 | 1455CBTRD       | 1455CBTRD-<br>10 | 1455CBTBU        | 1455CBTBU-<br>10  |
| 1455CS         | 1455CSBBK | 1455CSBBK-<br>10 |         |            |           |                  |                 |                  |                  |                   |
| 1455D          | 1455DBBK  | 1455DBBK-<br>10  |         |            |           |                  |                 |                  | 1455DBTBU        | 1455DBTBU-<br>10  |
| 1455J          | 1455JBBK  | 1455JBBK-<br>10  | 1455JBY | 1455JBY-10 | 1455JBRED | 1455JBRED-<br>10 | 1455JBTRD       | 1455JBTRD-<br>10 | 1455JBTBU        | 1455JBTBU-<br>10  |
| 1455K          | 1455KBBK  | 1455KBBK-<br>10  | 1455KBY | 1455KBY-10 | 1455KBRED | 1455KBRED-<br>10 | 1455KBTRD       | 1455KBTRD-<br>10 | 1455KBTBU        | 1455KBTBU-<br>10  |
| 1455L          | 1455LBBK  | 1455LBBK-<br>10  | 1455LBY | 1455LBY-10 | 1455LBRED | 1455LBRED-<br>10 | 1455LBTRD       | 1455LBTRD-<br>10 | 1455LBTBU        | 1455LBTBU-<br>10  |
| 1455N          | 1455NBBK  | 1455NBBK-<br>10  | 1455NBY | 1455NBY-10 | 1455NBRED | 1455NBRED-<br>10 | 1455NBTRD       | 1455NBTRD-<br>10 | 1455NBTBU        | 1455NBTBU-<br>10  |
| 1455NS         | 1455NSBBK | 1455NSBBK-<br>10 |         |            |           |                  |                 |                  |                  |                   |
| 1455P          | 1455PBBK  | 1455PBBK-<br>10  | 1455PBY | 1455PBY-10 | 1455PBRED | 1455PBRED-<br>10 | 1455PBTRD       | 1455PBTRD-<br>10 | 1455PBTBU        | 1455PBTBU-<br>10  |
| 1455Q          | 1455QBBK  | 1455QBBK-<br>10  | 1455QBY | 1455QBY-10 | 1455QBRED | 1455QBRED-<br>10 | 1455QBTRD       | 1455QBTRD-<br>10 | 1455QBTBU        | 1455QBTBU-<br>-10 |
| 1455R          | 1455RBBK  | 1455RBBK-<br>10  | 1455RBY | 1455RBY-10 | 1455RBRED | 1455RBRED-<br>10 | 1455RBTRD       | 1455RBTRD-<br>10 | 1455RBTBU        | 1455RBTBU-<br>10  |
| 1455T          | 1455TBBK  | 1455TBBK-<br>10  | 1455TBY | 1455TBY-10 | 1455TBRED | 1455TBRED-<br>10 | 1455TBTRD       | 1455TBTRD-<br>10 | 1455TBTBU        | 1455TBTBU-<br>10  |
| 1455U          | 1455UBBK  | 1455UBBK-<br>10  | 1455UBY | 1455UBY-10 | 1455UBRED | 1455UBRED-<br>10 | 1455UBTRD       | 1455UBTRD-<br>10 | 1455UBTBU        | 1455UBTBU-<br>10  |

### Aluminum End Panels (For Use With Metal End Plate Enclosures)

| For Part Number | Clear Anodize | Black Anodize | Blue Anodize | Red Anodize  |
|-----------------|---------------|---------------|--------------|--------------|
| Starting With   | 10-pack       | 10-pack       | 10-pack      | 10-pack      |
| 1455C           | 1455CAL-10    | 1455CALBK-10  | 1455CALBU-10 | 1455CALRD-10 |
| 1455CS          | 1455CSAL-10   | 1455CSALBK-10 |              |              |
| 1455D           | 1455DAL-10    | 1455DALBK-10  | 1455DALBU-10 | 1455DALRD-10 |
| 1455J           | 1455JAL-10    | 1455JALBK-10  | 1455JALBU-10 | 1455JALRD-10 |
| 1455K           | 1455KAL-10    | 1455KALBK-10  | 1455KALBU-10 | 1455KALRD-10 |
| 1455L           | 1455LAL-10    | 1455LALBK-10  | 1455LALBU-10 | 1455LALRD-10 |

| For Part Number Starting With | Clear Anodize 10-pack | Black Anodize 10-pack | Blue Anodize 10-pack | Red Anodize 10-pack |
|-------------------------------|-----------------------|-----------------------|----------------------|---------------------|
| 1455N                         | 1455NAL-10            | 1455NALBK-10          | 1455NALBU-10         | 1455NALRD-10        |
| 1455NS                        | 1455NSAL-10           | 1455NSALBK-10         |                      |                     |
| 1455P                         | 1455PAL-10            | 1455PALBK-10          | 1455PALBU-10         | 1455PALRD-10        |
| 1455Q                         | 1455QAL-10            | 1455QALBK-10          | 1455QALBU-10         | 1455QALRD-10        |
| 1455R                         | 1455RAL-10            | 1455RALBK-10          | 1455RALBU-10         | 1455RALRD-10        |
| 1455T                         | 1455TAL-10            | 1455TALBK-10          | 1455TALBU-10         | 1455TALRD-10        |
| 1455U                         | 1455UAL-10            | 1455UALBK-10          |                      |                     |

## Flanged End Panel Kits

| For Part Number Starting With | Clear Anodize | Black Anodize | Replacement Screws For Flange Kits (100-pack) |
|-------------------------------|---------------|---------------|---|
| 1455C                         | 1455CF        | 1455CFBK      | 1455MSFL100BK                                 |
| 1455D                         | 1455DF        | 1455DFBK      | 1455MSFL100BK                                 |
| 1455J                         | 1455JF        | 1455JFBK      | 1455MSFL100BK                                 |
| 1455K                         | 1455KF        | 1455KFBK      | 1455MSFL100BK                                 |
| 1455L                         | 1455LF        | 1455LFBK      | 1455MSFL100BK                                 |
| 1455N                         | 1455NF        | 1455NFBK      | 1455MSFL100BK                                 |
| 1455P                         | 1455PF        | 1455PFBK      | 1455MSFL100BK                                 |
| 1455Q                         | 1455QF        | 1455QFBK      | 1455MSFL100BK                                 |
| 1455R                         | 1455RF        | 1455RFBK      | 1455MSFL100BK                                 |
| 1455T                         | 1455TF        | 1455TFBK      | 1455MSFL100BK                                 |
| 1455U                         | 1455UF        | 1455UFBK      | 1455MSFL100BK                                 |

Tags: extruded, PCB mount, PCB slot, PCB enclosure, board enclosure, anodized, extruded aluminum, aluminum cover, plastic cover, extrusion

*Data subject to change without notice.*

© 2026. Hammond Manufacturing Ltd. All rights reserved.