


## Specification Sheet

Part Number: FPC

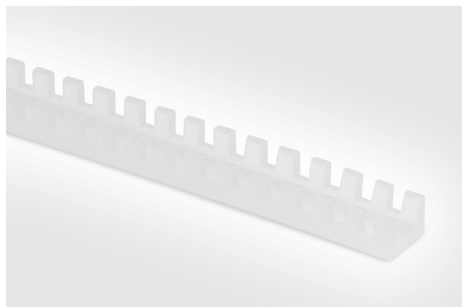

Can be cut to length with scissors, eliminating waste and keeping stock to a minimum.

Available in 9 sizes, for thicknesses from .016" to .512", insuring proper fit.

Article Number 251-10309

Type G51PC

Color Natural (NA)

Quantity Per pack

Product Description HellermannTyton's Flexiform grommet is a unique, continuous wire protection product which fits easily in all shapes and sizes of holes without the aid of tools or adhesives. Flexiform grommet can be used on any type of material including wood, steel, aluminum, plexiglass, and glass.

Short Description Grommet, Panel Thickness 0.083"-0.130", PE, Natural, 82ft/pkg

Global Part Name G51PC-PE-NA

Length L (Imperial)	82.0
Variant	Open
Width W (Imperial)	0.224
Width W (Metric)	5.7
Height H (Imperial)	0.169
Height H (Metric)	4.3
Panel Thickness Min (Imperial)	0.08
Panel Thickness Max (Imperial)	0.13
Panel Thickness Min (Metric)	2.1
Panel Thickness Max (Metric)	3.3

Material Polyethylene (PE)

Material Shortcut PE

Flammability UL 94 HB

Halogen Free Yes

UV Resistant (Yes/No) No

Operating Temperature -22°F to +176°F (-30°C to +80°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial) 82

Package Quantity (Metric) 25

Customs Number 3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224

Phone: (800) 537-1512 | Email: [corp@htamericas.com](mailto:corp@htamericas.com)

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)