
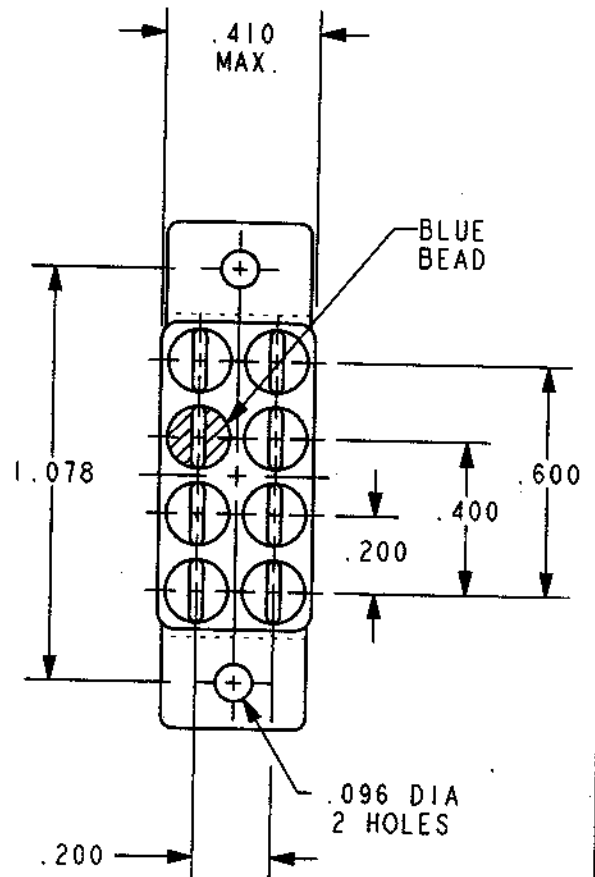


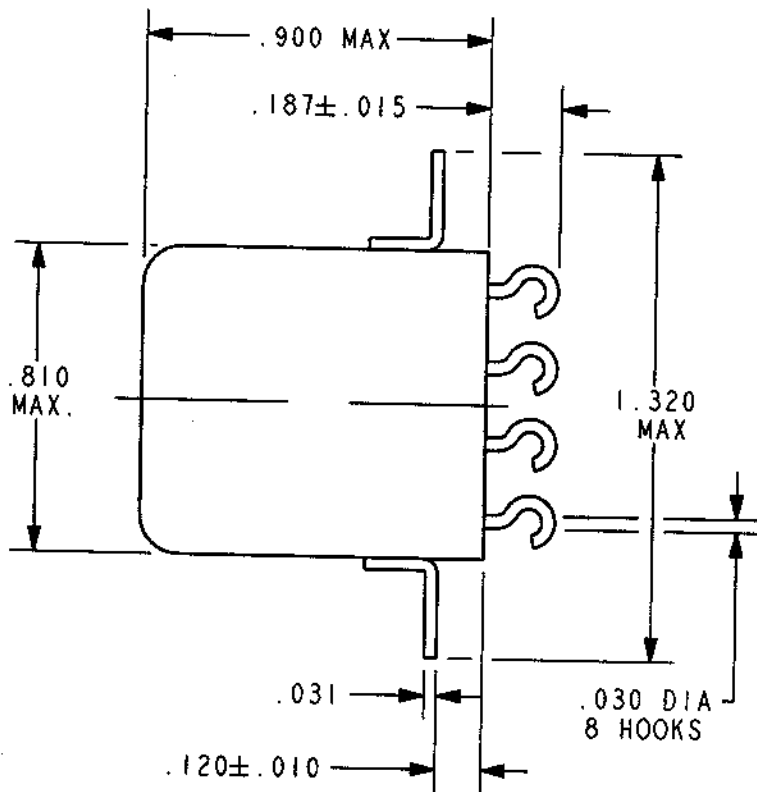


REV. 0
DCO 17597

COIL: @ 25°C	
RESISTANCE	675 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.0 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:	
VIBRATION	10 Hz TO 2000 Hz @ 20 g's
SHOCK	100 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C
NOTES:	OPERATE 6 MS MAX
	RELEASE 3 MS MAX
	CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

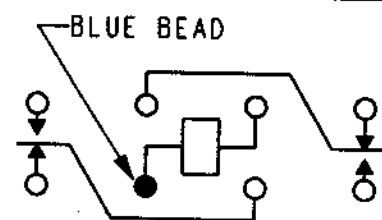

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
5 AMPS 30 VDC RESISTIVE, 2 AMPS 115
VAC 60 HZ RESISTIVE 100,000 OPERATIONS

DR. ASB 17 MAY 02 CK 5/26/02

CII Technologies
advanced control electronic solutions

CUST. HI-G
CUST. NO. 28N-1E-126 REV.

"FW5A" RELAY

FW5A1196S02