
 


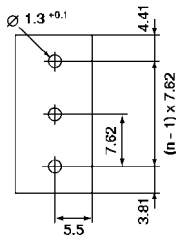

LP 7.62/90



Technical data	VDE	UL	CSA
Rated voltage (V)	500*	300	300
Rated current (A)	26	15	20
Wire size (mm ² /AWG)	4.0	26...12	26...12

*Pollution severity 3 / Overvoltage category III
Additional technical data see page 59

Solder pin length 4.5 mm 4.5 mm



Color				
Poles	Type	Part No.	Part No.	Qty.
2	LP 7.62/2/90	1594660000	1697200000	100
3	LP 7.62/3/90	1594670000	1697210000	100
4	LP 7.62/4/90	995336	995349	
5	LP 7.62/5/90	995337	995350	
6	LP 7.62/6/90	995338	995351	
7	LP 7.62/7/90	995339	995352	
8	LP 7.62/8/90	995340	995353	
9	LP 7.62/9/90	995341	995354	
10	LP 7.62/10/90	995342	995355	
11	LP 7.62/11/90	995343	995356	
12	LP 7.62/12/90	995344	995357	
13	LP 7.62/13/90	995345	995358	
14	LP 7.62/14/90	995346	995359	
15	LP 7.62/15/90	995347	995360	
16	LP 7.62/16/90	995348	995361	

Accessories	Page
Marking	40
Mounting	46
Miscellaneous	46

LPP 7.62/90



 with test point

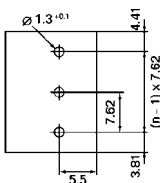

Technical data	VDE	UL	CSA
Rated voltage (V)	500*	300	300
Rated current (A)	26	15	20
Wire size (mm ² /AWG)	4.0	26...12	26...12

*Pollution severity 3 / Overvoltage category III
Additional technical data see page 59

Solder pin length 4.5 mm 4.5 mm



Color				
Poles	Type	Part No.	Part No.	Qty.
2	LPP 7.62/2/90	1594680000	1697240000	100
3	LPP 7.62/3/90	1594690000	1697250000	100
4	LPP 7.62/4/90	995362	995375	
5	LPP 7.62/5/90	995363	995376	
6	LPP 7.62/6/90	995364	995377	
7	LPP 7.62/7/90	995365	995378	
8	LPP 7.62/8/90	995366	995379	
9	LPP 7.62/9/90	995367	995380	
10	LPP 7.62/10/90	995368	995381	
11	LPP 7.62/11/90	995369	995382	
12	LPP 7.62/12/90	995370	995383	
13	LPP 7.62/13/90	995371	995384	
14	LPP 7.62/14/90	995372	995385	
15	LPP 7.62/15/90	995373	995386	
16	LPP 7.62/16/90	995374	995387	

Accessories	Page
Marking	40
Mounting	46
Miscellaneous	43, 46

LP 7.62/135



 with test point

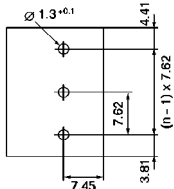

Technical data	VDE	UL	CSA
Rated voltage (V)	500*	300	300
Rated current (A)	26	15	20
Wire size (mm ² /AWG)	4.0	26...12	26...12

*Pollution severity 3 / Overvoltage category III
Additional technical data see page 59

Solder pin length 4.5 mm 4.5 mm

Color				
Poles	Type	Part No.	Part No.	Qty.
2	LP 7.62/2/135	1595800000	1697280000	100
3	LP 7.62/3/135	1595810000	1697290000	100
4	LP 7.62/4/135	995388	995401	
5	LP 7.62/5/135	995389	995402	
6	LP 7.62/6/135	995390	995403	
7	LP 7.62/7/135	995391	995404	
8	LP 7.62/8/135	995392	995405	
9	LP 7.62/9/135	995393	995406	
10	LP 7.62/10/135	995394	995407	
11	LP 7.62/11/135	995395	995408	
12	LP 7.62/12/135	995396	995409	
13	LP 7.62/13/135	995397	995410	
14	LP 7.62/14/135	995398	995411	
15	LP 7.62/15/135	995399	995412	
16	LP 7.62/16/135	995400	995413	

Accessories	Page
Marking	40
Mounting	-
Miscellaneous	46