


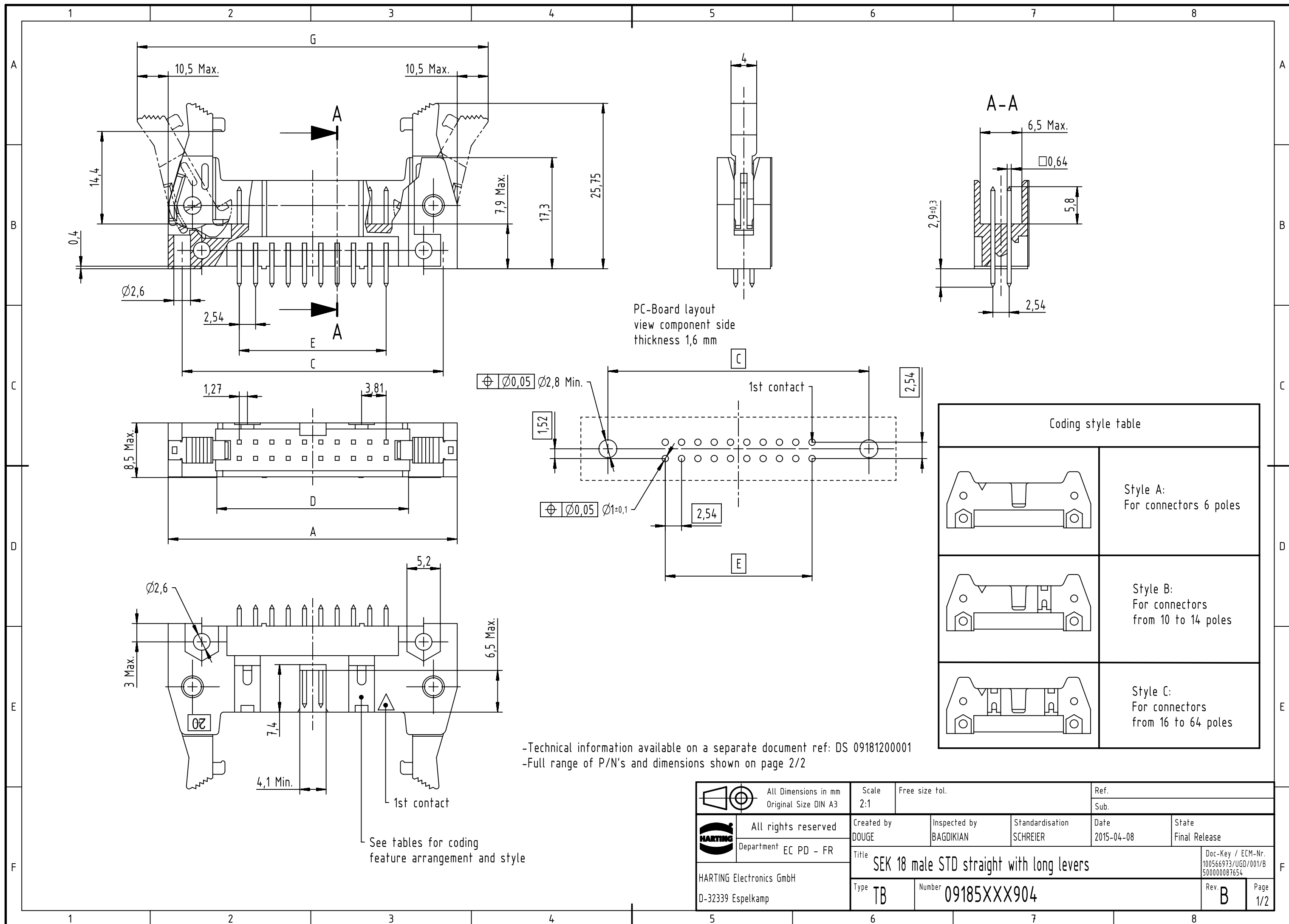

1	2	3	4	5	6	7	8		
Performance Level									
	PL3	PL2	S4		Dimensions (mm)				
Nb of Contacts	Part Number	Part Number	Part Number	Insulator Color	A Max	C	D	E	G
06	0918 506 7904	0918 506 6904	0918 506 5904	Grey	27,2	22,86	12,45	2,54 x 2 = 5,08	40,3
10	0918 510 7904	0918 510 6904	0918 510 5904		32,3	27,94	17,53	2,54 x 4 = 10,16	45,4
14	0918 514 7904	0918 514 6904	0918 514 5904		37,4	33,02	22,61	2,54 x 6 = 15,24	50,4
16	0918 516 7904	0918 516 6904	0918 516 5904		39,9	35,56	25,15	2,54 x 7 = 17,78	53,0
20	0918 520 7904	0918 520 6904	0918 520 5904		45,0	40,64	30,23	2,54 x 9 = 22,86	58,1
24	0918 524 7904	0918 524 6904	0918 524 5904		50,1	45,72	35,91	2,54 x 11 = 27,94	63,2
26	0918 526 7904	0918 526 6904	0918 526 5904		52,6	48,26	37,85	2,54 x 12 = 30,48	65,7
30	0918 530 7904	0918 530 6904	0918 530 5904		58,0	53,34	43,83	2,54 x 14 = 35,56	68,6
34	0918 534 7904	0918 534 6904	0918 534 5904		62,8	58,42	48,01	2,54 x 16 = 40,64	75,8
40	0918 540 7904	0918 540 6904	0918 540 5904		70,4	66,04	55,63	2,54 x 19 = 48,26	83,5
50	0918 550 7904	0918 550 6904	0918 550 5904		83,1	78,74	68,33	2,54 x 24 = 60,96	96,2
60	0918 560 7904	0918 560 6904	0918 560 5904		95,8	91,44	81,03	2,54 x 29 = 73,66	108,9
64	0918 564 7904	0918 564 6904	0918 564 5904		100,9	96,52	86,11	2,54 x 31 = 78,74	113,9
06	0918 506 7904 001	0918 506 6904 001	0918 506 5904 001	Black	27,2	22,86	12,45	2,54 x 2 = 5,08	40,3
10	0918 510 7904 001	0918 510 6904 001	0918 510 5904 001		32,3	27,94	17,53	2,54 x 4 = 10,16	45,4
14	0918 514 7904 001	0918 514 6904 001	0918 514 5904 001		37,4	33,02	22,61	2,54 x 6 = 15,24	50,4
16	0918 516 7904 001	0918 516 6904 001	0918 516 5904 001		39,9	35,56	25,15	2,54 x 7 = 17,78	53,0
20	0918 520 7904 001	0918 520 6904 001	0918 520 5904 001		45,0	40,64	30,23	2,54 x 9 = 22,86	58,1
24	0918 524 7904 001	0918 524 6904 001	0918 524 5904 001		50,1	45,72	35,91	2,54 x 11 = 27,94	63,2
26	0918 526 7904 001	0918 526 6904 001	0918 526 5904 001		52,6	48,26	37,85	2,54 x 12 = 30,48	65,7
30	0918 530 7904 001	0918 530 6904 001	0918 530 5904 001		58,0	53,34	43,83	2,54 x 14 = 35,56	68,6
34	0918 534 7904 001	0918 534 6904 001	0918 534 5904 001		62,8	58,42	48,01	2,54 x 16 = 40,64	75,8
40	0918 540 7904 001	0918 540 6904 001	0918 540 5904 001		70,4	66,04	55,63	2,54 x 19 = 48,26	83,5
50	0918 550 7904 001	0918 550 6904 001	0918 550 5904 001		83,1	78,74	68,33	2,54 x 24 = 60,96	96,2
60	0918 560 7904 001	0918 560 6904 001	0918 560 5904 001		95,8	91,44	81,03	2,54 x 29 = 73,66	108,9
64	0918 564 7904 001	0918 564 6904 001	0918 564 5904 001		100,9	96,52	86,11	2,54 x 31 = 78,74	113,9

	All rights reserved	Scale 2:1	Free size tol.	Ref.
	Department EC PD - FR	Created by DOUGE	Inspected by BAGDIKIAN	Sub.
HARTING Electronics GmbH D-32339 Espelkamp		Title SEK 18 male STD straight with long levers		
		Type TB	Number 09185XXX904	Doc-Key / ECM-Nr. 100566973/UGD/001/B 500000087654
				Rev. B
				Page 2/2

	All Dimensions in mm Original Size DIN A3		Scale 2:1	Free size tol.		Ref.	
	All rights reserved		Created by DOUGE	Inspected by BAGDIKIAN	Standardisation SCHREIER	Date 2015-04-08	State Final Release
Department EC PD - FR		Title SEK 18 male STD straight with long levers				Doc-Key / ECM-Nr. 100566973/UGD/001/B 500000087654	
HARTING Electronics GmbH D-32339 Espelkamp		Type TB	Number 09185XXX904			Rev. B	Page 2/2