



Color: ■ gray

Electrical data

Ratings per IEC/EN

Rated current	10 A
---------------	------

Physical data

Width	8 mm / 0.315 inches
Height	10 mm / 0.394 inches
Depth	4 mm / 0.157 inches
Jumper assignment	1-2

Material data

Note (material data)	Information on material specifications can be found here
Color	gray
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.005 MJ
Weight	0.4 g

Environmental requirements

Processing temperature	-35 ... +85 °C
Continuous operating temperature	-60 ... +105 °C

Commercial data

Product Group	9 (Std Chassis Mt Blocks)
PU (SPU)	500 (25) pcs
Packaging type	Box
Country of origin	PL
GTIN	4045454030858
Customs tariff number	85366990990

Product Classification

UNSPSC	39121421
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 9.0	EC000489
ETIM 10.0	EC000489
ECCN	NO US CLASSIFICATION

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Downloads





Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 260-402	↓

Documentation

Bid Text			
260-402	19.02.2019	xml 2.62 KB	↓
260-402	17.08.2017	doc 23.50 KB	↓

CAD/CAE-Data

CAD data	CAE data
2D/3D Models 260-402 	EPLAN Data Portal 260-402 
	WSCAD Universe 260-402 
	ZUKEN Portal 260-402 

1 Compatible Products

1.1 Optional Accessories

1.1.1 Tool

1.1.1.1 Operating tool




Item No.: [209-132](#)

Operating tool; for connecting comb-style jumper bar; made of insulating material; 2-way; natural

Installation Notes

Commoning

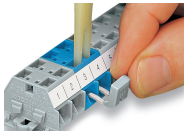

Commoning with comb-style jumper bar.