
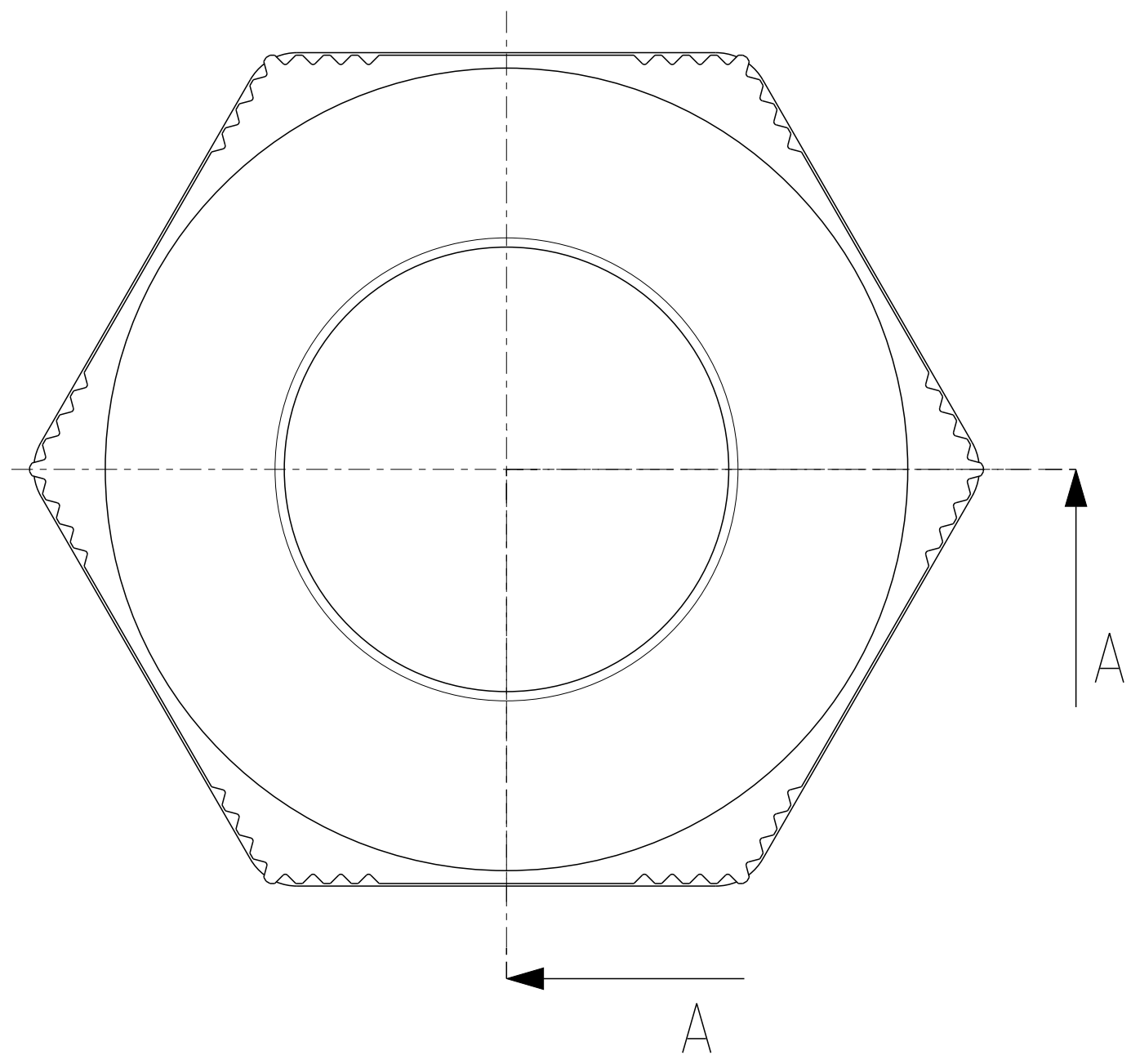


REVISIONS					
P	LT#	DESCRIPTION	DATE	OWN	APPD
	A	INITIAL REVISION	07FEB2022	KR	RM

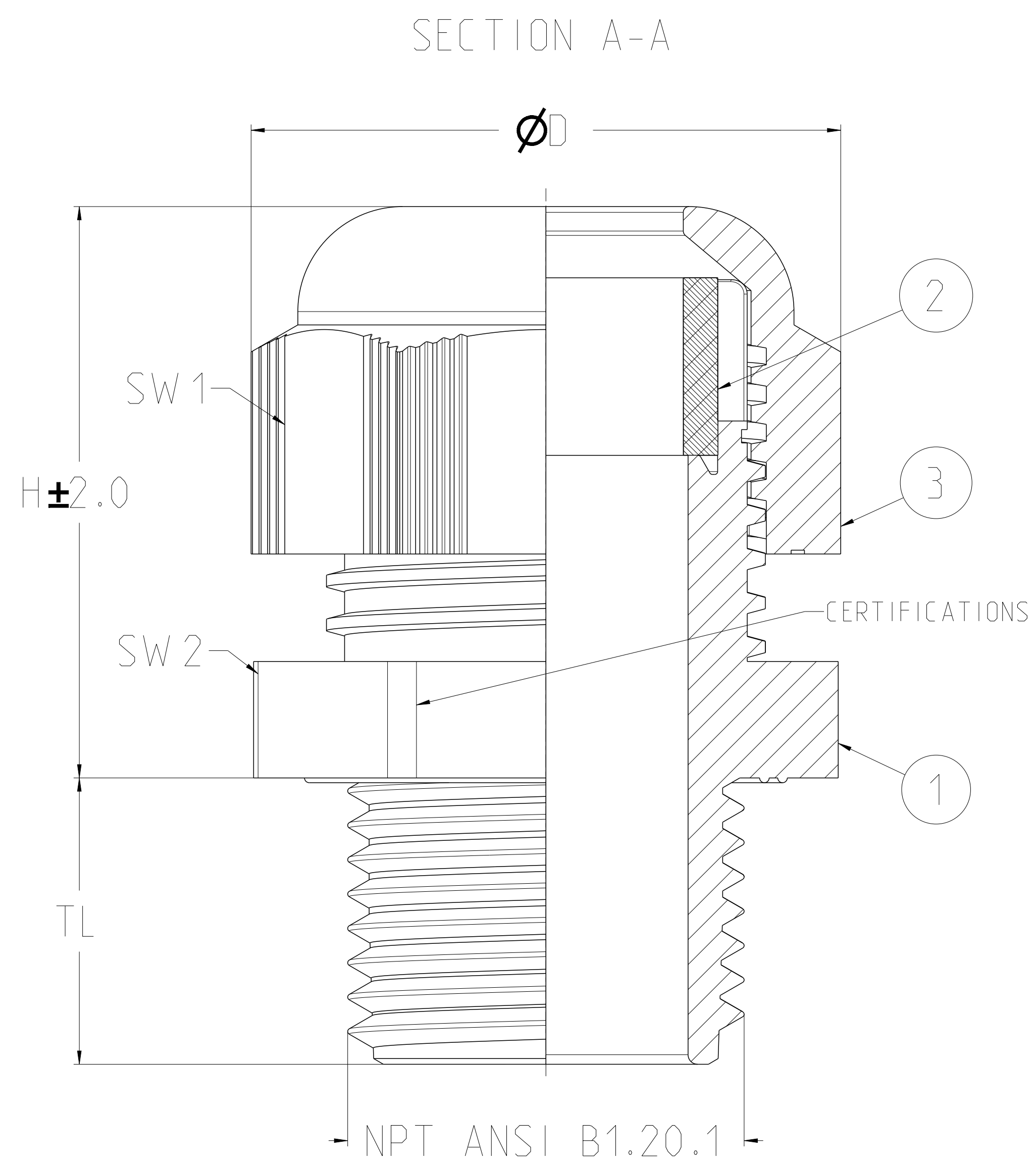

TCPN	TE Product Type (Entrelec)	RAL NUMBER	COLOR	UL RATING	CERTIFICATIONS			NPT ANSI B1.20.1	TL	H	ØD	SW 1	SW 2	Clamping Range Ø min - max
1SNG601151R0000	EP-SG-NPT38-LGR-A	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	3.0 - 7.0
1SNG601152R0000	EP-SG-NPT38-GR-A	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	3.0 - 7.0
1SNG601153R0000	EP-SG-NPT38-BL-A	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	3.0 - 7.0
1SNG601154R0000	EP-SG-NPT38-LGR-B	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	5.0 - 10.0
1SNG601155R0000	EP-SG-NPT38-GR-B	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	5.0 - 10.0
1SNG601156R0000	EP-SG-NPT38-BL-B	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 3/8"	15.0	30.2	25.0	22	22	5.0 - 10.0
1SNG601157R0000	EP-SG-NPT12-LGR-A	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	5.0 - 9.0
1SNG601158R0000	EP-SG-NPT12-GR-A	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	5.0 - 9.0
1SNG601159R0000	EP-SG-NPT12-BL-A	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	5.0 - 9.0
1SNG601160R0000	EP-SG-NPT12-LGR-B	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	6.0 - 12.0
1SNG601161R0000	EP-SG-NPT12-GR-B	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	6.0 - 12.0
1SNG601162R0000	EP-SG-NPT12-BL-B	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	30.4	27.0	24	24	6.0 - 12.0
1SNG601163R0000	EP-SG-NPT12-LGR-C	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	7.0 - 12.0
1SNG601164R0000	EP-SG-NPT12-GR-C	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	7.0 - 12.0
1SNG601165R0000	EP-SG-NPT12-BL-C	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	7.0 - 12.0
1SNG601166R0000	EP-SG-NPT12-LGR-D	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	10.0 - 14.0
1SNG601167R0000	EP-SG-NPT12-GR-D	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	10.0 - 14.0
1SNG601168R0000	EP-SG-NPT12-BL-D	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1/2"	15.0	29.9	30.9	27	27	10.0 - 14.0
1SNG601169R0000	EP-SG-NPT34-LGR-A	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	9.0 - 16.0
1SNG601170R0000	EP-SG-NPT34-GR-A	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	9.0 - 16.0
1SNG601171R0000	EP-SG-NPT34-BL-A	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	9.0 - 16.0
1SNG601172R0000	EP-SG-NPT34-LGR-B	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	13.0 - 18.0
1SNG601173R0000	EP-SG-NPT34-GR-B	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	13.0 - 18.0
1SNG601174R0000	EP-SG-NPT34-BL-B	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 3/4"	15.0	36.4	37.2	33	33	13.0 - 18.0
1SNG601175R0000	EP-SG-NPT1-LGR-A	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	12.0 - 20.0
1SNG601176R0000	EP-SG-NPT1-GR-A	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	12.0 - 20.0
1SNG601177R0000	EP-SG-NPT1-BL-A	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	12.0 - 20.0
1SNG601178R0000	EP-SG-NPT1-LGR-B	7035	L.Grey	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	18.0 - 25.0
1SNG601179R0000	EP-SG-NPT1-GR-B	7001	Grey	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	18.0 - 25.0
1SNG601180R0000	EP-SG-NPT1-BL-B	9005	Black	TYPE 4X	cURus	-	cCSAus	NPT 1"	18.0	41.3	47.1	42	42	18.0 - 25.0

3	1	CAP	-	PA6 V2 (F1 Listed)	-	
2	1	SEAL	-	CR	-	
1	1	BODY	-	PA6 V2 (F1 Listed)	-	
RP	QTY	QDC	TITLE	DRAWING NUMBER	MATERIAL	COMMENTS
THIS DRAWING IS A CONTROLLED DOCUMENT.						
DIMENSIONS: mm		TOLERANCES, UNLESS OTHERWISE SPECIFIED:		 TE Connectivity		
				NAME		
1. PACC		1. PACC		NPT-STD-GLAND-PA		
2. PACC		2. PACC		PRODUCT SPEC		
3. PACC		3. PACC		APPLICATION SPEC		
4. ANGLES		4. ANGLES		SIZE		
5. FINISH		5. FINISH		CHD CODE		
REF. TABLE		CUSTOMER DRAWING		DRAWING NO.		
				RESPECTED TO		
				SCALE		
				SHEET		
				1 of 9		
				REV		
				A0 00779 C=ISNP061306-0100		