


AMO-HSDPA02E

Advantech HSDPA 6Band / MiniPCle,
Cable, Antenna

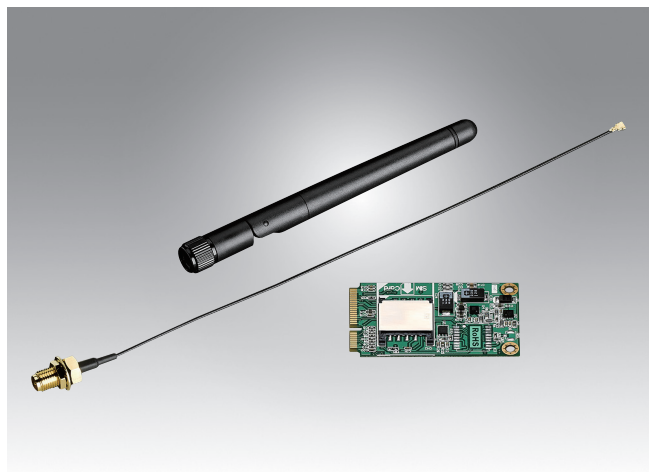

Features

- World wide 6-bands, 800/850/900/1700/1900/2100 MHz for UMTS/HSPA network, 850/900/1800/1900 MHz for EDGE/GPRS/GSM network
- With SIM card holder
- HSDPA 7.2Mbps, HSUPA 5.76Mbps
- Operating temperature : -40 to +85° C

Specifications

Chipset	U-blox LISA-U200
Antenna	1 RF Antenna Coaxial Connectors
Band	UMTS/HSPA: 800/850/900/1700/1900/2100 MHz EDGE/ GPRS/ GSM: 850/ 900/ 1800/ 1900 MHz
Data Rate	Downlink: 7.2 Mbps Uplink: 5.76 Mbps
Interface	PCI Express mini-card rev. 1.2
Operating Voltage	3.3V ~ 3.6V
Power Consumption	< 700 mA (HSPA connected Mode)
OS Support	Windows XP/Vista/7, WinCE 5.0/6.0,Linux 2.4.x/2.6.x, Mac
Operating Temperature	-40 to +85° C
Module Dimension (L x W x H)	50.85 x 29.9 x 6.2 mm

Packing List

Part Number	Description
-	1x 6-band HSPA Cellular Module
-	1x Dipole antenna, 109 mm
-	1x Coaxial GSM/ GPS Cable, 250 mm

Ordering Information

Part Number	Description
AMO-HSDPA02E	Advantech 3.75G HSDPA 6 Band Full-size Mini PCle Card with SIM Card holder

Suggestion Antenna and Cable

Part Number	Description
1750005865	824~960 MHz, 1710~2170 MHz dipole antenna, 109 mm
1750006426	824~960 MHz, 1710~2170 MHz dipole antenna, 169.5 mm
1750005866	Coaxial GSM/ GPS Cable, 100 mm
1750006009	Coaxial GSM/ GPS Cable, 250 mm