

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0887685300](#)
Status: **Active**
Overview: [DMS-59®](#)
Description: 1.27mm Pitch DMS-59®-to-Two DVI-I Adapters Cable Assembly, 0.20m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	88759
Assembly Configuration	Dual Ended Connectors
Connector to Connector	DMS-59™-to-DVI-I
Overview	DMS-59®
Product Name	DMS59®
UPC	756054581629

Physical

Cable Length	0.20m
Circuits (Loaded)	59
Color - Resin	Black
Gender	Male-Female
Lock to Mating Part	Yes
Material - Metal	Aluminum, Phosphor Bronze, Steel
Material - Plating Mating	Gold, N/A
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	132.200/g
Packaging Type	Bag
Pitch - Mating Interface	1.27mm
Plating min - Mating	0.051µm, 0.762µm, 1.905µm
Plating min - Termination	2.540µm, 3.810µm
Single Ended	No
Termination Interface: Style	N/A, Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	32
Wire/Cable Type	Round


Electrical

Current - Maximum per Contact	1.0A
Impedance	100#
Shielded	Yes
Voltage - Maximum	30V AC

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-88744-097
---------------	--------------

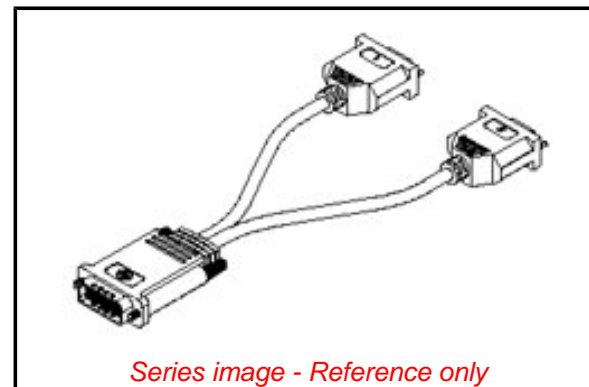

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(a)

REACH SVHC

Not Contained Per - ED/108/2014 (17 Dec 2014)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

Search Parts in this Series

[88759 Series](#)