


P.C. MOUNTING

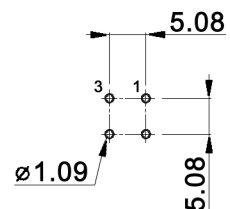

Specifications:

Contact rating:	0.4VA max., 20V max. (AC or DC)
Contact resistance:	20mOhm max.
Insulation resistance:	1 000MOhm min.
Dielectric strength:	1 500V RMS
Operating temperature:	-30°C to +85°C
Electrical life:	30 000 make-and-break cycles
Switching function:	off - mom
Material:	Terminals / movable contact: copper alloy, gold plated over nickel plated
IP rating:	IP67



Tolerances:			Date	Name	TSP 1 C-RA		
			12/09	dr			
			knitter-switch		30 19 73		Page
							1/1
IP rating	04/12	dr					
Modifications	Date	Name					