

Rotary knob switches


Serie 419

Type 419


Basic design: width 19.4 mm, plastic moduled spindle diameter 6 mm

Switching Combinations


1-polig
1 Pole

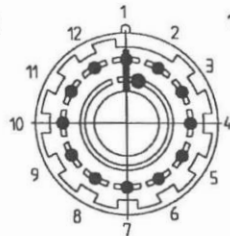


1 x 2 - 1 x 12

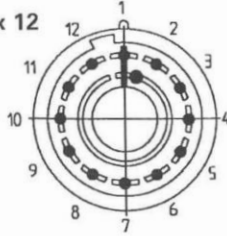


1-polig
durchdrehbar
1 Pole
without stop

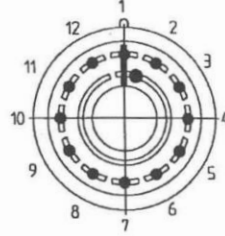


2-polig
2 Pole

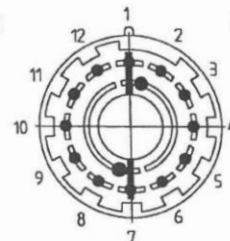


2 x 2 - 2 x 6

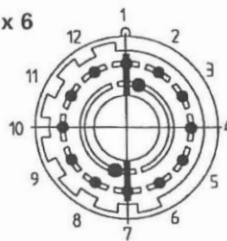


2-polig
durchdrehbar
2 Pole
without stop

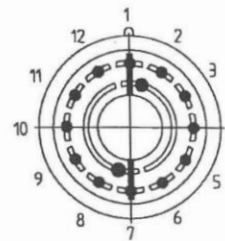


3-polig
3 Pole

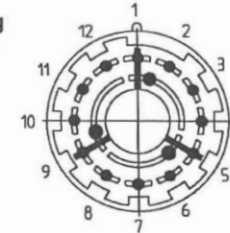


3 x 2 - 3 x 4

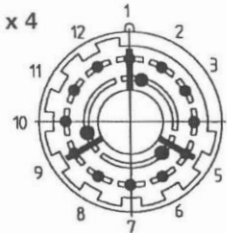


3-polig
durchdrehbar
3 Pole
without stop

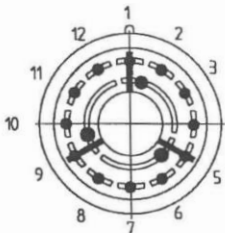


4-polig
4 Pole

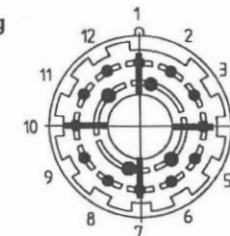


4 x 2 - 4 x 3

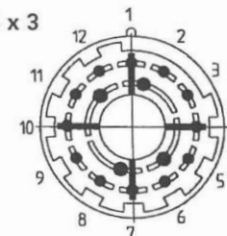

4-polig
durchdrehbar
4 Pole
without stop

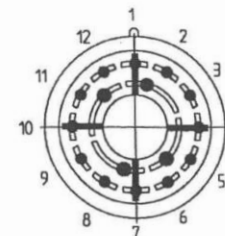


6-polig
6 Pole

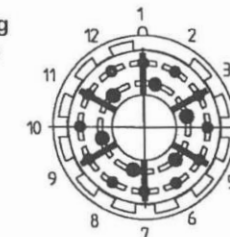

6 x 2



6-polig
durchdrehbar
6 Pole
without stop

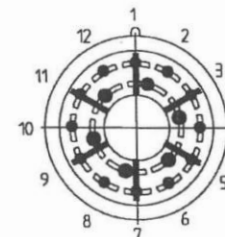

Erläuterung: $2 \times 3 \hat{=}$ 2-polig, 3 Schaltstellungen

Explanation: $2 \times 3 \hat{=}$ 2 Pole, 3 Ways