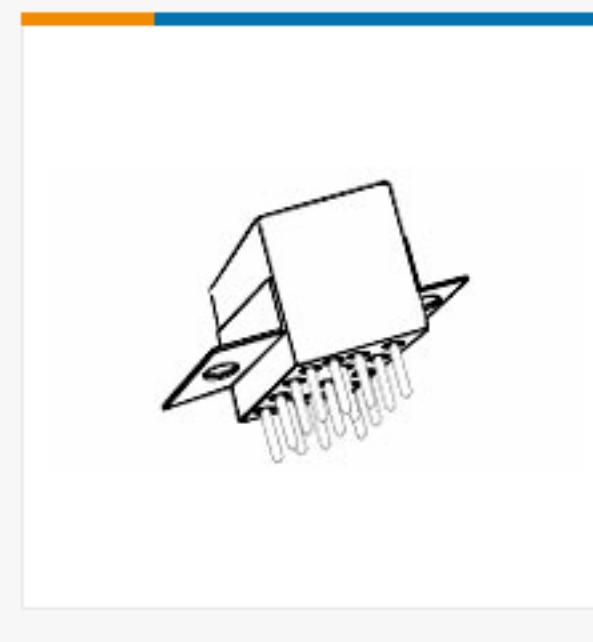


+ RELAYS, CONTACTORS & SWITCHES

MID-RANGE

TE CONNECTIVITY
FCA-415-BY4

CII | FCA 10-25 Amp Relay

FCA-415-BY4

TE Internal Number: 2-1617756-2

Not EU RoHS or ELV Compliant
Find Compliant AlternativesContact Arrangement **4 Form C, 4PDT, 4 C/O**Coil Suppression Diode **With**Auxiliary Contacts **Without**Terminal Plating **Tin-Lead**Contact Current Rating(A) **15**

> See All Features

✓ Active

[PRODUCT DRAWING](#)

English

[3D MODEL](#)

> See All Documentation

North America ▾

[SAVE TO LIST](#)[CHECK FOR TOOLING](#)[FIND SIMILAR PRODUCTS](#)DOCUMENTATION [FEATURES](#)

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type

Relay

Relay Type

Military/Aerospace Mid-Range

Enclosure Type

Hermetically Sealed

Terminal Configuration

Solder Pins

Electrical Characteristics

Coil Suppression Diode

With

Coil Voltage Rating(VDC)

28

Coil Resistance(Ω)

290

Back EMF Suppression

With

Coil Magnetic System

Polarized, Monostable

Vibration

30G's, 70 – 3000Hz

Shock

200G's, 6ms

Actuating System

DC

Contact Features

Contact Arrangement

4 Form C, 4PDT, 4 C/O

Auxiliary Contacts

Without

Terminal Plating

Tin-Lead

Contact Current Rating(A)

15

Contact Base Material

Silver Cadmium Oxide

Mechanical Attachment

Mounting Type

Raised Vertical Flange Mount

Product Compliance

Statement of Compliance

PDF

[VIEW ALL PRODUCT COMPLIANCE](#)

COMPATIBLE

No compatible products found for FCA-415-BY4

Feedback