

Quick Links

Cross reference

RoHS/LF P/N Search

Industry Standards

Alphabetical List

Documentation

3D model search

Customer drawing search


Multi Selection Search

Search by category

Start > Search=10123000-002C-TRLF* > 10123000-002C-TRLF

10123000-002C-TRLF

10123000-002C-TRLF - SAS : 29 Position Vertical Receptacle SMT, 12Gb/s

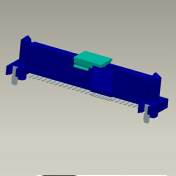

ACTIVE

RoHS Compliant

Distributor Stock

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

Customer drawing

Product Environmental Compliance Report

Specifications

Download document

General Electrical Mechanical Physical Approvals / Certifications Mounting Other Features	
General	
Number of contacts	29
Orientation	Vertical
Retention Feature	SMT Metal Clip
Electrical	
Current rating	1.5A at 30°C
Resistance (Contact)	15 M-ohms max.
Resistance (Insulation)	1000 M-ohms min.
Voltage rating	500V AC
Mechanical	
Durability (Mating cycles)	500 Mating Cycles
Physical	
Color (Housing)	Black
Material (Contact)	Copper Alloy
Material (Housing)	High Temperature Plastic, UL94V-0
Plating (Contact)	30u" Gold
Temperature (Operating - range)	0°C to +55°C
Approvals / Certifications	
Approvals / Certifications	UL
UL File Number	E66906, Sec 99
Mounting	
Termination	Surface Mount
Other Features	
Packaging (Type)	Tape and reel with cap
Type	Receptacle

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.