




CT30125M, Tie, 1.25" Max Bundle, 30 Lb Tensile, Natural

By Burndy
Catalog # [CT30125M](#)

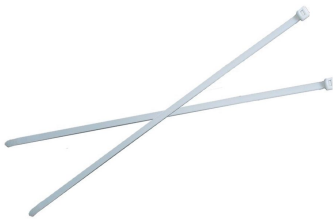

Nylon UNIRAP™ Cable Tie - 30 Lb. Tensile Strength

Features

- Standard Cable Tie
- Suitable for General Use
- Most sizes are available in Natural or Black

Application

For General Purpose

Specifications

Certification - UL Recognized	No
Buy American Compliant	Contact Manufacturer
Certification - cULus	Yes
EU RoHS Indicator	Yes
Buy America(n) Qualified	Contact Manufacturer
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-5-9
Certification - ETL	No
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
Certification - UV Rated	No
UL Listed	No
Certification - CSA Approved	No
Certification - 94VO Rated	N

Dimensions

Package Height	2.000 in
Package Weight	1.570 lb.
Package Length	17.000 in
Package Width	10.100 in
Dimension - L Length Overall mm	146 mm
Width	0.14 in
Length	6 in

Dimension - Width mm	3.6 mm
Dimension - Width inch	0.14 in
Dimension - Length Overall inch	5.75 in
Dimension - Bundle Diameter Max inch	1.25

Force Related

Rating - Minimum Tensile Strength lbs	30
---------------------------------------	----

General

Trade Name	UNIRAP™
Military Specification	MS3367
Color	Natural
Sub Brand	UNIRAP,CABLE TIE
Series	UNIRAP™ Series
UPC	781810331910
Type	Intermediate
Material	Nylon 6/6
UPC 14 Digit GTIN	00781810331910

Logistics

Minimum Pack Quantity	1000
Pallet Quantity	99999
Carton Quantity	5000

Operational

Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C

Product Assets

[Catalog \[English\]](#)