




Search by Part# or Keyword

🔍

[Labels](#) / [Labels by Application](#) / [Barcode Labels](#) /
3" Core Glossy White Polyester Barcode and Solar Panel Labels

3" Core Glossy White Polyester Barcode and Solar Panel Labels



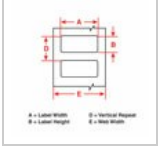

Product Highlights:

Color:

White

Material Number:

B-423 (View Technical Data Sheet)

Finish:

Gloss

For Use with Printer:

BBP®81 Label Printer, BRADY IP® Series
Label Printer, BradyPrinter i5100,
BradyPrinter i7100, BRADYPRINTER PR
Plus Series Label Printer, THT 3" Core
Printer

Material:

Polyester

Label Properties:

Aggressive Adhesive Labels, Harsh
Environment Labels, Heat Resistant Labels,
Permanent Adhesive Labels

Choose your options: [Reset Options](#)

1

Quantity per Row

1

2

Quantity per Roll

10000

3

Label/Tape Size

0.4 IN H X 2 IN W

Part Number:

THT-79-423-10



[View All Options](#)

ADD TO CART

+

-



Add To Favorites

People Also
Viewed



BMP21-PLUS Camo Portable Label Printer - Limited Edition



3" Core Self-Laminating Vinyl Wire and Cable Labels



3" Core High Adhesion Glossy Polyester with Rubber Adhesive Labels



3" Core Glossy White 2 mil Polyimide Circuit Board Labels



Need a different size? Customize it!



Calculate how many labels you can print with one ribbon



Request product certification



Overview

Permanent Polyester (B-423) is ideal for electronic PCB and component identification, bar code labels, rating plates and solar panel identification.

- Glossy white finish with permanent acrylic is thermal transfer printable
- UL approved;CSA accepted
- Meets requirements of a halogen-free material per DIN VDE 0472 part 815
- Service temperature of -94 to 230° F (-70 to 110° C)

Specifications

Key Characteristics		154
	Product Number	30357
	UPC	662820303572
	UOM	Roll of 10000 Labels
	Quantity per Roll	10000
	Unit Price	/Label
	Trade Name	WorkHorse
	Brand Name	Brady®
		Mexico
		8443.99.2550
		EAR99

Dimensions	Sign Size (H x W)	0.4" x 2"
	Dimensions	0.4 in H x 2 in W
	Height	0.4 in
	Width	2 in
	Label/Tape Size	0.4 in H x 2 in W
	Thickness	0.003 in
	Vertical Repeat	0.5 in

Material Characteristics		B-423 (View Technical Data Sheet)
		Polyester
	Label Properties	Aggressive Adhesive Labels, Harsh Environment Labels, Heat Resistant Labels, Permanent Adhesive Labels
	Adhesive Type	Permanent Acrylic
	Finish	Gloss
	Color	White
	Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, UV-Resistant, Weather-Resistant
	Indoor or Outdoor Use	Outdoor Use
	Minimum Service Temperature °F	-94 °F

	Maximum Service Temperature °F	230 °F
	Compatible Surface Types	High Surface Energy

Product Features		Circuit Board Labeling, Component and Equipment Labeling, Inventory and Inspection Labeling
	Shape	Rectangle
	Label/Media Format	Roll
	Ribbon Series	R6000HF
	Quantity per Row	1

Printing Specifications	Print Technology	Thermal Transfer
-------------------------	------------------	------------------

Compatibility	For Use with Printer	BBP®81 Label Printer, BRADY IP® Series Label Printer, BradyPrinter i5100, BradyPrinter i7100, BRADYPRINTER PR Plus Series Label Printer, THT 3" Core Printer
		IP-R6000, R6000

Compliance		55121612
------------	--	----------

Related Items

Support

VIDEOS

[Will It Brady? How Brady's B-425A labels hold up to brake cleaner](#)

LITERATURE

[B-423 Polyester Solves Labeling Challenges](#)

About
Careers
Investors
Do Not Sell My Personal Info
Privacy Policy
Terms and Conditions
ISO Certificates

Distributor Portal
International Sites
Brand Protection Solutions

Contact Us
Customer & Technical
Support
Resource Center
Searchable Support Articles
Certificate Request
Website Feedback

6555 W. Good Hope Rd
Milwaukee, WI 53223

Phone: [888-250-3082](tel:888-250-3082)
Hours: 7:00am–5:00pm CT
Monday–Friday

Brady (NYSE:BRC) is a manufacturer of
complete solutions that identify and

We use cookies to ensure you get the best
experience on our website. [Learn More.](#)

GOT IT!