


223W601-25/225-0 Product Details

 Share  Print  Email

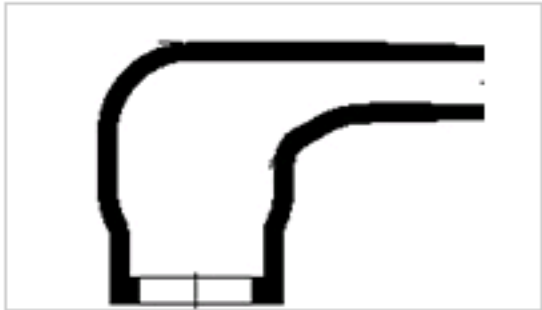

 Active

Molded Parts

223W601-25/225-0

223W601-25/225-0 

TE Internal Number: CX3524-000

- Product Highlights [View All](#)
- VG95343 Parts 6,7,8 and 9
 - Molded Part Type = Molded Boot
 - Molded Part Shape = Bulbous
 - Molded Part Lip = With Lip
 - Operating Temperature = -75 - 150 °C

Pricing & Availability 

Request Sample 

Add to My Part List 

Buy Product through Distributor 

Feedback

Documents

Features

Compliance

Please Note:

Use the Product Drawing for all design activity

Product Type Features	
Molded Part Type 	Molded Boot
Molded Part Shape	Bulbous
Molded Part Lip	With Lip
Angle	90°
Adhesive Description	Unicure Pre-Coated Epoxy Adhesive
Size	01
Family Name	223W6
Color	Black

Mechanical Attachment	
Adhesive Pre-Coating	With

Dimensions	
Cable Diameter Range (mm [in])	6.30 – 10.00 [0.250 – 0.390]
Expanded ID, Min. (mm [in])	10.00 [0.394]
Recovered ID, Max. (mm [in])	6.40 [0.250]

Body Features	
Material	Fluid Resistant Modified Elastomer

Housing Features	
Material Systems Code 	25
Max. Inside Diameter of Part (mm [in])	6.40 [0.250]

Configuration Features	
Material Code	25

Industry Standards	
Government/Industry Qualification	No
Approved Standards	VG95343 Parts 6,7,8 and 9
RoHS/ELV Compliance 	RoHS compliant, ELV compliant
Lead Free Solder Processes 	Not reviewed for lead free solder process
RoHS/ELV Compliance History	Always was RoHS compliant

Environmental	
Operating Temperature (°C)	-75 – +150

Operation/Application	
Application	General Purpose

Purchasing Information	
Adhesive Code	225

Other	
Brand	Raychem

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- About TE
- Investors
- News Room
- Supplier Portal
- Careers
- Terms & Conditions
- Privacy Policy
- Global Accessibility Statement

Quick Links

- Distributor Inventory
- Product Cross Reference
- Documents & Drawings
- Product Compliance Support Center
- Site Map

Customer Support

- Email or Chat With Us
- Find a Phone Number
- Knowledge Base
- Manage Your Account

Keep Me Informed

