


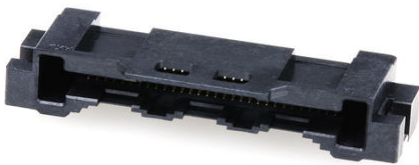

Part Number : [5018643092](#)
Product Description : 0.50mm Pitch Easy-On FFC/
FPC-to-Board Connector, Receptacle Housing
Assembly, Right-Angle, Surface Mount, without
Grounding Terminals, Gold (Au) Plating, 30 Circuits
Series Number : 501864
Status : Active
Product Category : FFC / FPC Connectors



Documents & Resources

Drawings

[5018643092 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

[5018643092.dxf](#)

Specifications

[5018649200-SPK-200.pdf](#)

[PS-501864-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	FFC / FPC Connectors
Series	501864
Description	0.50mm Pitch Easy-On FFC/FPC-to-Board Connector, Receptacle Housing Assembly, Right-Angle, Surface Mount, without Grounding Terminals, Gold (Au) Plating, 30 Circuits
Comments	Requires a custom FFC/FPC with notches
Product Name	Easy-On
UPC	822350783798

Agency

UL	E29179
----	--------

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

Physical

Actuator Type	Flexi-Latch
Circuits (Loaded)	30
Color - Resin	Black
Contact Position	Bottom
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	4.85mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Material - Resin	Liquid Crystal Polymer
Net Weight	673.095/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	Yes
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FFC/FPC

Mates With / Use With

Use with Part(s)

Description	Part Number
0.50mm Pitch FFC-to-Board Plug Jacket, 30 Circuits	<u>5017833009</u>
0.50mm Pitch FFC-to-Board Plug Jacket Cover, 30 Circuits	<u>5017843009</u>

This document was generated on Sep 13, 2025