


- NOTES:
- 1. IDENTIFICATION: ANALOG MAGNETIC DOOR SENSOR WITH RJ45 JACK
 - 2. GENERAL APPEARANCE:
COLOR
BLACK

PART NUMBER	CABLE LENGTH
ZEDL06	500MM

3. PRODUCT SPECIFICATION:
- A. OPERATING TEMERATURE: -40 C - 105 C
 - B. MAX POWER: 10W
 - C. SWITCHING VOLTAGE (MAX): 200VDC
 - D. SWITCHING CURRENT (MAX): 0.5ADC
 - E. CONTACT RESISTANCE (MAX): 200mOHM
 - F. CONTACT TYPE: NORMALLY OPEN
 - G. MAGNETIC SENSITIVITY:
PULL-IN AT RANGE 27-33 AT
ACTIVATE DISTANCE 9.0mm AVERAGE
 - H. MAGNETIC SENSITIVITY DERATES WHEN MOUNTED ON STEEL

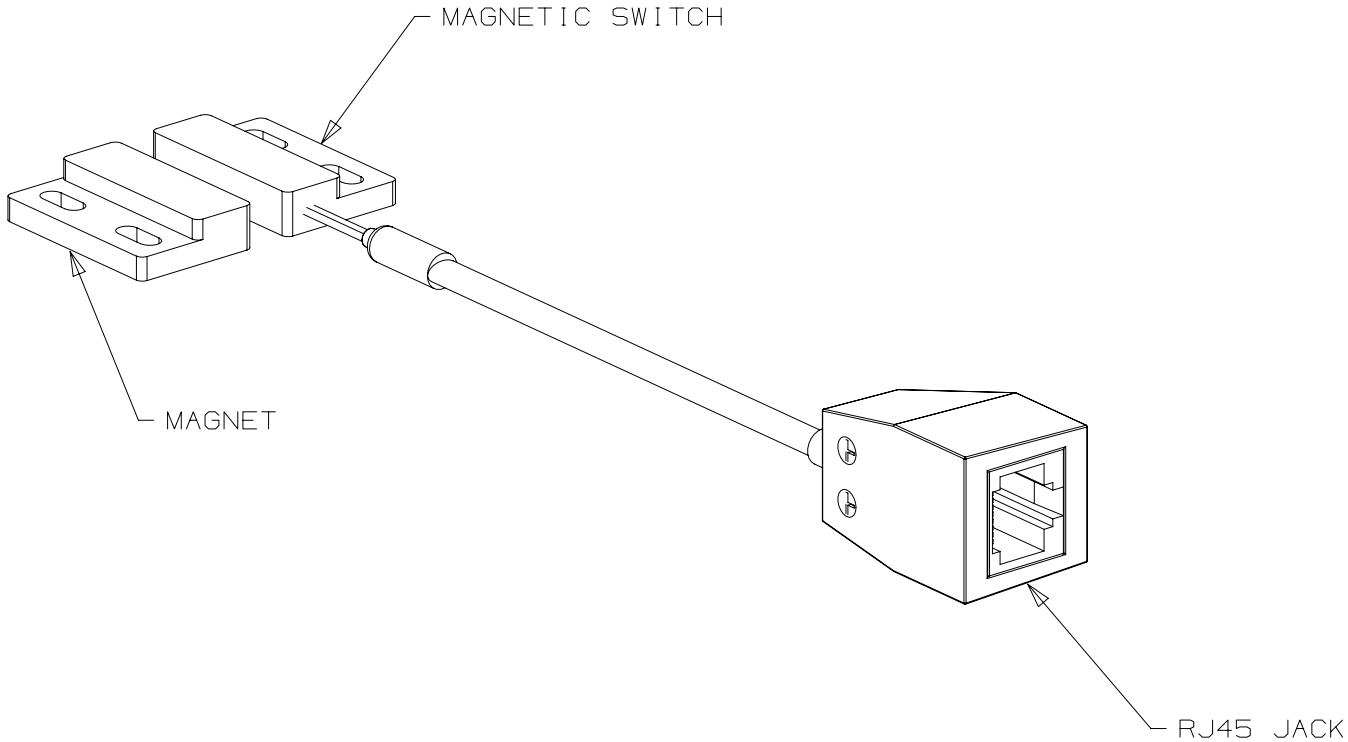

							TITLE			
							MAGNETIC DOOR SENSOR WITH RJ45 JACK			
							CUSTOMER DRAWING			
							ITEM REVISION NAME		14V125BA/00	
							DATASET FILE NAME		14V125BA_DC/00A	
							UNLESS OTHERWISE SPECIFIED, DIMENSIONAL TOLERANCES ARE: IN [mm]		MATERIAL:	
							.X ±		.XXX ±	
							.XX ±		ANGLES ±	
									THIRD ANGLE PROJECTION	
00A	05/09/2017	CSH		EDM	RELEASED TO PRODUCTION	14V125BA	DRAWN BY		DATE	
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN	CSH		05/09/2017	
							CHK		SCALE	
									NTS	
									SHT 1 OF 1	
									SIZE	
									B	