



PART FINDER

FIND NOW

Find faster what you're looking for!

Product Overview

Connectors

Customer specific solutions
D SUB
D SUB accessories
D SUB cover
DVI
Centronics

IDC


Modular
USB
USB 3.0 + USB 3.1
IEEE 1394
Power supply
DIN 41612
DIN 41617
Mini DIN
IC Socket
Pin and female header
LED connectors
Jumper
Connector sleeves
Solder terminals
Test terminals
Terminal Blocks
Memory Card connectors
FFC / FPC connectors
Micro-Miniature
Keystone Jack
Gender Changer
Modular Plug
Waterproof parts

Thermal management

Cable assembly

Capabilities

IT Network Products

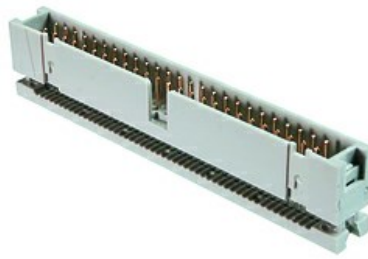

download
technical drawing



download
Product Change Notification



3D view

IDC

AWHC 16-0111-T

IDC

header, pitch 2,54 mm, IDC
16pin, low profile header, AuSn

Part number: AWHC 16-0111-T

product group: IDC

style: header

contact type: IDC

pin count: 16

pitch in mm: 2,54

current rating: 3A

version: low profile header

plating: AuSn

packaging: tray

process: IDC

insulator: PBT UL94V-0



USB 3.1 Cable Assemblies with PD-funktion

Download the Newsletters



MORE NEWS 



Company Film

Watch our company video!

[START WATCHING](#)

Contact

1840 W. Drake Drive, Suite 101
Tempe AZ, A
+1 (480) 8977 001
info@assmann-wsw-usa.com

[TO CONTACT](#)



 PART FINDER

 IMPRINT

 SITEMAP

 TERMS & CONDITIONS

 PRIVACY POLICY

 PRINT

 RECOMMEND