


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	30-01226	Wire, 2C BC, 24 AWG, UL20280, 300V, 80C, 4.3mm, braided shield, FT2, TPU	1	

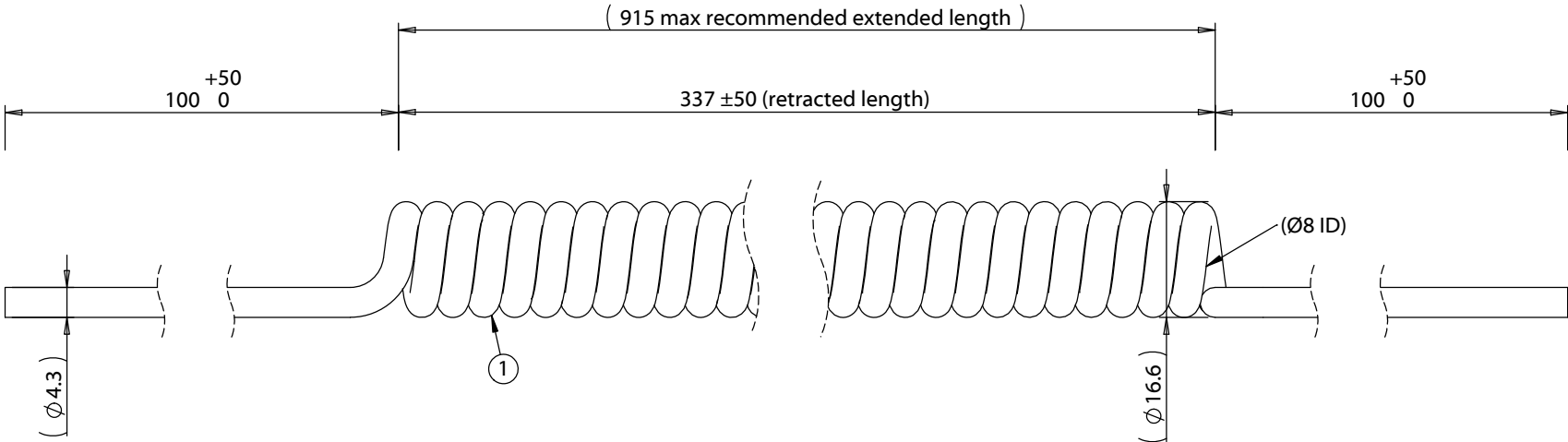

Notes:
Total wire length for resistance calculation: 3250 mm

Revision:	Date:	Description:	Prepared:	Notes: RoHS and REACH compliant Phthalate and halogen free Function test: no open, no short circuit, no intermittent	TENSILITY tel 1.541.323.3228800 877.670.7118 fax 1.541.323.4202web tensility.com		
A	10/17/2018	Initial release	Verified:				
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Coiled cable, 1115 mm, 2C blunt cut to same, 24 AWG, 4.3 mm, TPU, shielded, 30-01226 wire	Size:	Part number:	
					A	31-00009	
					Scale:	1:1	