


3-1985844-0 Product Details

Share Print Email

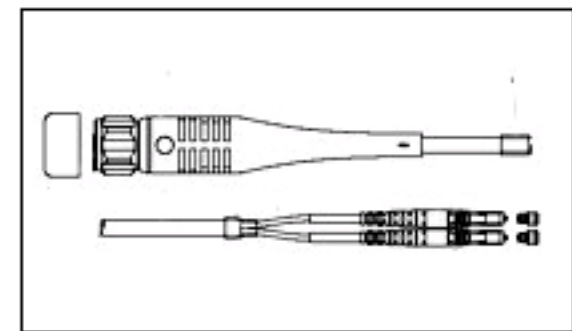

3-1985844-0

TE Internal Number: 3-1985844-0
Active

Fiber Optic Cable Assemblies

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Duplex Fiber
 - Cable Assembly
 - FOKIT ODC™ Fiber Optic Cable Connector Type, LC Fiber Optic Cable Connector Type
 - Fiber Type = 9/125 Micron
 - Cable Assembly Type = FOKIT ODC™ to LC Duplex
- View all Features

Quick Links

- Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product

Add to My Part List Request Sample Find Similar Products Buy Product

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none">FIBER OPTIC ODC LEAD 2 FOLD PLUG - LC DUPLEX SINGLE ... (PDF, English) <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none">None Available <p>Product Specifications:</p> <ul style="list-style-type: none">None Available <p>Application Specifications:</p> <ul style="list-style-type: none">None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none">None Available <p>CAD Files:</p> <ul style="list-style-type: none">None Available	<p>Related Products:</p> <ul style="list-style-type: none">Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none">Product Designation = Duplex FiberProduct Type = Cable AssemblyFiber Optic Cable Connector Type = FOKIT ODC™, LCCable Assembly Type = FOKIT ODC™ to LC DuplexCable Type = FOCAB ODC™ <p>Termination Features:</p> <ul style="list-style-type: none">Fiber Type (Micron) = 9/125 <p>Dimensions:</p> <ul style="list-style-type: none">Cable Diameter (mm [in]) = 5.50 [.216]Length (M [ft]) = 300.00 [984.25] <p>Body Features:</p> <ul style="list-style-type: none">Cable Color = BlackConnector Color = Black, BlueBoot Body Style - Left = StandardBoot Color - Left = BlackBoot Body Style - Right = StandardBoot Color - Right = BlueProtective Cap = With	<p>Contact Features:</p> <ul style="list-style-type: none">Fibre Channel = No <p>Configuration Features:</p> <ul style="list-style-type: none">Mode = SinglemodeNumber of Fibers = 2Cable Buffering = Tight BufferedConnector(s) Exit Angle to Connector(s) Exit Angle = 180° to 180° <p>Industry Standards:</p> <ul style="list-style-type: none">RoHS/ELV Compliance = RoHS compliant, ELV compliantLead Free Solder Processes = Not relevant for lead free processRoHS/ELV Compliance History = Always was RoHS compliant <p>Product Availability:</p> <ul style="list-style-type: none">Region = Not Specified <p>Other:</p> <ul style="list-style-type: none">Brand = TE Connectivity

Corporate Information

About TE
Investors
News Room
Supplier Portal
Careers
Terms & Conditions
Privacy Policy
Global Accessibility Statement

Quick Links

Distributor Inventory
Product Cross Reference
Documents & Drawings
Product Compliance Support Center
Site Map

Customer Support

Email or Chat With Us
Find a Phone Number
Knowledge Base
Manage Your Account

Keep Me Informed

