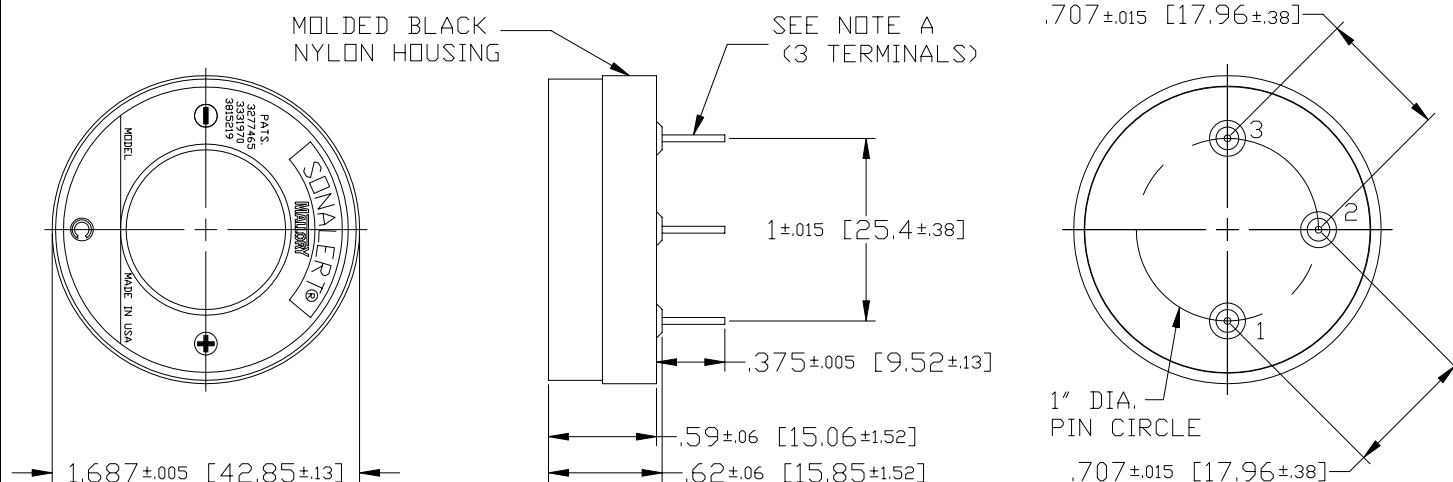


**Specifications:**

|                         |                                    |
|-------------------------|------------------------------------|
| Sound level Category    | Medium Sound Level                 |
| Mode of Operation       | Continuous tone                    |
| Mounting                | Printed Circuit Board (see note B) |
| Voltage Rating          | 4 - 28 Vdc                         |
| Frequency               | 2900 Hz $\pm$ 500 Hz               |
| Loudness (Min. Voltage) | 64 dB(A) min. @ 2 FT and 4 Vdc     |
| Loudness (Max Voltage)  | 78 dB(A) min. @ 2FT and 28 Vdc     |
| Current Draw            | 3 mA Max @ 4 Vdc                   |
| Current Draw            | 16 mA Max @ 28 Vdc                 |
| Storage Temperature     | -40°C to +85°C                     |
| Operating Temperature   | -30°C to +65°C                     |
| Weight (Typical)        | 0.6 oz (17 g)                      |
| Housing                 | 6/6 Nylon, Color Black             |
| Options                 | For other options contact factory  |

**Dimensions:** Inches (mm)**UL Recognized** **NOTE A:**

TERMINALS - .031" DIA. SOLDER COATED COPPER-CLAD STEEL. TERMINAL 1 IS POSITIVE, TERMINAL 3 IS NEGATIVE. TERMINAL 2 IS FOR SUPPORT ONLY - NO ELECTRICAL CONNECTION.

**NOTE B:**

MOUNTING - INSERT INTO PRINTED CIRCUIT BOARD AND HAND OR MACHINE SOLDER.