


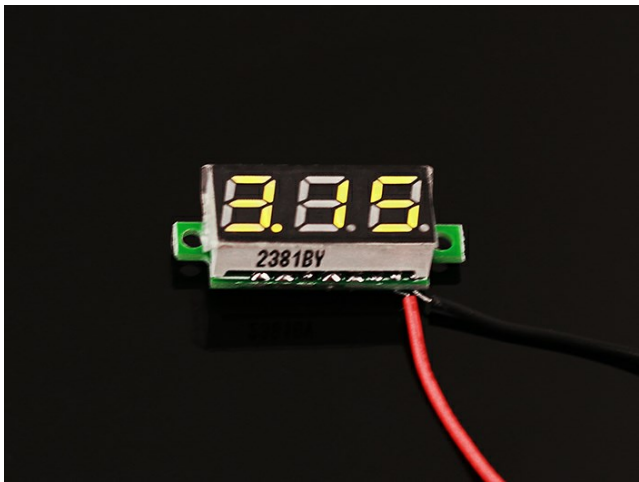

0.28 Inch LED digital DC voltmeter - Yellow

SKU 114990165     

IN STOCK 10 Available

– 1 +

ADD TO CART

- Description
- Best-sellers
- Technical Details
- Questions and Answers
- View History

Description

This is a super mini voltmeter with 0.28inch LED display. It has reverse connect protection function. When voltage is less than 10V, two decimal places will be shown. When voltage is more than 10V, one decimal place will be shown. This voltmeter can be used to measure mobile phone battery ,car battery and such other application.

SPECIFICATION

- Voltage range: 2.5~ 30V
- Work current: <30mA
- Size: 30x11.7x9.2 mm
- Measure speed: 200ms/one time
- Accuracy: 3%

Best-sellers




0.28 Inch LED digital DC vo...



0.28 Inch LED digital DC vo...



0.28 Inch LED digital DC vo...

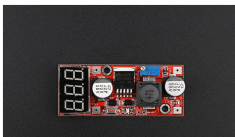

Adjustable DC&DC Power ...

Technical Details

Dimensions	60mm x 60mm x 10.5mm
Weight	G.W 5g
Battery	Exclude

Questions and Answers

Have a question about this? Ask people who own it.



View History



Dragino Yun Shield



3V Mini Pressure Pump



Breakout Kit for Rasperr...



RF Explorer Signal Genera...

POPULAR SEARCHES

- PCB Manufacturing
- PCB Stencil
- Arduino
- XBee
- Arduino Shield
- Beaglebone Black
- Raspberry Pi
- Raspberry Pi Touchscreen
- Linkit
- Cubieboard
- Beaglebone Cape
- FPGA
- Linkit ONE
- Crazyflie 2.0
- Raspberry Pi 3 Model B
- RF Explorer
- DSO Nano v3
- MediaTek X20
- HiKey Board
- rplidar
- raspberry pi relay
- RPLIDAR A2



SHIPPING INFORMATION



KNOWLEDGE BASE



HELP CENTER

Seed Info

- Reach Us
- Distributors
- Designers
- Careers
- Site Map

Customer Service

- Contact Us
- Customer Support
- Technical Support

Terms and Conditions

- Order Information
- Shipping Information
- Payment Information
- Warranty and Return
- Terms of use
- Privacy Policy

Stay Tuned

Subscribe to get the latest product releases, activities and tutorials from Sseed Studio.

email address

>

-
-
-
-
-