



# HIRSCHMANN

A BELDEN BRAND

## Product information MAB 5 S


Industrial Connecting Solutions: Circular Connectors: Audio/Video Connectors: DIN EN 60 130-09 Connectors (MAS/MAK series): without locking screw: Panel-mounted sockets: MAB 5 S

<https://catalog.beldensolutions.com:443/link/57078-24228-256281-256282-24384-24385-24386-34458/en/conf/ui/state>

| Name                         | MAB 5 S                                        |
|------------------------------|------------------------------------------------|
|                              |                                                |
|                              | panel-mounted socket with flange; solder joint |
| Delivery informations        |                                                |
| Availability                 | available                                      |
| Product description          |                                                |
| Type                         | MAB 5 S                                        |
| Order No.                    | 930 071-200                                    |
| Type of contact              | female                                         |
| Description                  | panel-mounted socket with flange; solder joint |
| Number of contacts           | 5                                              |
| Conductor size               | $\leq 0.34 \text{ mm}^2$                       |
| Technical data               |                                                |
| LF output "Phone"            | EN 60 130-09                                   |
| Pole arrangement DIN         | DIN 41 524                                     |
| Rated current                | 4 A                                            |
| Rated voltage                | AC/DC 34 V                                     |
| Type of termination          | solder                                         |
| Material                     |                                                |
| Contact material (socket)    | brass                                          |
| Contact surface material     | tin plated                                     |
| Contact bearer material      | PA 66/UL standard 94V-2                        |
| Housing material             | steel, nickel-plated                           |
| Environmental conditions     |                                                |
| Protection class (IEC 60529) | IP 30                                          |
| Temperature range            | -20 °C to +60 °C                               |

Picture

Drawing

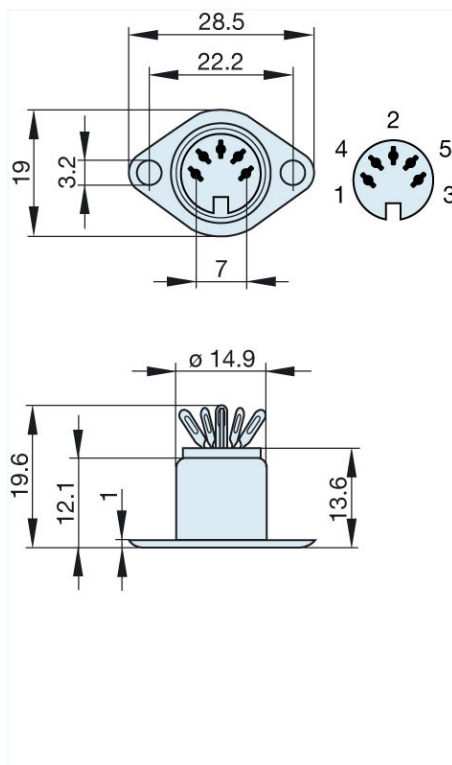

**Belden Deutschland GmbH**  
Im Gewerbepark 2  
58579 Schalksmühle  
Germany  
Phone: +49 7127/14-1806  
E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.