

# PTF 0,3/ 4-FLEX-I-8 - PCB



1848477

<https://www.phoenixcontact.com/us/products/1848477>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

PCB direct plug, color: white, number of positions: 4, product range: PTF 0,3/...-Flex, pitch: 1.8 mm, type of packaging: packed in cardboard



## Your advantages

- Extension for implementing complex arrangements of flexible LED printed-circuit boards
- Easy connection of flexible LED printed-circuit boards
- Minimal heating during operation
- UL-approved materials

## Commercial data

Item number	1848477
Packing unit	20 pc
Minimum order quantity	20 pc
Sales key	AA08
Product key	AAHRCA
GTIN	4055626282206
Weight per piece (including packing)	0.397 g
Weight per piece (excluding packing)	0.362 g
Customs tariff number	85340019
Country of origin	CN

# PTF 0,3/ 4-FLEX-I-8 - PCB



1848477

<https://www.phoenixcontact.com/us/products/1848477>

## Technical data

### Product properties

Product type	PCB direct plug
Product family	PTF 0,3/..-Flex
Number of positions	4
Pitch	1.8 mm

### Data management status

Article revision	02
------------------	----

### Mounting

Mounting type	PCB connector
---------------	---------------

### Material specifications

Color (Housing)	white (RAL 9010)
-----------------	------------------

### Dimensions

Dimensional drawing	
Width	8 mm
Length	17 mm
Pitch	1.8 mm

### Packaging specifications

Type of packaging	packed in cardboard
-------------------	---------------------

# PTF 0,3/ 4-FLEX-I-8 - PCB


1848477

<https://www.phoenixcontact.com/us/products/1848477>



## Drawings

Dimensional drawing

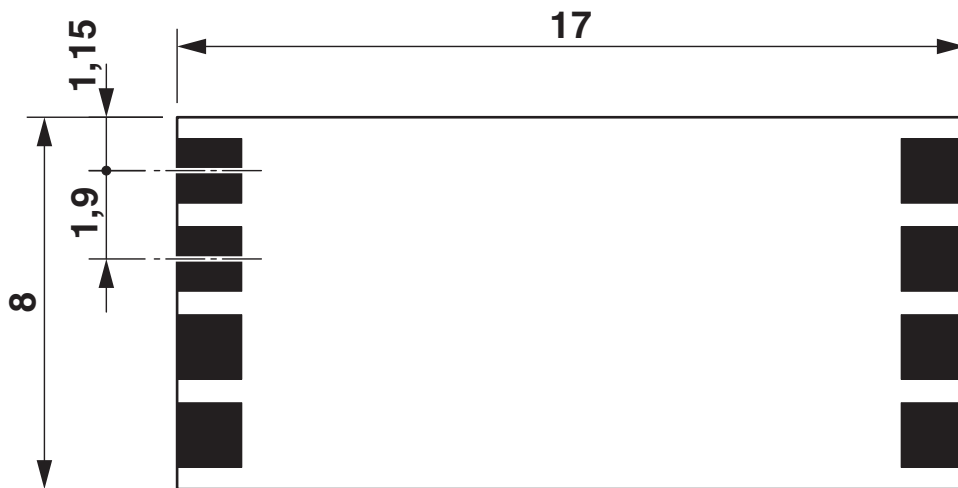

# PTF 0,3/ 4-FLEX-I-8 - PCB



1848477

<https://www.phoenixcontact.com/us/products/1848477>

## Classifications

### ECLASS

ECLASS-11.0	27460201
ECLASS-12.0	27460201
ECLASS-13.0	27460201

### ETIM

ETIM 8.0	EC002637
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# PTF 0,3/ 4-FLEX-I-8 - PCB

1848477

<https://www.phoenixcontact.com/us/products/1848477>



## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
-----------------------------------------	--------------------

### China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

# PTF 0,3/ 4-FLEX-I-8 - PCB

1848477

<https://www.phoenixcontact.com/us/products/1848477>



## Accessories

### PTF 0,3/ 2-WB-8-H - Cable set

1707558

<https://www.phoenixcontact.com/us/products/1707558>




Assembled PCB connector, Cable 1: cable length: 0.5 m, Color: red, black, Cable type:PVC litz wire, PVC litz wire

### PTF 0,3/ 4-BB-8-H - PCB connector

1707559

<https://www.phoenixcontact.com/us/products/1707559>

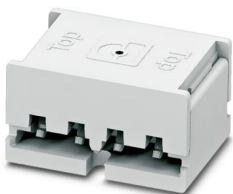

PCB direct plug, nominal cross section: 0.34 mm<sup>2</sup>, color: white, rated voltage (III/2): 25 V, contact surface: Tin, contact connection type: Socket, number of potentials: 4, number of rows: 1, number of positions: 4, number of connections: 4, product range: PTF 0,3/..-BB-H, pitch: 1.9 mm, mounting: Direct plug-in method, plug-in system: COMBICON PTF, type of packaging: packed in cardboard, For flexible PCBs with a width of 8 mm and a permissible PCB thickness in the contact zone of 0.15 mm ... 0.3 mm

# PTF 0,3/ 4-FLEX-I-8 - PCB

1848477

<https://www.phoenixcontact.com/us/products/1848477>



## PTF 0,3/ 4-WB-8-H - Cable set

1707561

<https://www.phoenixcontact.com/us/products/1707561>



Assembled PCB connector

---

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)