


**OMNIMATE Signal - series BL/SL 5.08
SL 5.08HC/10/180LF 3.2SN OR BX**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

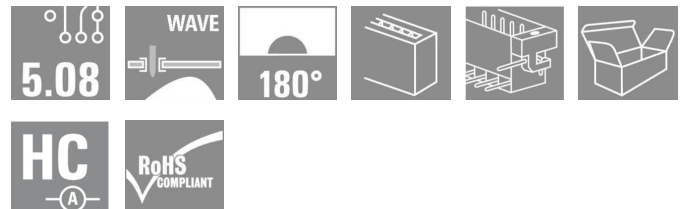

Pin headers in glass-fibre-reinforced plastic with straight wire outlet; optimised for wave soldering. The flange variant (F) can be screwed onto the respective counter piece or the circuit board. There is no need for an extra screw to connect the circuit board when the solder flange (LF) version is used. This also protects the solder points from mechanical strain. All pin headers can be manually coded or ordered pre-coded. HC = High Current.

General ordering data

Type	SL 5.08HC/10/180LF 3.2SN OR BX
Order No.	1148150000
Version	PCB plug-in connector, male header, Solder flange, THT solder connection, 5.08 mm, No. of poles: 10, 180°, Solder pin length (l): 3.2 mm, tinned, Orange, Box
GTIN (EAN)	4032248931842
Qty.	50 pc(s).
Product data	IEC: 400 V / 24 A UL: 300 V / 18.5 A
Packaging	Box

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Dimensions and weights

Net weight	4.94 g
------------	--------

System specifications

Product family	OMNIMATE Signal - series BL/SL 5.08	Mounting onto the PCB	THT solder connection
Pitch in mm (P)	5.08 mm	Pitch in inches (P)	0.2 inch
Outgoing elbow	180°	No. of poles	10
Number of solder pins per pole	1	Solder pin length (l)	3.2 mm
Solder pin length tolerance	+0.1 / -0.3 mm	Tolerance of solder pin position	± 0.15 mm
Solder pin dimensions	d = 1.2 mm, Octagonal	Solder pin dimensions = d tolerance	0 / -0.03 mm
Solder eyelet hole diameter (D)	1.3 mm	Solder eyelet hole diameter tolerance (D)	+ 0.1 mm
L1 in mm	45.72 mm	L1 in inches	1.8 inch
Number of rows	1	Pin series quantity	1
Can be coded	Yes	Plugging cycles	25
Packaging	Box		

Material data

Insulating material	PA GF	Colour	Orange
Colour chart (similar)	RAL 2000	Insulating material group	II
CTI	≥ 550	Insulation resistance	≥ 10 ⁸ Ω
UL 94 flammability rating	V-0	Contact material	Cu-Leg
Contact surface	tinned	Layer structure of solder connection	1-3 µm Ni / 2-4 µm Sn matt
Layer structure of plug contact	1-3 µm Ni / 2-4 µm Sn matt	Storage temperature, min.	-25 °C
Storage temperature, max.	55 °C	Max. relative humidity during storage	80 %
Operating temperature, min.	-50 °C	Operating temperature, max.	100 °C
Temperature range, installation, min.	-25 °C	Temperature range, installation, max.	100 °C

Rated data acc. to IEC

tested acc. to standard	IEC 60664-1, IEC 61984	Rated current, min. no. of poles (Ta = 20°C)	24 A
Rated current, max. no. of poles (Ta = 20°C)	19 A	Rated current, min. no. of poles (Ta = 40°C)	21 A
Rated current, max. no. of poles (Ta = 40°C)	16.5 A	Rated voltage for surge voltage class / pollution degree II/2	400 V
Rated voltage for surge voltage class / pollution degree III/2	320 V	Rated voltage for surge voltage class / pollution degree III/3	250 V
Rated impulse voltage for surge voltage class/ pollution degree II/2	4 kV	Rated impulse voltage for surge voltage class/ pollution degree III/2	4 kV
Rated impulse voltage for surge voltage class/ contamination degree III/3	4 kV		

Rated data acc. to CSA

Rated voltage (Use group B)	300 V	Rated voltage (use group D)	300 V
Rated current (use group B)	18.5 A	Rated current (use group D)	18.5 A

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Technical data

Rated data acc. to UL 1059

Institute (cURus)



Certificate No. (cURus)

E60693

Rated voltage (use group B)

300 V

Rated voltage (use group D)

300 V

Rated current (use group B)

18.5 A

Rated current (use group D)

10 A

Reference to approval values

Specifications are
maximum values, details -
see approval certificate.

Classifications

ETIM 4.0

EC002637

ETIM 5.0

EC002637

ETIM 6.0

EC002637

eClass 6.2

27-26-07-04

eClass 7.1

27-44-04-02

eClass 8.1

27-44-04-02

eClass 9.0

27-44-04-02

eClass 9.1

27-44-04-02

Notes

Notes

- Additional colours on request
- Gold-plated contact surfaces on request
- Rated current related to rated cross-section & min. No. of poles.
- P on drawing = pitch
- Rated data refer only to the component itself. Clearance and creepage distances to other components are to be designed in accordance with the relevant application standards.

IPC conformity

The products are developed, manufactured and delivered according to the internationally recognised IPC-A-610 standard, category "permissible". More extensive demands on the products can be evaluated on request.

Approvals

Approvals



ROHS

Conform

Downloads

EDA Layout Library (Mentor Graphics
Expedition, Mentor Graphics Pads,
Altium Designer)

[Select your download](#)





Safety notice

[Safety indication](#)

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Drawings

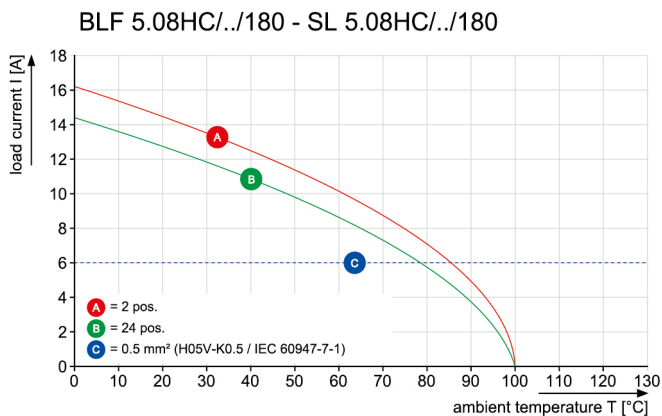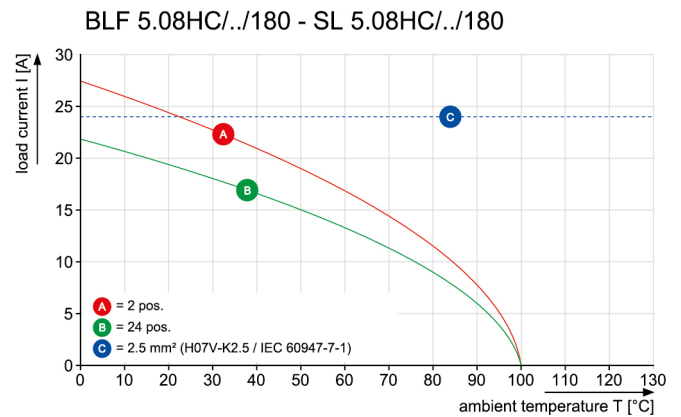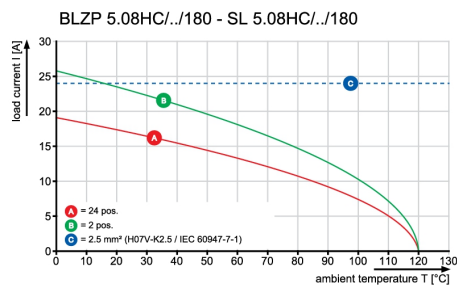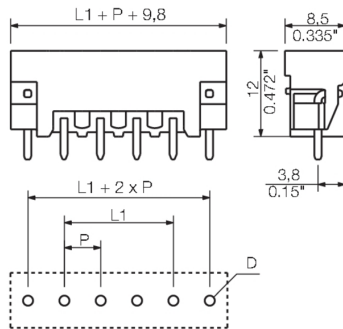

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

BLF 5.08HC/90LR SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF 5.08HC/10/90LR SN BK BX	1000490001	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248690459 30 pc(s).		IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box
BLF 5.08HC/10/90LR SN OR BX	1002360000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248694525 30 pc(s).		IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box

BLT 5.08HC/180LR



Female plugs with TOP screw connection system for connecting wires with straight wire outlet and release latch mechanism. The female connectors provide space for labelling and can be coded. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLT 5.08HC/10/180LR SN OR BX	1890300000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, TOP connection, Clamping	4032248498789 30 pc(s).		IEC: 400 V / 27 A / 0.2 - 2.5 mm ² UL: 300 V / 17 A / AWG 26 - AWG 14	Box

Creation date November 16, 2016 10:55:57 AM CET

Catalogue status 04.11.2016 / We reserve the right to make technical changes.

5

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

range, rated connection, max.: 2.5 mm ² , Box				
Discontinued	2016-04-08T00:00:00+02:00	BLT 5.08HC/10/180LR SN 1894210000 BK BX	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, TOP connection, Clamping range, rated connection, max.: 2.5 mm ² , Box	4032248508556 30 pc(s).

BLF 5.08HC/180F SN



Just as reliable as the millionfold proven original and featuring innovative details:
The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.
In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF 5.08HC/10/180F SN BK BX	1012730000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248720378	30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box
BLF 5.08HC/10/180F SN OR BX	1013170000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248720927	30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

BLT 5.08HC/180F



Female plugs with TOP screw connection system for connecting wires with straight outlet direction and screw flange. The female connectors provide space for labelling and can be coded. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLT 5.08HC/10/180F SN BK BX	1844300000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, TOP connection, Clamping range, rated connection, max.: 2.5 mm², Box	4032248356232	30 pc(s).	IEC: 400 V / 27 A / 0.2 - 2.5 mm² UL: 300 V / 17 A / AWG 26 - AWG 14	Box
BLT 5.08HC/10/180F SN OR BX	1844070000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, TOP connection, Clamping range, rated connection, max.: 2.5 mm², Box	4032248355990	30 pc(s).	IEC: 400 V / 27 A / 0.2 - 2.5 mm² UL: 300 V / 17 A / AWG 26 - AWG 14	Box

BLZP 5.08HC/180F SN



Female plug with clamping-yoke screw system for connecting wires with straight (180°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLZP 5.08HC/10/180F SN OR BX	1944170000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm², Box	4032248618750	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm² UL: 300 V / 20 A / AWG 30 - AWG 12	Box
BLZP 5.08HC/10/180F SN BK BX	1944410000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, Clamping yoke connection, Clamping range, rated	4032248618989	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm² UL: 300 V / 20 A / AWG 30 - AWG 12	Box

Creation date November 16, 2016 10:55:57 AM CET

Catalogue status 04.11.2016 / We reserve the right to make technical changes.

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

connection, max.: 4 mm²,
Box

BLL 5.08/90FI



Female header for PCB mounting. The solder pin length is optimised for wave flow soldering.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLL 5.08/10/90FI 3.2SN OR BX	1843830000	PCB plug-in connector, female header, Inverted flange, THT solder connection, 5.08 mm, No. of poles: 10, 90°, Solder pin length (l): 3.2 mm, tinned, Orange, Box	4032248355587	30 pc(s).	IEC: 400 V / 23 A UL: 300 V / 15 A	Box

BLZP 5.08HC/90LR



Female plugs with clamping-yoke connection for connecting wires with a right-angle (90° or 270°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Delivery status Available until	Type	Order No.	Version	GTIN (EAN)	Qty.
Discontinued 2016-04-08T00:00:00+02:00	BLZP 5.08HC/10/90LR SN BK BX	1087110000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box	4032248853755	30 pc(s).
BLZP 5.08HC/10/90LR SN OR BX	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, Clamping yoke connection, Clamping	4032248854028	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box

Creation date November 16, 2016 10:55:57 AM CET

Catalogue status 04.11.2016 / We reserve the right to make technical changes.

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

range, rated connection,
max.: 4 mm², Box

BLZP 5.08HC/90F SN



Female plugs with clamping-yoke connection for connecting wires with a right-angle (90° or 270°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLZP 5.08HC/10/90F SN OR BX	1949880000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box	4032248627806	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box
BLZP 5.08HC/10/90F SN BK BX	1950120000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 90°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box	4032248628056	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

BLF 5.08HC/180LR SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF 5.08HC/10/180LR SN BK BX	1014210000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248723133	30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box
BLF 5.08HC/10/180LR SN OR BX	1014460000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box	4032248722907	30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box

BLZP 5.08HC/180LR SN



Female plug with clamping-yoke screw system for connecting wires with straight (180°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLZP 5.08HC/10/180LR SN BK BX	1945140000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 180°, Clamping yoke connection, Clamping range, rated	4032248620289	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box

Creation date November 16, 2016 10:55:57 AM CET

Catalogue status 04.11.2016 / We reserve the right to make technical changes.

10

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

		connection, max.: 4 mm ² , Box		
BLZP	1944910000	PCB plug-in connector,	4032248619962 30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm ² Box
5.08HC/10/180LR		female plug, 5.08 mm,		UL: 300 V / 20 A / AWG 30 - AWG 12
SN OR BX		No. of poles: 10, 180°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box		

BLF 5.08HC/90F SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF	1000300001	PCB plug-in connector,	4032248690268 30 pc(s).		IEC: 400 V / 24 A / 0.2 - 2.5 mm ²	Box
5.08HC/10/90F		female plug, 5.08 mm, No.			UL: 300 V / 18.5 A / AWG 26 - AWG	
SN BK BX		of poles: 10, 90°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box			12	
BLF	1002170000	PCB plug-in connector,	4032248694327 30 pc(s).		IEC: 400 V / 24 A / 0.2 - 2.5 mm ²	Box
5.08HC/10/90F		female plug, 5.08 mm, No.			UL: 300 V / 18.5 A / AWG 26 - AWG	
SN OR BX		of poles: 10, 90°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm ² , Box			12	

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmüller.com

Mating connector (fully pluggable)

BLZP 5.08HC/270LR SN



Female plugs with clamping-yoke connection for connecting wires with a right-angle (90° or 270°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLZP 5.08HC/10/270LR SN BK BX	1947840000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm², Box	4032248624331	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm² UL: 300 V / 20 A / AWG 30 - AWG 12	Box
BLZP 5.08HC/10/270LR SN OR BX	1947610000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm², Box	4032248623907	30 pc(s).	IEC: 400 V / 23 A / 0.2 - 4 mm² UL: 300 V / 20 A / AWG 30 - AWG 12	Box

BLF 5.08HC/270F SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF 5.08HC/10/270F SN BK BX	1982200000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, PUSH	4032248686292	30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box

Creation date November 16, 2016 10:55:57 AM CET

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

		IN, Clamping range, rated connection, max.: 3.31 mm ² , Box		
BLF	1982970000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, PUSH	4032248687060 30 pc(s).	IEC: 400 V / 24 A / 0.2 - 2.5 mm ² UL: 300 V / 18.5 A / AWG 26 - AWG 12
5.08HC/10/270F		IN, Clamping range, rated connection, max.: 3.31 mm ² , Box		
SN OR BX				

BLZP 5.08HC/270F SN



Female plugs with clamping-yoke connection for connecting wires with a right-angle (90° or 270°) outlet direction. The female connectors provide space for labelling and can be coded. Fastened by means of a flange or release latch. They also provide an integrated plus/minus screw, protection against faulty insertion of the wire, and they are delivered with open clamping yokes. HC = High Current.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLZP	1950660000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box	4032248629039 30 pc(s).		IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box
5.08HC/10/270F						
SN BK BX						
BLZP	1950390000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, Clamping yoke connection, Clamping range, rated connection, max.: 4 mm ² , Box	4032248628513 30 pc(s).		IEC: 400 V / 23 A / 0.2 - 4 mm ² UL: 300 V / 20 A / AWG 30 - AWG 12	Box
5.08HC/10/270F						
SN OR BX						

OMNIMATE Signal - series BL/SL 5.08 SL 5.08HC/10/180LF 3.2SN OR BX

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 1429-0
Fax: +49 5231 14292083
www.weidmueller.com

Mating connector (fully pluggable)

BLF 5.08HC/270LR SN



Just as reliable as the millionfold proven original and featuring innovative details:

The BLF 5.08HC PUSH IN version of the BLZP 5.08HC female connector is not only different in terms of connection system; it also has a more compact design. Weidmüller's innovative PUSH IN spring connection system stands for the future of easy and tool-free wire connection. HC = High Current.

In terms of versatility, the BLF 5.08HC offers just as much as the version which served as a model:

- 3 tested-and-proven wire outlet directions provide the usual flexibility for application-specific design
- 4 flange variations and the patented release latch allow the locking concept to be based on the requirements of the user
- Use the BLF 5.08HC and SL 5.08HC plug combination to reach the max. rated specifications


General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.	Product data	Packaging
BLF 5.08HC/10/270LR SN OR BX	1983160000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm², Box	403224868725130 pc(s).		IEC: 400 V / 24 A / 0.2 - 2.5 mm² UL: 300 V / 18.5 A / AWG 26 - AWG 12	Box
Discontinued	2016-04-08T00:00:00+02:00	BLF 5.08HC/10/270LR SN BK BX	1982390000	PCB plug-in connector, female plug, 5.08 mm, No. of poles: 10, 270°, PUSH IN, Clamping range, rated connection, max.: 3.31 mm², Box	4032248686483	30 pc(s).


Recommended wave soldering profiles

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Single Wave:

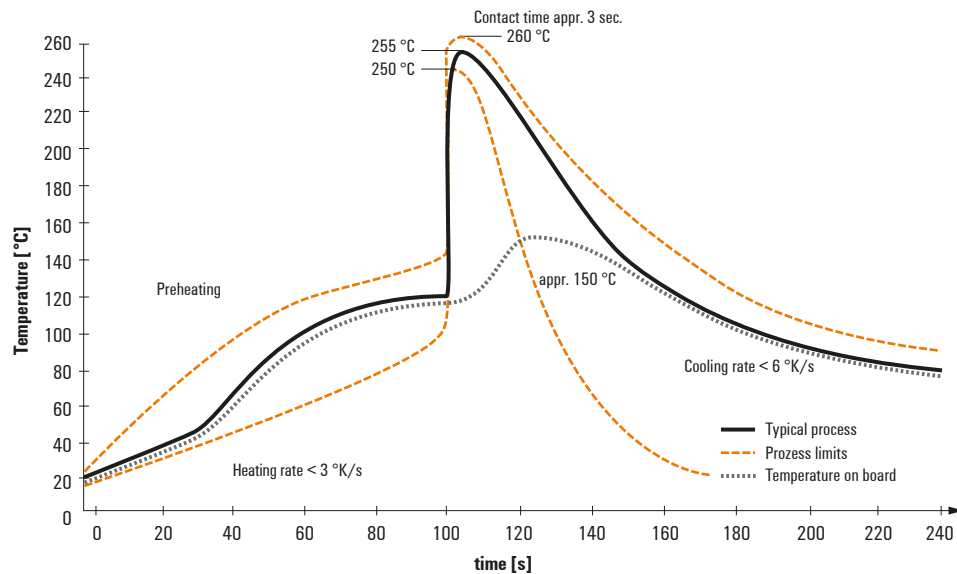

Double Wave:

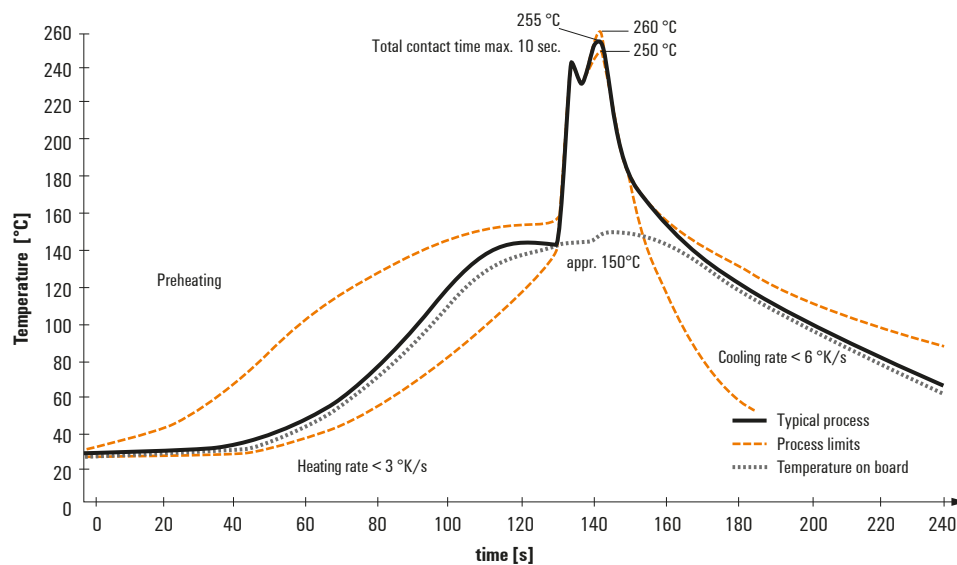

Wave soldering profiles

Wired connection elements should be processed in accordance with the DIN EN 61760-1 standard. We have included two recommendations for practical wave soldering profiles, with which Weidmüller PCB terminals and connectors are qualified.

When choosing a suitable profile for your application, the following factors also need to be considered:

- PCB thickness
- Proportion of Cu in the layers
- Single/double-sided assembly
- Product range
- Heating and cooling rates

The single and double wave profiles each indicate the recommended operating range, including the maximum soldering temperature of 260°C. In practice, the maximum soldering temperature is quite often well below the above maximum profile.

We reserve the right to make technical changes.

Addresses worldwide

Let's connect.

AE United Arab Emirates

Weidmüller Middle East FZE
Warehouse Q3-79
SAIF-Zone
P.O. BOX 8591
Sharjah
Telephone number +971 65572723
Fax number +971 65572724
wme.info@weidmueller.com

AO Angola

Please contact
Phambili Interface
South Africa

AR Argentina

CPI SA
Bauness 2660
C1431DOF Buenos Aires
Telephone number +54 11 4523 8008
Fax number +54 11 4522 0546
info@cpi.com.ar
www.cpi.com.ar

AT Austria

Weidmüller GmbH
IZ NOE Süd, Str 2b, Obj M59,
2355 Wiener Neudorf
Telephone number +43 2236 67080
Fax number +43 2236 6708-899
office.at@weidmueller.com
www.weidmueller.com

AU Australia

Weidmüller Pty. Ltd.
PO BOX 6944
Huntingwood 2148
Huntingwood Drive 43
Huntingwood NSW 2148
Telephone number +61 2 9671 9999
Fax number +61 2 9671 9911
info@weidmuller.com.au
www.weidmuller.com.au

AZ Azerbaijan

Representative Office
Weidmüller Interface
Demirchi Tower, 4th floor
37, Khojali ave.
AZ 1025 Baku
Telephone number +994 12 488 80 37
Fax number +994 12 488 80 37
aliyar.hashimli@weidmueller

BA Bosnia and Herzegovina

Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Serbia
or
BIG electric d.o.o
Mladena Stojanovića 117A
78000 Banja Luka
Telephone number +387 51926277
Fax number +387 51926277
bigelectric@blic.net
www.bigelectric.ba

BE Belgium

Weidmüller Benelux B. V.
Mechelsesteenweg 519 bus
6 en 7
1930 Nossegem
Telephone number +32 2 752 40 70
Fax number +32 2 751 36 06
info@weidmueller.be
www.weidmueller.be

BG Bulgaria

Weid-Bul EOOD
Bul. "Kliment Ohridski" 13
1756 Sofia
Telephone number +359 2 963 2560
Fax number +359 2 963 1098
sofia@weidbul.com
www.weidbul.com

BH Bahrain

Khayber Trading Company
P.O Box 1976
Manama
Telephone number +973 720747
Fax number +973 720331
khayber@batelco.com.bh

BR Brazil

Weidmüller Conexel do Brasil
Conexões Elétricas Ltda.
Av. Presidente Juscelino, 642
- Piraporinha
Diadema, São Paulo
09950-370
Telephone number +55 (11) 4366-9600
Fax number +55 (11) 4362-1677
vendas@weidmueller.com.br
www.weidmueller.com.br

BW Botswana

Please contact
Phambili Interface
South Africa

BY Belarus

TECHNIKON Ltd.
Nezavisimosti pr. 177-9
220125 Minsk
Telephone number +375 17 393-11-77
Fax number +375 17 3930080
wm@technikon.by

CA Canada

W Interconnections Canada
Inc.
10 Spy Court
Markham Ontario L3R 5H6
Telephone number +1 (905) 475-1507 Ext. 9836
Fax number +1 (905) 475-2798
support@weidmuller.ca
www.weidmuller.ca

CG Congo

Please contact
Phambili Interface
South Africa

CH Switzerland

Weidmüller Schweiz AG
Rundbuckstraße 2
8212 Neuhausen am
Rheinfall SH
Telephone number +41 52 674 07 07
Fax number +41 52 674 07 08
info@weidmueller.ch
www.weidmueller.ch

CL Chile

ATS - INTECH
Maria Luisa Santander 0475
Santiago
Providencia 7500859
Telephone number +56 2 341 1271
Fax number +56 2 341 1275
felipe@atsintech.com
www.atsintech.com
CPI CHILE LTDA
Av. Presidente Frei Montalva
6001, 47 complejo el cortijo
Santiago - Conchalí
Telephone number +562 963 8440
Fax number +562 963 8440
cpi@cpichile.cl
www.cpichile.cl

CN China

Weidmüller Interface
(Shanghai) Co. Ltd.
100 Yutong Road
25 F. BM Intercontinental
Business Center
200070 Shanghai
Telephone number +86 21-22195008
Fax number +86 21-22195009
customer.hotline@weidmueller.com.cn
www.weidmueller.com.cn

CO Colombia

Automatización Avanzada
S. A.
Carrera 97 No., 24 c - 23
Bodega 4
110911 Bogotá-D.C.
Telephone number +57 (1) 547-8510
Fax number +57 (1) 422-3044
comercial@
automatizacionavanzada.com
www.
automatizacionavanzada.com

CR Costa Rica

ELVATRON S. A.
la Uruca 400 Norte Banco
Costa Rica
San Jose Costa Rica
Telephone number +506 2961-060
Fax number +506 5200-609
dirk.haase@elvatron.com
www.elvatron.com

CZ Czech Republic

Weidmüller s.r.o.
Lomnického 5/1705
140 00 Praha 4
Telephone number +420 244 001 400
Fax number +420 244 001 499
office@weidmueller.cz
www.weidmueller.cz

DE Germany

Weidmüller GmbH & Co. KG
Ohmstraße 9
32758 Detmold
Postfach 30 54
32720 Detmold
Telephone number +49 5231 1428-0
Fax number +49 5231 14-292083
weidmueller@weidmueller.de
www.weidmueller.de

DK Denmark

Weidmüller Danmark
Vallensbækvej 18A
2605 Brøndby
Telephone number +45 27747800
kundenservice@weidmueller.dk
www.weidmueller.dk

DZ Algeria

SARL INTER ELECTRIC
1a Angles des Rues Okba Ibn
Nafaa et Hassi Beida
2300 Annaba
Telephone number
Fax number
contact@inter-electric.com

EC Ecuador

Elsystec S. A., Electricidad
Sistemas y Tecnología
Vasco de Contreras N35-251
y Mañosa
Quito - Pichincha
Telephone number +593 22456510
Fax number +593 22456755
Elsystec@uio.satnet.net

EE Estonia

Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
Latvia
or

Soots Interface OÜ
Pärnu mnt 142
11317 Tallinn
Telephone number +372 609 6933
Fax number
info@sootsinterface.ee
www.sootsinterface.ee

EG Egypt

Standard Electric (OMEGA)
1, Abdelhamid Badawy Street
Heliopolis
Cairo
Telephone number +202 21805111
Fax number +202 21805600
stdelec@rite.com

ES Spain

Weidmüller, S. A.
Narcis Monturiol 11-13, Pol.
Ind. Sudoeste
8960 Sant Just
Desvern - Barcelona
Telephone number +34 934 803 386
Fax number +34 933 718 055
weidmuller@weidmuller.es
www.weidmuller.es

FI Finland

Weidmüller Suomi,
Weidmüller Aktiebolagetin
sivuliike
Koy Plaza Vivace
Äyrtie 8C
FI 1510 Vantaa
Telephone number +358 20 7351300
Fax number +358 800 114 667
asiakaspalvelu@weidmuller.fi
www.weidmuller.fi

FR France

Weidmüller E. U. R. L.
12, Chaussée Jules César
BP 263 Osny
95523 Cergy-Pontoise Cedex
Telephone number +33 1 34 24 55 00
Fax number +33 1 34 24 55 01
mail@weidmuller.fr

GB Great Britain

Weidmüller Ltd.
Klippon House
Centurion Court Office Park,
Meridian East, Meridian
Business Park
Leicester
LE19 1TP
Telephone number +44 116 282 3470
Fax number +44 116 289 3582
marketing@weidmuller.co.uk
www.weidmuller.co.uk

GE Georgia

Please contact
our Representative Office
Weidmüller Interface
Azerbaijan.

GH Ghana

Please contact
our Representative Office
Weidmüller Interface GmbH
& Co. KG
South Africa.

GR Greece

G.A. Solutions
Ippokratous 11 Metamorfosi
144 52 Athen
Telephone number +30 210 2823233
Fax number +30 210 2823233
info@weidmuller.gr
www.weidmuller.gr

GT Guatemala

Prestelectro, Prestegard
Electro, S.A.
Avenida Petapa 44-22,
Zona 12
Guatemala City
Telephone number +502 2442-3346
Fax number +502 2476-8945
ventas@prestelectro.com

HK Hong Kong

Weidmüller (Hong Kong)
Limited Co. Ltd.
Unit 1617, Metropolis Tower
No. 10 Metropolis Drive,
Hungghom, Kowloon
Telephone number +852 3154 8088
Fax number +852 31548099
Info-hk@weidmueller.com.hk

HR Croatia

ElektroPARTNER d.o.o.
Slavonska avenija 24/6
HR-10000 Zagreb
Telephone number +385 (1) 6184 793
Fax number +385 (1) 6184 795
elektropartner@zg.t-com.hr
www.elektropartner.hr

HU Hungary

Weidmüller Kereskedelmi Kft.
Budapest
Gubacsi út 6.
1097
Telephone number +36 1 382 7700
Fax number +36 1 382 7701
info@weidmueller.hu
www.weidmueller.hu

ID Indonesia

PT. Nego Electrindo
Ruko Mega Grosir Cempaka
Mas Blok I No. 20 – 22
Jakarta 10640
Telephone number +62 21 42882255
Fax number +62 21 42882266
sales@negoelectrindo.co.id

IE Ireland

Please contact
Weidmüller Ltd.
Great Britain

IL Israel

A. U. Shay Ltd.
23/25, Embarr Street
49222 Petach-Tikva
P.O. Box 1 00 49
49222 Petach-Tikva
Telephone number +972 3-923-3601
Fax number +972 3-923-4601
shay@uriel-shay.com
www.uriel-shay.com

ATEKA Ltd.
4, Ha Tavor lane Industrial
area Segula
49691 Petach-Tikva
P.O. Box 4710
Petach-Tikva
Telephone number +972 73-200-1311
Fax number +972 3-924 4245
marketing@ateka.co.il
www.ateka.co.il

IN India

Representative Office
Weidmüller Electronics India
Pvt. Ltd.
No. 9, Union Street, Off.
Infantry Road
BANGALORE
560 001
Telephone number +91-80-22860028
wmi@weidmueller.in
www.weidmueller.com

IR Iran

Representative Office
Tamin Ehtiajat Fanni Tehran
(TAF Co.)
Unit #. 5, No. 62 Iranshahr
Ave.
Tehran - 15816-53717, Iran
Telephone number +9821 8831 7851
info@taf-co.com
http://www.taf-co.com

IS Iceland

Samey Automation Center
Lyngas 13
210 Garoabaer
Telephone number +354 510 5200
Fax number +354 510 5201
Samey@samey.is
www.samey.is

IT Italy

Weidmüller S. r.l.
Via Albert Einstein 4
20092 Cinisello
Balsamo Milano
Telephone number +39 02 660681
Fax number +39 02 6124945
weidmuller@weidmuller.it
www.weidmuller.it

JM Jamaica

Please contact
W Interconnections Inc.
United States



Let's connect.

You can find all Weidmüller addresses and your local contact on the internet at: www.weidmueller.com/countries

Sales company

Representation abroad

without representation abroad

JO Jordan Trans Jordan for Electro PO Box 33 06 07 Amman Telephone number +962 6 533 2020 Fax number +962 6 533 5800 transjordan@batelco.jo	LV Latvia SIA Abi4 Daugavgrivas 31b Riga, LV-1007 Telephone number +371 674 70999 Fax number +371 676 24562 abi_4@tvnet.lv Representative Office Weidmüller Interface GmbH & Co. KG Udens str. 12-118 Riga, LV-1007 Telephone number +371 29254766 Fax number +371 674 65637 ilgonis.rudaks@weidmueller.com www.weidmueller.com	MX Mexico W Interconnections S. A. DE C. V. Blvd. Hermanos Serdán 698, Col. San Rafael Oriente 72029 Puebla Telephone number +52 (222) 268 6227 Fax number +52 (222) 286 6242 clientes@weidmuller.com.mx	PE Peru IMPEXINCA S.A.C. Calle Ortiz de Zevallos No. 105, Urb. San Antonio 18 Lima, Miraflores Telephone number +51 1 447 5608 info@impexinca.pe www.impexinca.pe J & W CIA. S. A. Calle 6 Mz. D Lte. 23, Urb. Ind. Grimanesa 01 Callao Telephone number +51 1 572 2539 Fax number +51 1 572 0152 contacto@jwcia.com www.jwcia.com	RO Romania Representative Office Weidmüller Interface GmbH & Co. KG Ionescu Crum Street, No. 1, 1st Tower, 1st Floor, Office 4 500446 Brasov - Brasov Business Park Telephone number +40 (268) 446 222 Fax number +40 (268) 446 224 claudiu.totea@weidmueller.com www.weidmueller.ro
JP Japan Nihon Weidmüller Co. Ltd. Sphere Tower Tennoz 2-2-8 Higashi-Shinagawa, Shinagawa-ku Tokyo 140-0002 Telephone number +81 3 6711 5300 Fax number +81 3 6711 5333 weidmullerjapan@weidmueller.co.jp www.weidmuller.co.jp	MA Morocco Sofimed 137, Bd Moulay Ismail Roches Noires 20290 Casablanca Telephone number Fax number contact@sofimedmaroc.com	MY Malaysia Connect Plus Technology Sdn Bhd No. 43, Jalan PJS 11/22, Bandar Sunway 46150 Petaling Jaya Selangor Darul Ehsan Telephone number +60 3 5633 7363 Fax number +60 3 5633 6562 paul@cpctech.com.my www.cpctech.com.my	PH Philippines Enclosure Systems Specialists Inc. 2276 Don Chino Roces Avenue Extension Room 103/105 Narra Building 1231 Makati City Telephone number +63 2 813 8580 Fax number +63 2 813 8596 sales_encsys@pltdsl.net www.enclosuresystemsph.com	RS Serbia Representative Office Weidmüller Interface GmbH & Co. KG Ustanicka 189, III sprat lokal 7a 11050 Beograd Telephone number +381 112885274 Fax number +381 112885274 zoran.rabrenovic@weidmueller.com Tela Elektrik d.o.o. Ul. Dr. Drage Ljocić 6 Beograd Telephone number +381 11 2772 415 Fax number +381 11 2772 850 office@tela.rs www.tela.rs
KE Kenya Please contact our Representative Office Weidmüller Interface GmbH & Co. KG South Africa.	MD Moldova BERHORD A & D srl 79/1, str. Milescu Spartaru MD-2075 Chisinau Moldova Telephone number +373 (22) 815002 Fax number +373 (22) 815007 atiuleanu@berhord.com www.ad.berhord.com	MZ Mozambique Please contact Phambili Interface South Africa	PK Pakistan Automation Controls (Pak) Apartment No. 33 C III, Chenab Block, Allama Iqbal Town Lahore Telephone number +92 42 37809948 Fax number +92 42 37809950 nadeem@acpak.com.pk www.acpak.com.pk	RU Russia Weidmüller Group 7/10 Khlebozavodskiy Passage, Moskau 115230 Telephone number +7 495 280 72 71 Fax number +7 495 280 72 71 Info@weidmueller.ru www.weidmueller.ru
KG Kyrgyzstan Please contact our Representative Office Weidmüller Interface Azerbaijan.	ME Montenegro Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia.	NA Namibia Please contact Phambili Interface South Africa	PL Poland Weidmüller Sp. z o. o. ul. Ogrodowa 58 00-876 Warszawa Telephone number +48 22 510 09 40 Fax number +48 22 510 09 41 biuro@weidmuller.com.pl www.weidmuller.pl	SA Saudi Arabia Al Abdulkarim Holding Co. P.O. Box 4 Dammam 31411 Telephone number +966 3 8337110 Fax number +966 3 8829547 E-mail salehsk@akh.com.sa www.weidmueller.ae Saudi Electric Supply Company (SESCO) P.O. Box 32 98 Al Khobar 31952 Telephone number +966 3 8829546 Ext. 3030 Fax number E-mail Safdar.Malik@sescogex.com www.sesco-gex.com
KR Korea Weidmüller Korea Co. Ltd. 9th floor 429, Teheran-ro, Gangnam-Gu Seoul 135-721 Telephone number +82 2-516-0003 Fax number +82 2-516-0090 info@weidmuller.co.kr www.weidmuller.co.kr	MG Madagascar Please contact Phambili Interface South Africa	NG Nigeria Please contact Weidmüller Interface GmbH & Co. KG South Africa	PT Portugal Weidmüller Sistemas de Interface S. A. Estrada Outeiro Polima, R. Augusto Dias da Silva, Lote B - Esc. 2 São Domingos de Rana 2785-515 Abóboda Telephone number +351 214 459 191 Fax number +351 214 455 871 weidmuller@weidmuller.pt www.weidmuller.pt	SE Sweden Weidmüller AB Axel Danielssons väg 271 BOX 31025 SE-200 49 Malmö Telephone number +46 77-143 00 44 Fax number +46 40-37 48 60 info@weidmuller.se www.weidmuller.se
KW Kuwait Kana Controls General Trading & Contracting Co. W. L. L. Al Rai Industrial Area, Plot 28-30, St. 31 13016 Safat B.P. 25593 Telephone number +965 4741373 Fax number +965 4741537 info@kanacontrols.com	MK Macedonia Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Serbia or ELEKTRO - SMK dooel UL. III Makedonska brigada b.b. 1000 Skopje Telephone number +389 22460295 Fax number Elektro-smk@telekabel.net.mk	NL Netherlands Weidmüller Benelux B. V. Franciscusweg 221 1216 SE Hilversum P.O. Box 1505 1200 BM Hilversum Telephone number +31 35 626 12 61 Fax number +31 35 623 20 44 info@weidmuller.nl www.weidmuller.nl	PR Puerto Rico Please contact W Interconnections Inc. United States	SG Singapore Weidmüller Pte. Ltd. 70 Bendemeer Road # 04-03 Luzerne Building Singapore 339940 Telephone number +65 6841 5311 Fax number +65 6841 5377 info@weidmuller.com.sg www.weidmuller.com.sg
KZ Kazakhstan Please contact Weidmüller Group Russia	MN Mongolia Please contact our Representative Office Weidmüller Interface Azerbaijan.	NO Norway Sivilingenier J.F. Knudtzen AS Billingstadsletta 97 1396 Billingstad PO Box 160 1378 Nesbru Telephone number +47 66 98 33 50 Fax number +47 66 98 09 55 firmaPost@jfkknudtzen.no www.jfkknudtzen.no	QA Qatar Doha Motors PO Box 145 Telephone number +974 4651441 Fax number +974 4654579 dmtech@qatar.net.qa http://www.dohamotorsgroup.com/td.html Petroleum Technology Co. W.L.L. PO Box 16069 5th Floor Toyota tower Telephone number +974 44419603 Fax number +974 44419604 petrotec@qatar.net.qa www.petrotec.com.qa	SI Slovenia Elektrospoji d. o. o. Stegne 27 SI- 1000 Ljubljana Osrednjeslovenska Telephone number +386 1 511 3810 Fax number +386 1 511 1604 info@elektrospoji.si www.elektrospoji.si
LB Lebanon Progress Engineering & Trading Enterprises Al Nahr Street Beirut 11-1111 Telephone number +961 1 444 664 Fax number +961 1 561 880 progress@inco.com.lb	MT Malta E. S. S., Electrical Supplies & Services Ltd. San Gwakklin Road Mrieħel Telephone number +356 21255777 Fax number +356 21255999 robert.agius@ess.com.mt	NZ New Zealand Cuthbert S. Steward Ltd. 27 Te Puni Street Petone PO Box 38496 Wellington Mail Centre 5054 Telephone number (04) 568 6156 Fax number (09) 489 1752 cs@cuthbertsteward.co.nz Cuthbert S. Steward Ltd 4 Fred Thomas Drive Aon Building, Ground Floor, South Entry Takapuna PO Box 100 338 North Shore City 745 Telephone number (09) 489 1751 Fax number (04) 568 6056 cs@cuthbertsteward.co.nz	OM Oman DAN INTERNATIONAL LLC. Ghala St. 111 BP 2901 Seeb Telephone number +968 5036 77 Fax number +968 5037 55 yedu@danintl.com	
LT Lithuania Please contact our Representative Office Weidmüller Interface GmbH & Co. KG Latvia or ELEKTROS IRANGA Tinklu g. 29 a LT-5319 Panevezys Telephone number +370 (45) 582 828 Fax number info@eliranga.lt	MU Mauritius Mubelo Electrical Ltd. Office 26, Gateway building, St Jean Road Quatre Bornes Mauritius Telephone number +230 4670989 Fax number +230 4654051 richard.mubelo@orange.mu			
LU Luxembourg Please contact Weidmüller Benelux B. V. Netherlands	MW Malawi Please contact our Representative Office Weidmüller Interface GmbH & Co. KG South Africa.			

Addresses worldwide

Let's connect.

SK	Slovakia ELEKTRIS s.r.o. Elektrárenská 1 831 04 Bratislava Telephone number +421 2/4920 0113 Fax number +421 2/4920 0119 bratislava@elektris.sk	UA	Ukraine LLC WM UKRAINE Levanevskogo str. 6 Kiev 3058 Telephone number +38 044 490 32 48 Fax number info@wm-ua.com.ua wm-ua.com.ua/ Representative Office Weidmüller Interface GmbH & Co. KG Z, office 303 7-D, Zdolbunivska str. Kiev, 2081 Telephone number (mobile) +38 050 440 25 24 info.ua@weidmueller.com	ZA	South Africa Phambili Interface PO Box 193 1609 Johannesburg, Edenvale 5 Bundo Road, Sebenza 1610 Johannesburg Telephone number +27 (11) 4521930 Fax number info@weidmuller.co.za www.weidmuller.co.za Representative Office Weidmüller Interface GmbH & Co. KG 210 Amarand Avenue, Pegasus Building 181 Pretoria, waterkloof Glen ext 2 - Telephone number +27 12 003 2906 Fax number +27 (11) 4526455 Jacques.Vosloo@weidmueller. com www.weidmueller.com
SV	El Salvador Prestegard Electro 11 Avenida Norte No. 240 Edificio Salazar No. 2 San Salvador Telephone number +503 2271 1690 Fax number +503 2221 3851 prestegard@navegante.com.sv	US	United States W Interconnections Inc. 821 Southlake Boulevard Richmond Virginia 23236 Telephone number +1 (804) 794-2877 Fax number +1 (804) 379- 2593 info@weidmuller.com www.weidmuller.com	ZM	Zambia Please contact Phambili Interface South Africa
SY	Syria Please contact Weidmüller Middle East FZE United Arab Emirates	UY	Uruguay REWO Uruguay S. A. AV. Bolivia 2001Esq Rocafuerte 11300 Carrasco Montevideo Telephone number +598 2604 8439 Fax number +598 2604 8439 rewo@rewo Uruguay.com.uy	ZW	Zimbabwe Please contact Phambili Interface South Africa
SZ	Swaziland Please contact Phambili Interface South Africa	UZ	Republic of Uzbekistan Please contact our Representative Office Weidmüller Interface Azerbaijan.		
TH	Thailand Pisanu Engineering Co. Ltd. Kwang Dingaeng, Khet Dingaeng 800/2 Soi Trakulsuk, Asoke- dindaeng Road Dindaeng, Bangkok 10400 Telephone number +66 2 248 2896 Fax number +662 105 6301 ecsales@pisanu.co.th www.pisanu.co.th Representative Office Weidmüller Pte. Ltd. 37/F, Sathorn Square Building 98 North Sathorn Road Bangkok, Silom Bangrak 10500 Telephone number +66 2 105 6300 Fax number +66 2 642 9220 info@weidmuller.com.sg	VE	Venezuela Somerinca C. A. Corazon de Jesus - 3ra Transversal con calle el Carmen- Los Dos Caminos Caracas 1070-A Telephone number +58 2122352748 Fax number +58 2122399341 klocmoeller@cantv.net www.somerinca.com		
TJ	Tajikistan Please contact our Representative Office Weidmüller Interface Azerbaijan.	VN	Vietnam AUMI Industrial Equipment & Automation Company Limited E1, La Thanh Hotel 218 Doi Can Street Lieu Giai Ward, Ba Dinh District Hanoi City Telephone number +84 4 37628601 Fax number +84 4 62661391 aumi@aumi.com.vn www.aumi.com.vn Representative Office Weidmüller Pte. Ltd. Level 16 Saigon Tower Building 29 Le Duan Street District 1 Ho Chi Minh Telephone number +848 3520 7717 Fax number +848 3520 7604 info@weidmuller.com.sg		
TM	Turkmenistan Please contact our Representative Office Weidmüller Interface Azerbaijan.				
TN	Tunisia Please contact Weidmüller E. U. R. L. France				
TR	Turkey Weidmüller Elektronik Ticaret Ltd. Sirketi Kavacik Mah. Orhan Veli Kanik Caddesi 9/1 34810 Beykoz / Istanbul Telephone number +90 (216) 537 10 70 Fax number +90 (216) 537 10 77 info@weidmuller.com.tr www.weidmuller.com.tr				
TW	Taiwan Please contact Weidmüller (Hong Kong) Limited Co. Ltd. Hong Kong				
TZ	Tanzania Please contact our Representative Office Weidmüller Interface GmbH & Co. KG South Africa.				