

# SPLASH RESISTANT FUSE HOLDER

for MAXI® Style Blade Fuse

**RoHS**



## Description

The Inline Splash Resistant Fuse Holder provides an efficient, simple installation method for MAXI® / FK3-style fuse applications in harsh under-the-hood environments. Protected to IP54 rating.


\* PA66-GF30: heat resistant  
UL 94-V0: self extinguishing

## Ordering Information

| Part Number   | Package Size |
|---------------|--------------|
| 01520003TXN   | 10           |
| 279.6800.0001 | 10           |
| 279.6800.0002 | 100          |
| 01520003U     | 500          |

## Dimensions

Dimensions in mm

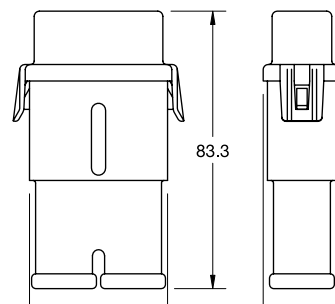

## Ratings

| Part Number    | Description                                                                                            | Fuse Rating |
|----------------|--------------------------------------------------------------------------------------------------------|-------------|
| 01520003TXN941 | Assortment: Fuse Holder 01520003 with terminals, seals and cover for 4-6mm <sup>2</sup> - 10 pcs.      | 60 A        |
| 01520003TXN942 | Assortment: Fuse Holder 01520003 with terminals, seals and cover for 6-10mm <sup>2</sup> - 10 pcs.     | 60 A        |
| 279.6850.0402  | Assortment: Fuse Holder 279.6800.000 with terminals, seals and cover for 4mm <sup>2</sup> - 10 pcs.    | 80 A        |
| 279.6850.0602  | Assortment: Fuse Holder 279.6800.000 with terminals, seals and cover for 6-10mm <sup>2</sup> - 10 pcs. | 80 A        |
| 279.6850.1602  | Assortment: Fuse Holder 279.6800.000 with terminals, seals and cover for 16mm <sup>2</sup> - 10 pcs.   | 80 A        |

# SPLASH RESISTANT MAXI® COMPONENTS

## Ratings

| Part Number   | Description                                                  | Fuse Rating |
|---------------|--------------------------------------------------------------|-------------|
| 279.6800.000_ | Fuse Holder UL 94-V0 *                                       | 80 A        |
| 01520003_     | Fuse Holder PA66-GF30*                                       | —           |
| 01520903_     | Cover                                                        | —           |
| 0913726001    | Loose terminals for wire Ø 2.5 - 4 mm <sup>2</sup> - 300 pcs | —           |
| 09130726TXN   | Loose terminals for wire Ø 2.5 - 4 mm <sup>2</sup> - 10 pcs  | —           |
| 0913727001    | Loose terminals for wire Ø 4 - 6 mm <sup>2</sup> - 300 pcs   | —           |
| 09130727TXN   | Loose terminals for wire Ø 4 - 6 mm <sup>2</sup> - 10 pcs    | —           |

## Ratings

| Part Number | Description                                                     | Fuse Rating |
|-------------|-----------------------------------------------------------------|-------------|
| 0913728001  | Loose terminals for wire Ø 6 - 10 mm <sup>2</sup> - 300 pcs     | —           |
| 09130728TXN | Loose terminals for wire Ø 6 - 10 mm <sup>2</sup> - 10 pcs      | —           |
| 868-905     | Wire seals for wire Ø 2.5 - 6 mm <sup>2</sup> , bulk - 1000 pcs | —           |
| 08680905TXN | Wire seals for wire Ø 2.5 - 6 mm <sup>2</sup> - 10 pcs          | —           |
| 868-906     | Wire seals for wire Ø 6 - 10 mm <sup>2</sup> , bulk - 1000 pcs  | —           |
| 08680906TXN | Wire seals for wire Ø 6 - 10 mm <sup>2</sup> - 10 pcs           | —           |