


CONNECTOR TYPE F, EN 60603, DIN 41612, MALE, 48 CONTACTS, SOLDER PINS, 2.9 MM

CATALOG NUMBER

69001-846

	d	b	z
2	□	□	□
4	□	□	□
6	□	□	□
8	□	□	□
10	□	□	□
12	□	□	□
24	□	□	□
26	□	□	□
28	□	□	□
30	□	□	□
32	□	□	□

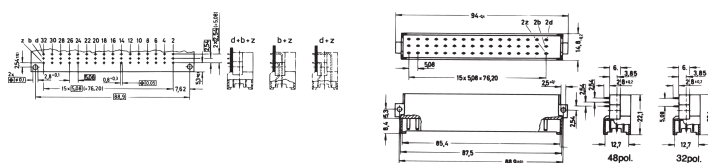

Male / Female DIN connector form F. Requirement class 2 as per EN 60603 (DIN 41642).

CERTIFICATIONS



FEATURES

Requirement class 2 as per EN 60603 (DIN 41642)

Separate Coding

PRODUCT ATTRIBUTES

Product Type: Connector
Type: Male Connectors
Works With: Front Panels
Number of Contacts: 48
Contact Material: Gold Plated
Max Current @ 20°C: 6A
Max Contact Resistance: 20mO
Test Voltage (Ueff), Contact-Contact: 1.55kV
Test Voltage (Ueff), Contact-Earth: 2.5kV
Row Assignment: Z; B; D
Finish: Gold Plated
Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER